


E10013



Wirable socket

SDOAJ040PLSFKPG

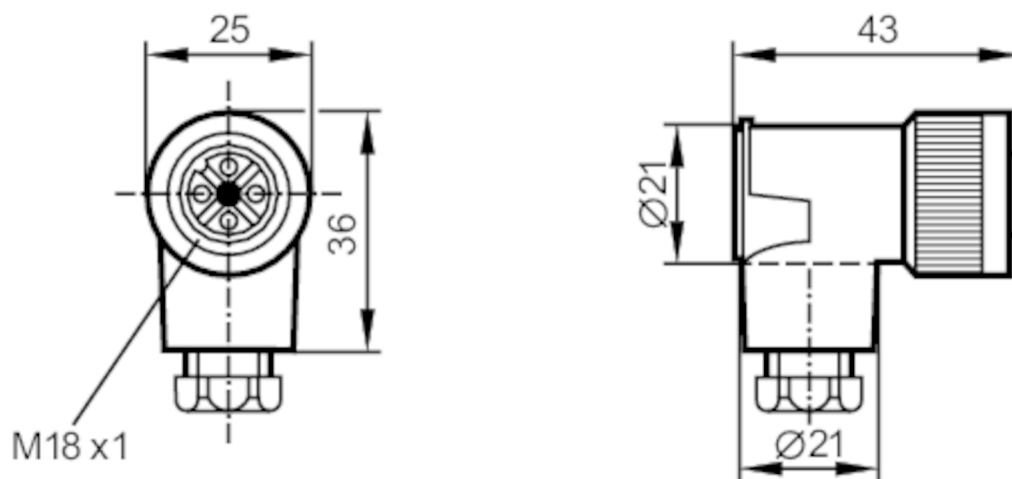

Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 65

Mechanical data

Weight	[g]	31.4
Dimensions	[mm]	43 x 25 x 36
Materials		PA
Moulded-body material		PA
Material nut		PA

Remarks

Pack quantity	1 pcs.
---------------	--------

E10013



Wirable socket

SDOAJ040PLSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - socket

Connector: 1 x M18, angled; coding: A; Moulded body: PA; Locking: PA



Connection

