


E10411



Adapter plug

ESTGH040MSS00,5E04 (PG9)

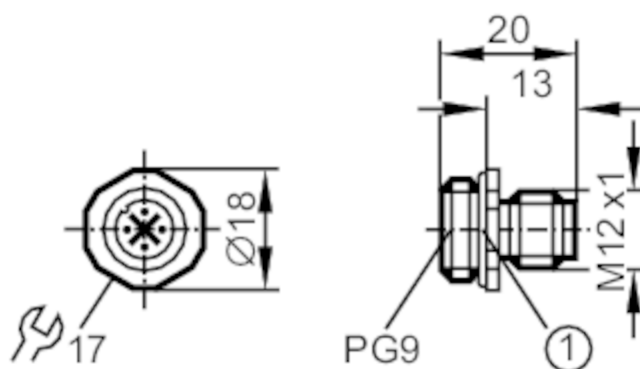

1 O-ring



Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Mechanical data

Weight	[g]	17.1
Dimensions	[mm]	18 x 18 x 20
Mounting thread		PG 9
Materials		diecast zinc nickel-plated
Moulded-body material		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E10411



Adapter plug

ESTGH040MSS00,5E04 (PG9)

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.25 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: diecast zinc, nickel-plated



Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white