


E11194



Adapter plug

ESTGH080MSS00,5E08 (PG9)

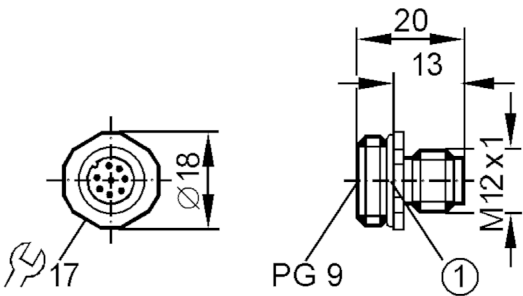

1 O-ring



Electrical data		
Operating voltage	[V]	< 50 AC / < 75 DC
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Weight	[g]	38.473
Mounting thread		PG 9
Materials		diecast zinc nickel-plated
Moulded-body material		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11194



Adapter plug


ESTGH080MSS00,5E08 (PG9)

Electrical connection

Cable: 0.5 m, PVC; 8 x 0.25 mm² (14 x Ø 0.15 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: diecast zinc, nickel-plated

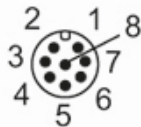

Connection

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD

colours to DIN
47100

BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow

Core colours :