


# E11510



## Wirable socket

SDOAH042MSSFKPG

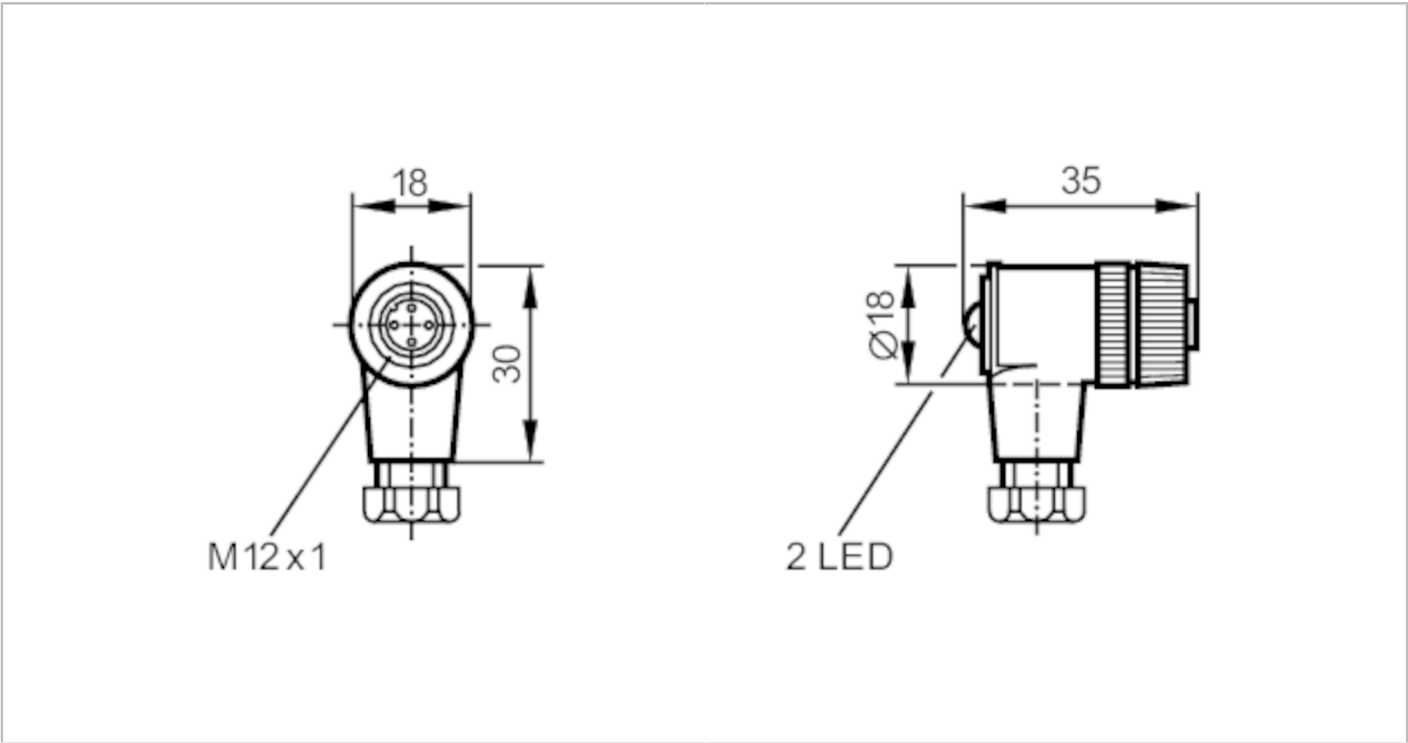

| Application                   |                                          |                 |
|-------------------------------|------------------------------------------|-----------------|
| Special feature               | Free from silicone; Gold-plated contacts |                 |
| Free from silicone            | yes                                      |                 |
| Electrical data               |                                          |                 |
| Operating voltage             | [V]                                      | 10...30 DC      |
| Max. current load total       | [A]                                      | 4; (...40 °C)   |
| Outputs                       |                                          |                 |
| Electrical design             | PNP                                      |                 |
| Operating conditions          |                                          |                 |
| Ambient temperature           | [°C]                                     | -25...85        |
| Protection                    | IP 68                                    |                 |
| Mechanical data               |                                          |                 |
| Weight                        | [g]                                      | 28.6            |
| Dimensions                    | [mm]                                     | 30 x 18 x 35    |
| Materials                     | PA                                       |                 |
| Moulded-body material         | PA                                       |                 |
| Material nut                  | brass, nickel-plated                     |                 |
| Displays / operating elements |                                          |                 |
| Display                       | switching status                         | 1 x LED, yellow |
|                               | operation                                | 1 x LED, green  |
| Remarks                       |                                          |                 |
| Pack quantity                 | 1 pcs.                                   |                 |

# E11510



## Wirable socket

SDOAH042MSSFKPG

### Electrical connection

screw terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 4...6 mm

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated



### Connection

