


E11590



Plug with CAN bus terminating resistor

SSTGH050ZDAFKPG

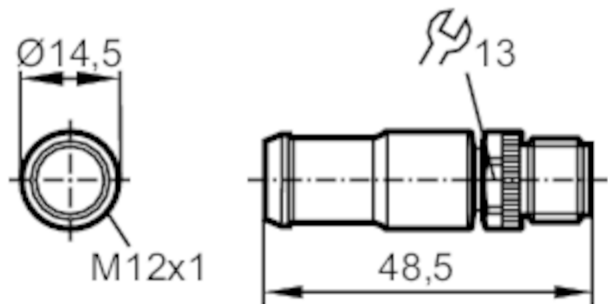

Application		
Special feature		Gold-plated contacts
Application		CAN bus
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 68
Mechanical data		
Weight	[g]	8.39
Dimensions	[mm]	14.5 x 14.5 x 48.5
Materials		TPU
Moulded-body material		TPU
Material nut		diecast zinc, nickel-plated
Remarks		
Remarks		The CAN bus terminating resistor (120 Ω) is integrated in the M12 connector.
Pack quantity		1 pcs.

E11590




Plug with CAN bus terminating resistor

SSTGH050ZDAFKPG

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Tightening torque: ...0.6 Nm

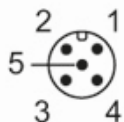

Connection

