


Fibre optic diffuse reflection sensor

FT-00-P-A-R4/1,5M

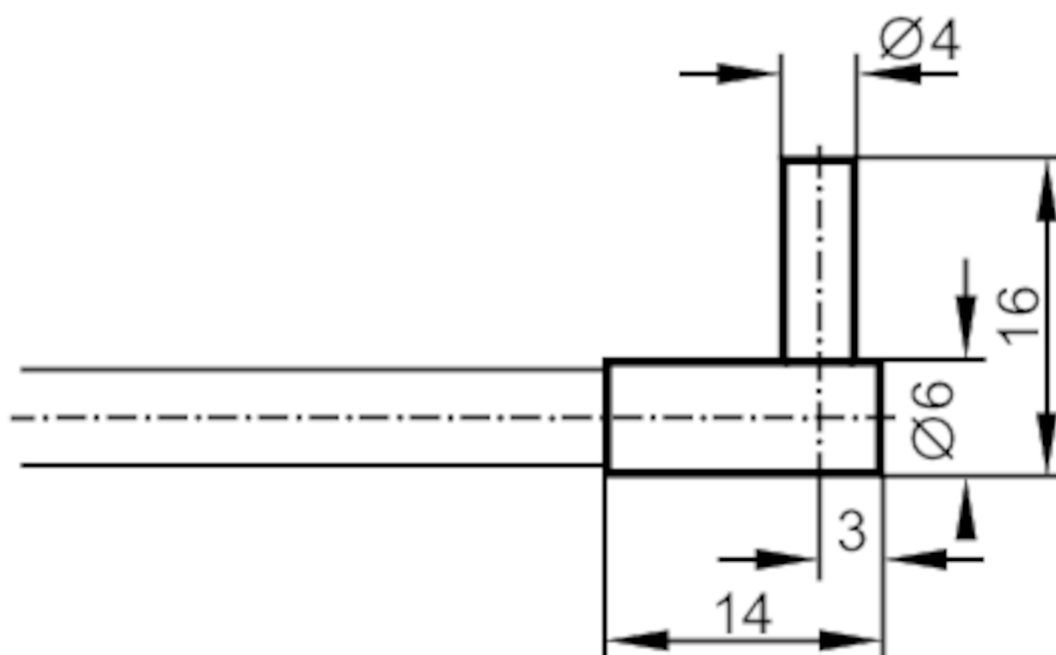

Application

Function principle

Diffuse reflection sensor

Application

For use in industrial environments

Detection zone

Range with fibre optic
amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

36

OUF

Range fibre optics

[mm]

36

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Weight

[g]

68.5

Version of sensing head

angled

Sensing head diameter

[mm]

4

Sensing head length

[mm]

10

Total length

[mm]

1500

Min. bending radius

[mm]

20

Fibre arrangement



E20351



Fibre optic diffuse reflection sensor

FT-00-P-A-R4/1,5M

Materials	Adapter: PPE
Fibre material	glass
Fibre head material	aluminium
Fibre sheath material	PVC
Accessories	
Items supplied	E20103
Remarks	
Pack quantity	1 pcs.