


# E30019



## Wirable plug

SSTGH040VASFPKG

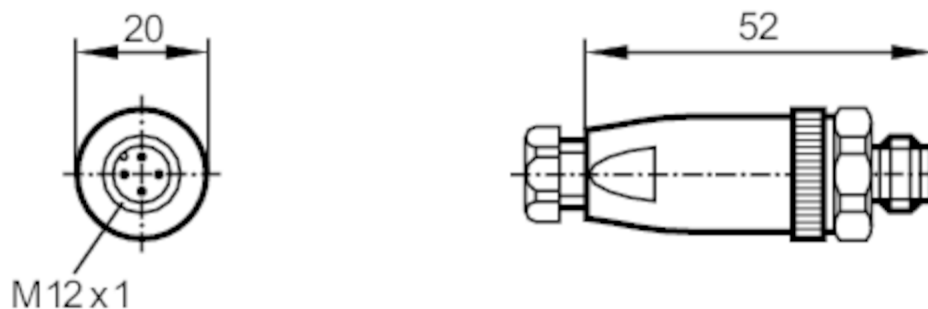

### Application

|                 |                      |
|-----------------|----------------------|
| Special feature | Gold-plated contacts |
|-----------------|----------------------|

### Electrical data

|                         |     |               |
|-------------------------|-----|---------------|
| Operating voltage       | [V] | 10...55 DC    |
| Max. current load total | [A] | 4; (...40 °C) |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -40...85 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |      |                                |
|-----------------------|------|--------------------------------|
| Weight                | [g]  | 23                             |
| Dimensions            | [mm] | 20 x 20 x 52                   |
| Materials             |      | PA                             |
| Moulded-body material |      | PA                             |
| Material nut          |      | stainless steel (316Ti/1.4571) |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E30019



## Wirable plug

SSTGH040VASFPKG

### Electrical connection

terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 4...6 mm

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated



### Connection

