




Welding thermowell for temperature sensors

THERMOWELL, D6/WELD-IN/G1/2 conical/L=150

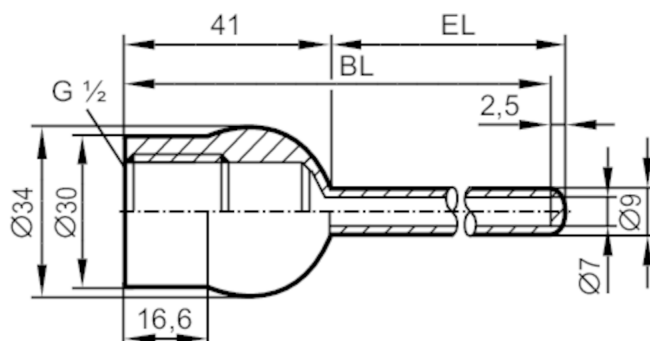

EC 1935/2004 EHEDG Certified



Application

Design	for temperature sensors EL = 150 mm	
Pressure rating	[bar]	300
Pressure rating	[MPa]	30

Mechanical data

Weight	[g]	184.7
Materials	stainless steel (316L/1.4404)	
Sensor connection	G 1/2 sealing cone Ø 6 mm	
Process connection	welding adapter Ø 34 mm	
Surface characteristics Ra/Rz of the wetted parts	≤ 0.6 / -	
Installation length EL	[mm]	149
Bore length BL	[mm]	187

Remarks

Pack quantity	1 pcs.
---------------	--------