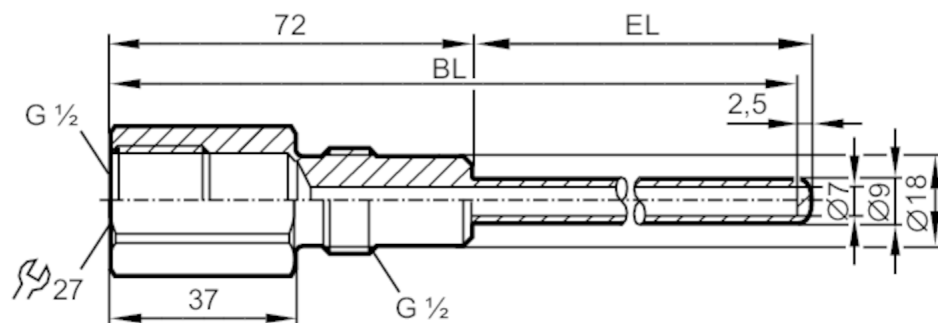


**Thermowell for temperature sensors**

THERMOWELL, D6/ G1/2 conical/L=150

EC 1935/2004 EHEDG Tested 

| Application                                       |       |                                     |
|---------------------------------------------------|-------|-------------------------------------|
| Design                                            |       | for temperature sensors EL = 150 mm |
| Pressure rating                                   | [bar] | 16                                  |
| Pressure rating                                   | [MPa] | 1.6                                 |
| Mechanical data                                   |       |                                     |
| Weight                                            | [g]   | 197.5                               |
| Materials                                         |       | stainless steel (316L/1.4404)       |
| Sensor connection                                 |       | G 1/2 sealing cone Ø 6 mm           |
| Process connection                                |       | G 1/2                               |
| Surface characteristics Ra/Rz of the wetted parts |       | ≤ 0.6 / -                           |
| Installation length EL                            | [mm]  | 118                                 |
| Bore length BL                                    | [mm]  | 187                                 |
| Remarks                                           |       |                                     |
| Pack quantity                                     |       | 1 pcs.                              |