


Thermowell for temperature sensors

THERMOWELL, D6/1,5"CLAMP/L=230

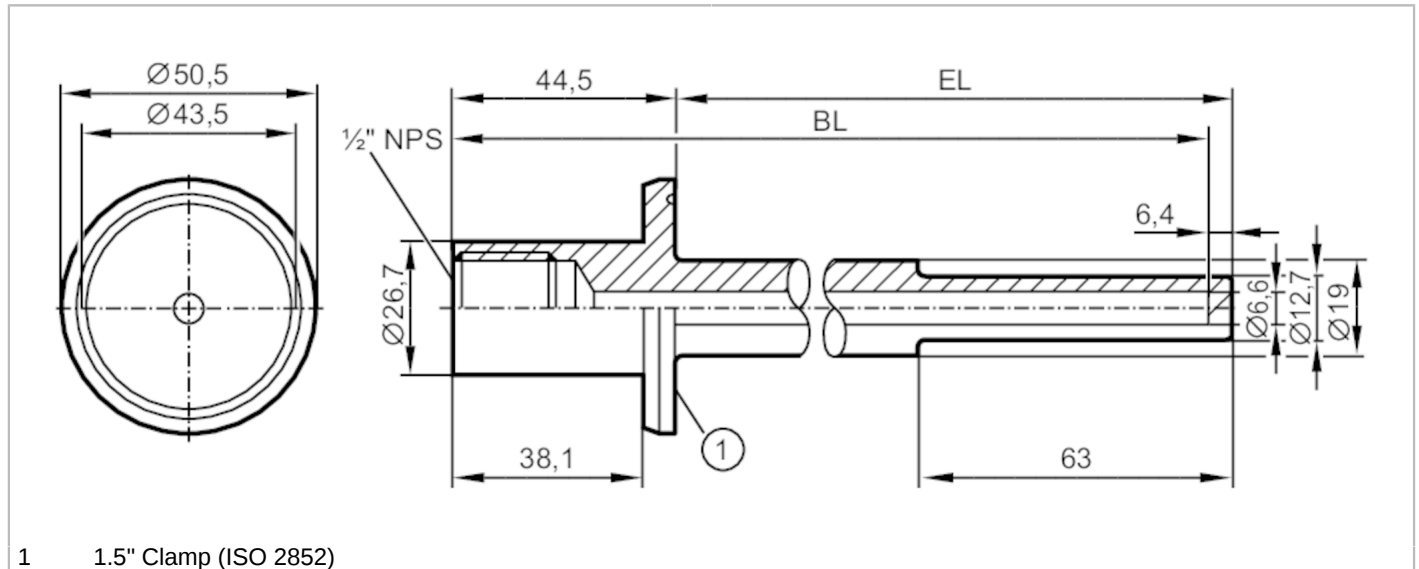

EC 1935/2004 EHEDG Certified


Application

Design	for temperature sensors EL = 300 mm	
Pressure rating	[bar]	25
Pressure rating	[MPa]	2.5

Mechanical data

Weight	[g]	500.5
Materials	stainless steel (316L/1.4404)	
Sensor connection	1/2" NPS Ø 6 mm suitable for G1/2 and 1/2" NPT	
Process connection	Clamp DN25...DN40 (1...1,5") DIN 32676 (ISO 2852)	
Surface characteristics Ra/Rz of the wetted parts	≤ 0.6 / -	
Installation length EL	[mm]	191
Bore length BL	[mm]	228.6

Remarks

Pack quantity	1 pcs.
---------------	--------