


Thermowell for temperature sensors

THERMOWELL, D3/DN25 Ingold/EL=25

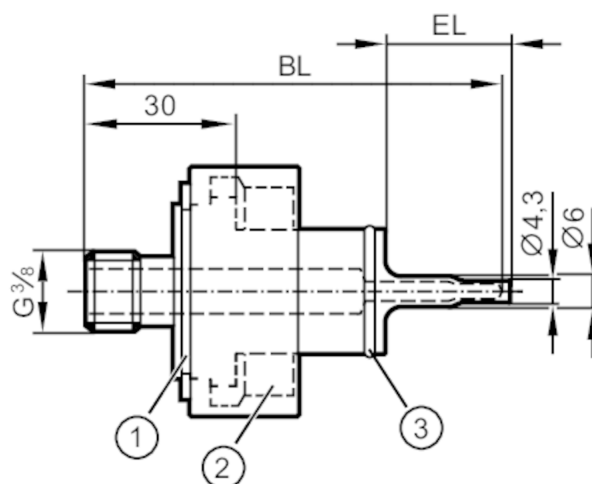

- 1 retaining ring
- 2 Lock nut G 1 1/4
- 3 O-ring

Application

Design	for temperature sensors EL = 83 mm	
Pressure rating	[bar]	16
Pressure rating	[MPa]	1.6

Mechanical data

Weight	[g]	868
Materials	stainless steel (316L/1.4435)	
Sensor connection	G 3/8 internal thread Ø 3 mm	
Process connection	Ingold Ø 25 mm	
Surface characteristics Ra/Rz of the wetted parts	< 0.4 / -	
Installation length EL	[mm]	25
Bore length BL	[mm]	83

Remarks

Pack quantity	1 pcs.
---------------	--------