




Thermowell for temperature sensors

THERMOWELL, D3/DIN10/15/20 CLAMP/EL=38

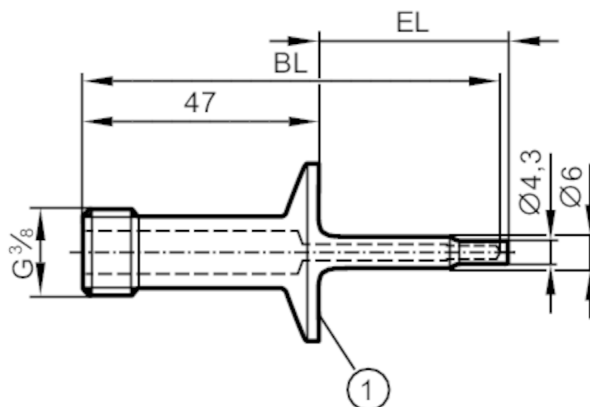

EC 1935/2004 FDA

Application

Design	for temperature sensors EL = 83 mm	
Pressure rating	[bar]	25
Pressure rating	[MPa]	2.5

Mechanical data

Weight	[g]	70
Materials	stainless steel (316L/1.4435)	
Sensor connection	G 3/8 internal thread Ø 3 mm	
Process connection	Clamp DN10...DN20 (1/2...3/4") DIN 32676 (ISO 2852)	
Surface characteristics Ra/Rz of the wetted parts	< 0.4 / -	
Installation length EL	[mm]	38
Bore length BL	[mm]	83

Remarks

Pack quantity	1 pcs.
---------------	--------