




Thermowell for temperature sensors

THERMOWELL, D3/1-1,5"CLAMP/EL=50

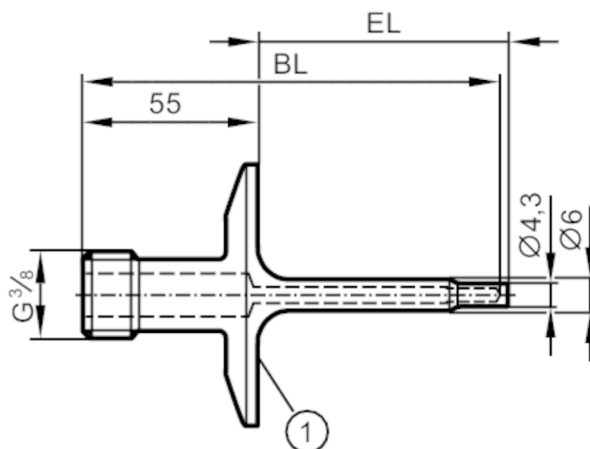

EC 1935/2004 FDA

Application

Design for temperature sensors EL = 83 mm

Pressure rating [bar] 25

Pressure rating [MPa] 2.5

Mechanical data

Weight [g] 108.4

Materials stainless steel (316L/1.4435)

Sensor connection G 3/8 internal thread Ø 3 mm

Process connection Clamp DN25...DN40 (1...1,5") DIN 32676 (ISO 2852)

Surface characteristics Ra/Rz of the wetted parts < 0.4 / -

Installation length EL [mm] 50

Bore length BL [mm] 83

Remarks

Pack quantity 1 pcs.