


ZDO4H050MSS0000-00STAK120MSS

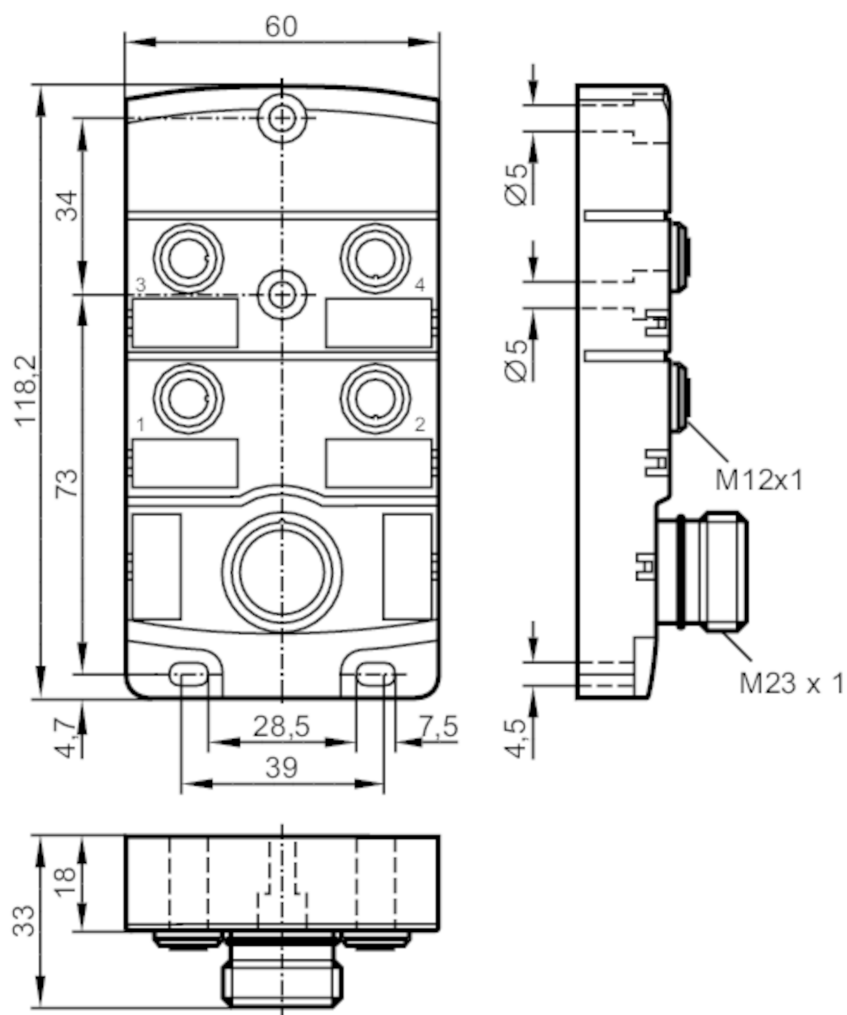

Free from silicone; Gold-plated contacts

yes

< 30 DC; ("supply class 2" to cULus)

[M]

[A]

4

[A]

12

[°C]

-25...80



Splitter box

ZDO4H050MSS0000-00STAK120MSS

Protection	IP 67
------------	-------

Tests / approvals

UL approval	Enclosure type	Type 1
-------------	----------------	--------

Mechanical data

Weight	[g]	236.5
Dimensions	[mm]	33 x 60 x 118.2
Materials		PA
Moulded-body material		PA
Number of ports splitter box		4
Connector type		M12

Accessories


Items supplied	Protective caps: 2
	labels: 4

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection

Connector: 1 x M23; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

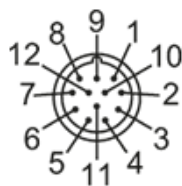

Connection

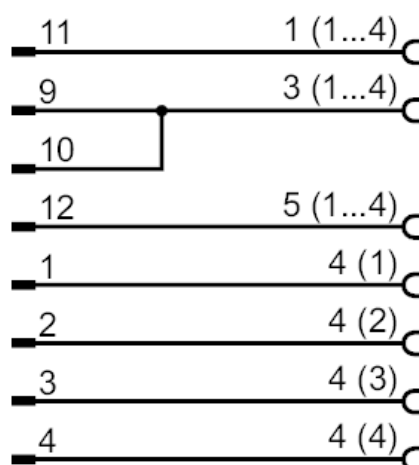



Splitter box

ZDO4H050MSS0000-00STAK120MSS

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

