




Splitter box

ZDO8H050MSS0000-00STAK120MSS

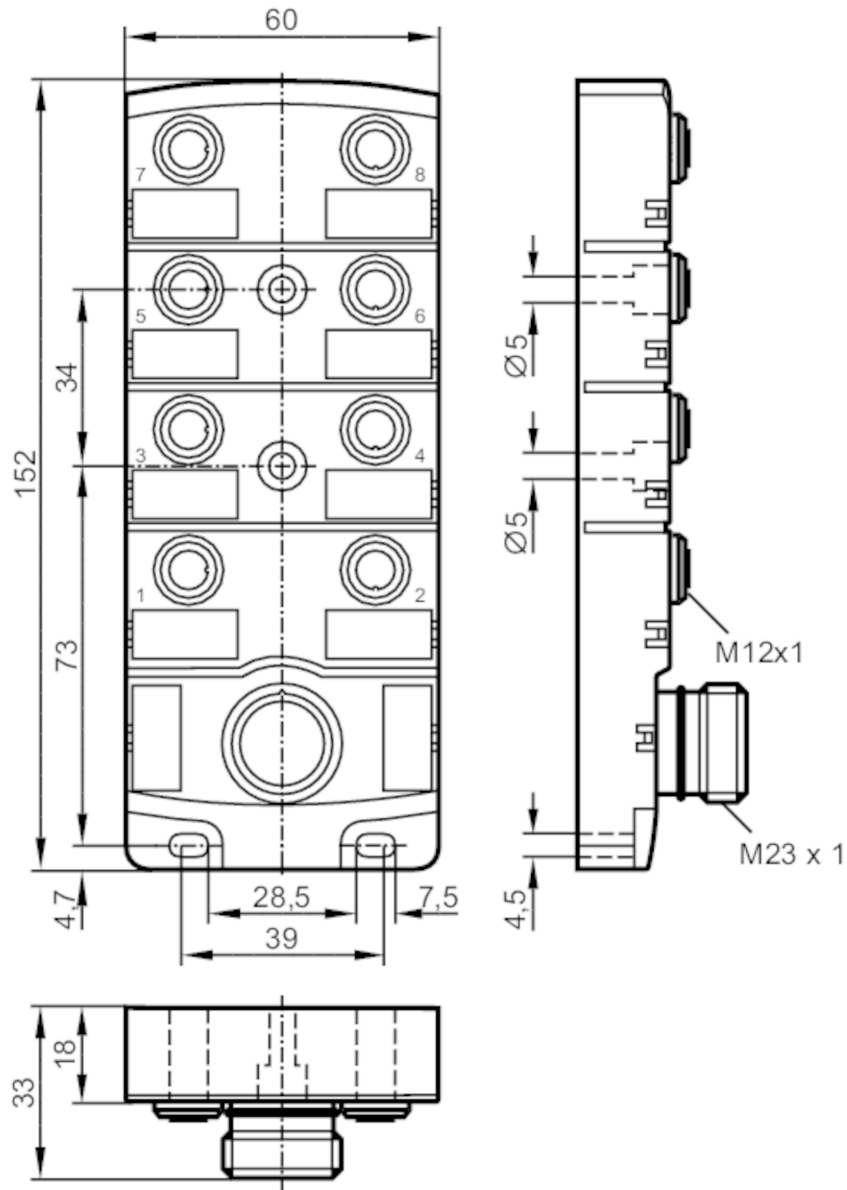

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 DC; ("supply class 2" to cULus)
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-25...80
---------------------	------	----------



Splitter box

ZDO8H050MSS0000-00STAK120MSS

Protection	IP 67
------------	-------

Tests / approvals

UL approval	Enclosure type	Type 1
-------------	----------------	--------

Mechanical data

Weight	[g]	303.5
Dimensions	[mm]	33 x 60 x 152
Materials		PA
Moulded-body material		PA
Number of ports splitter box		8
Connector type		M12

Accessories


Items supplied	Protective caps: 2
	labels: 8

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection

Connector: 1 x M23; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

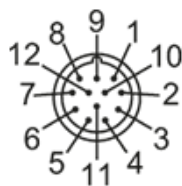

Connection

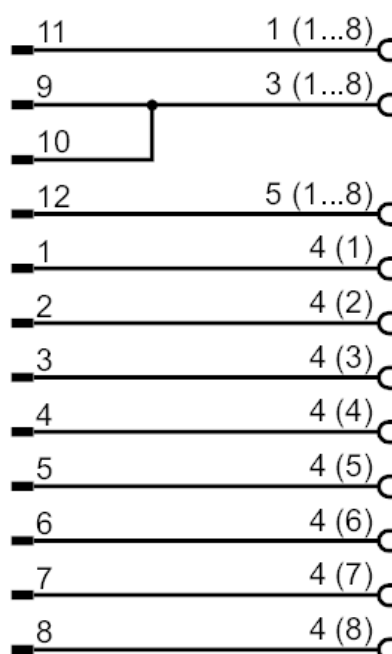



Splitter box

ZDO8H050MSS0000-00STAK120MSS

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

