




Splitter box

ZDO8H05HMSS0000-00STAK190MSS

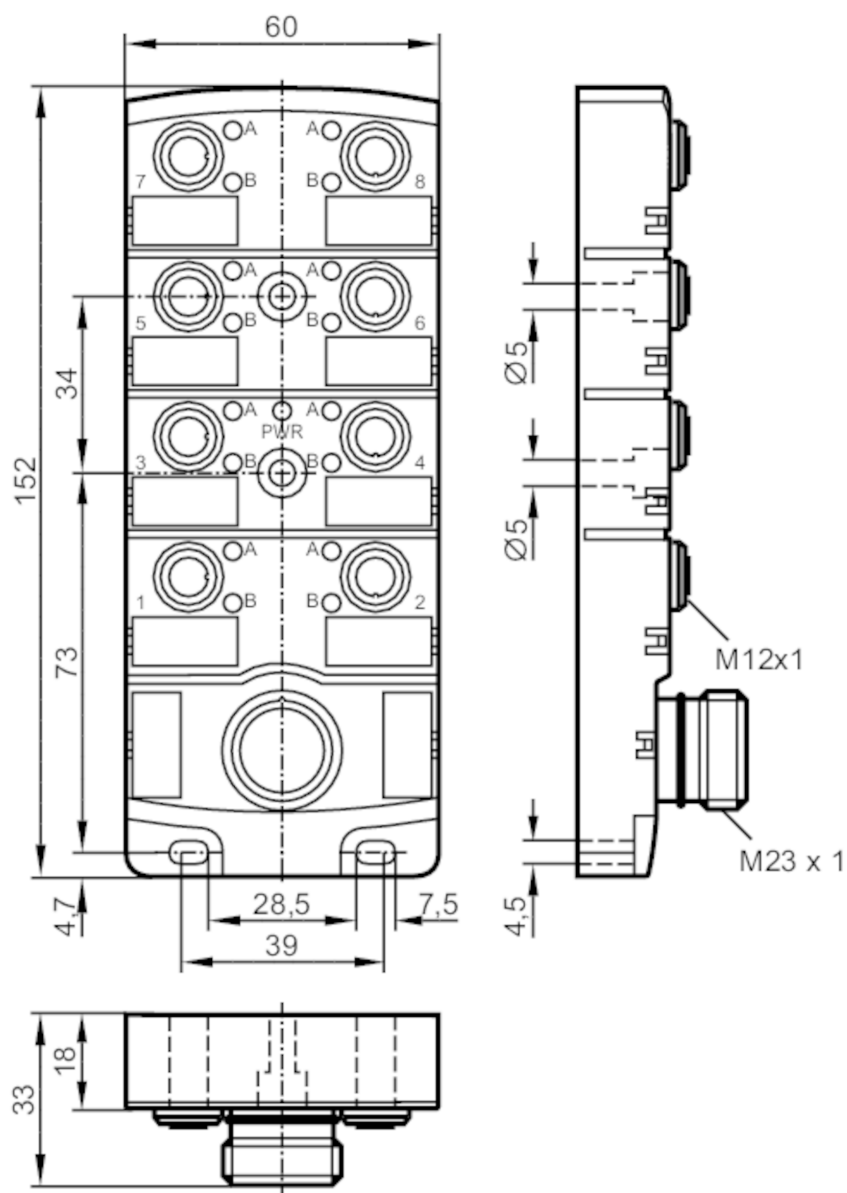

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC; ("supply class 2" to cULus)
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10


Outputs

Electrical design	PNP
-------------------	-----



Splitter box


ZDO8H05HMSS0000-00STAK190MSS

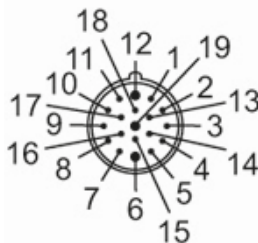Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Tests / approvals		
UL approval	Enclosure type	Type 1
Mechanical data		
Weight	[g]	306
Dimensions	[mm]	33 x 60 x 152
Materials		PA
Moulded-body material		PA
Number of ports splitter box		8
Connector type		M12
Displays / operating elements		
Display	switching status	16 x LED, yellow
	operation	1 x LED, green
Accessories		
Items supplied	Protective caps: 2	
	labels: 8	
Remarks		
Pack quantity	1 pcs.	
Electrical connection - Connection		
Connector: 1 x M23; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm		
		

Splitter box

ZDO8H05HMSS0000-00STAK190MSS

Connection

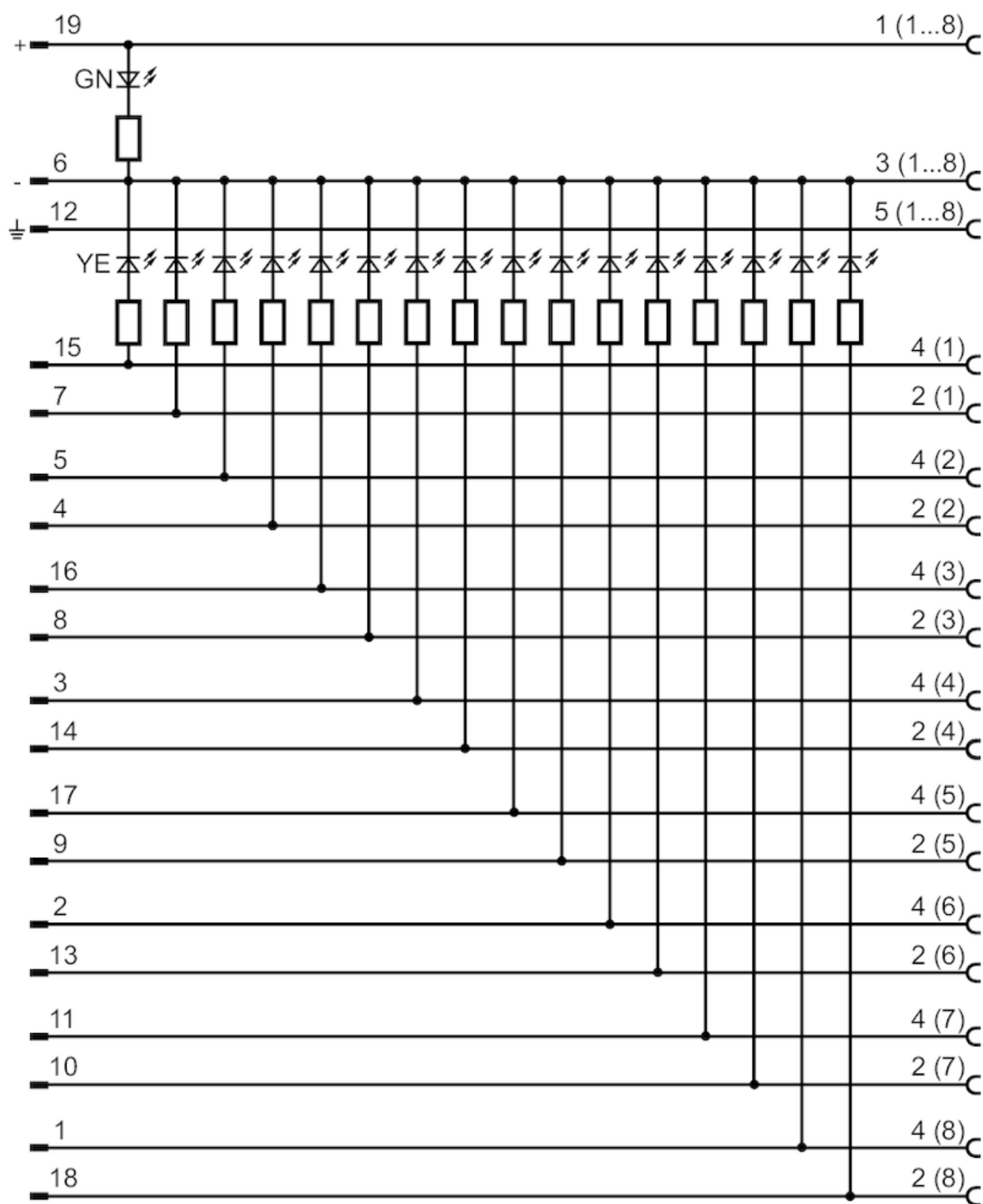



Splitter box

ZDO8H05HMSS0000-00STAK190MSS

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

