




Splitter box

ZDO8F039MSS0000-STGH120MSS

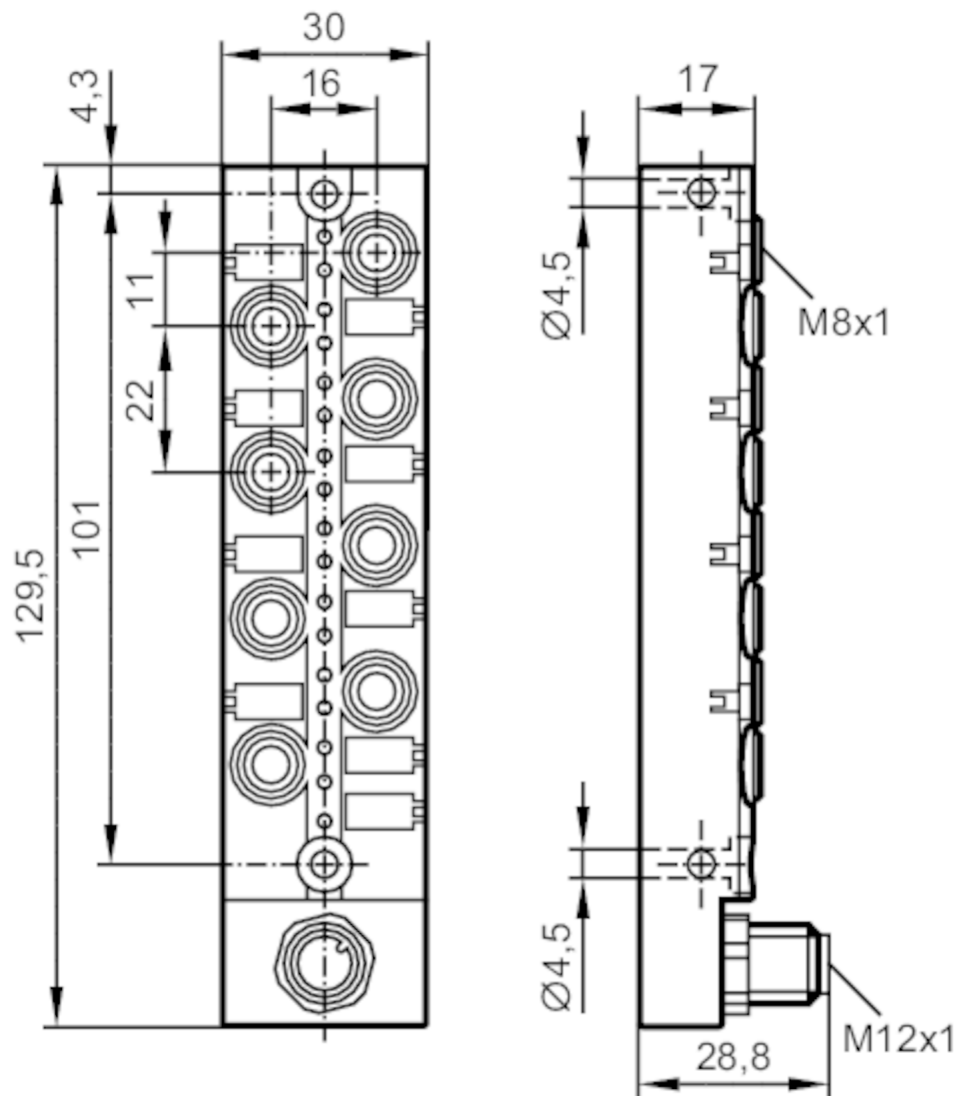

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	15...30 DC
Protection class		III
Max. current load per module/slot	[A]	1
Max. current load total	[A]	1
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...80



Splitter box

ZDO8F039MSS0000-STGH120MSS

Ambient temperature (moving)	[°C]	-5...60
Protection		IP 67

Mechanical data

Weight	[g]	125
Dimensions	[mm]	28.8 x 30 x 129.5
Materials		PBT-GF20; brass nickel-plated
Moulded-body material		PBT-GF 20 / brass, nickel-plated
Number of ports splitter box		8
Connector type		M8

Displays / operating elements


Display	switching status	8 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection


Connector: 1 x M12; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

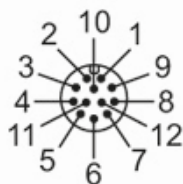

Splitter box

ZDO8F039MSS0000-STGH120MSS

Connection

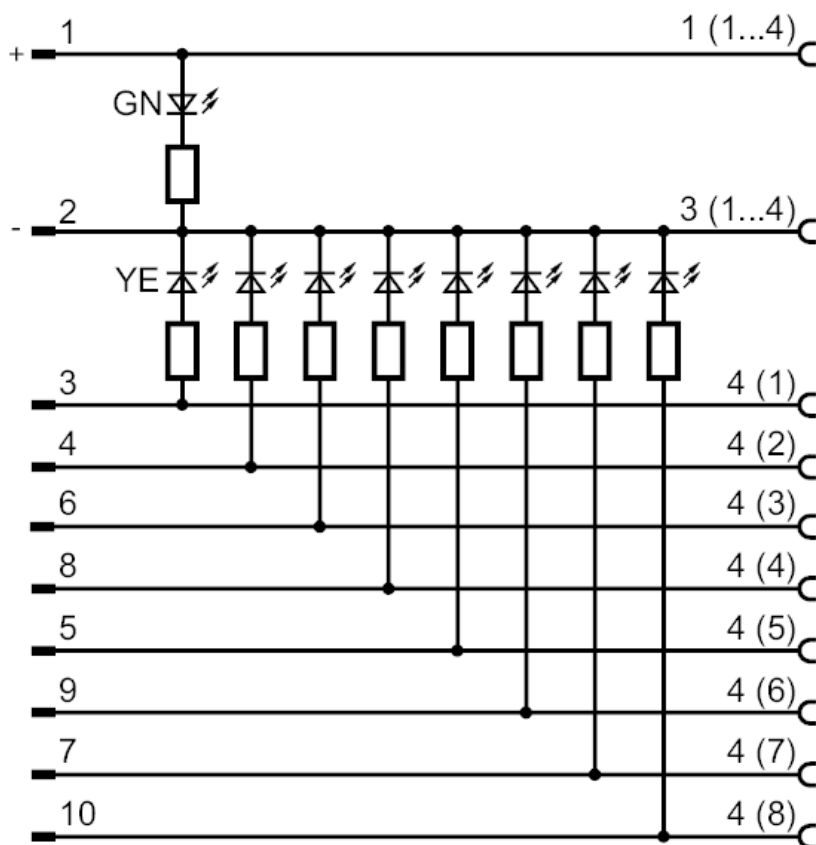

Electrical connection - slot

Connector: 8 x M8; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

