


Y-splitter

ZDO2H040VAS0000-00STGH050VAS

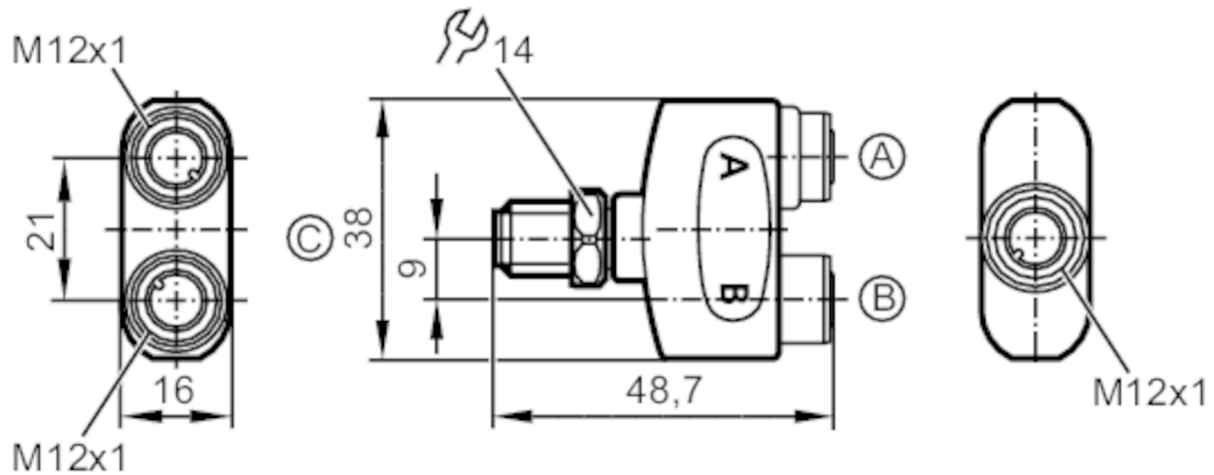

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	< 60 AC/DC; (cULus: 30 AC / 42 DC)
Protection class	II
Max. current load per module/slot [A]	4
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-25...100
Note on ambient temperature	cULus: ...65 °C
Storage temperature [°C]	-25...55
Storage humidity [%]	10...100
Other climatic conditions for storage according to stated class	1K22/ DIN 60721-3-1
Protection	IP 65; IP 67; IP 68; IP 69K

Tests / approvals

UL approval	power supply	Class 2
	File number UL	E191684

Mechanical data

Weight [g]	56.3
Materials	housing: PA Halogen-free; Sealing: EPDM

EBF010



Y-splitter

ZDO2H040VAS0000-00STGH050VAS


Moulded-body material	PA, Halogen-free
Material nut	stainless steel (316L/1.4404)

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: PA, Halogen-free; Locking: stainless steel (316L/1.4404); Contacts: gold-plated; Tightening torque: 0.6...1.2 Nm

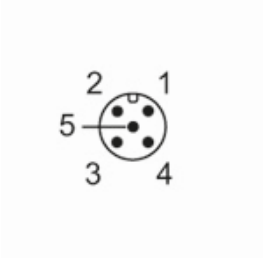

Connection

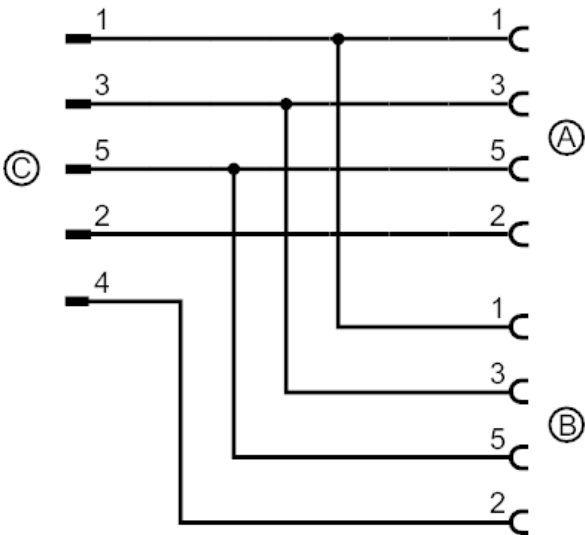

connection to IEC 61076-2-101

Electrical connection - socket

Connector: 2 x M12; coding: A; Moulded body: PA, Halogen-free; Locking: stainless steel (316L/1.4404); Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

