


## Connecting cable with plug

ASTGH020MSS0002H02

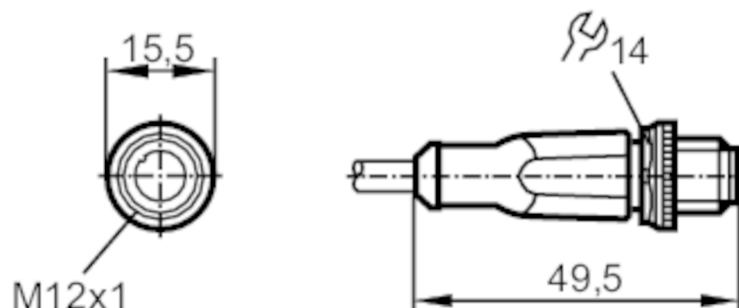

## Application

|                    |                                                                                |
|--------------------|--------------------------------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability |
| Free from silicone | yes                                                                            |

## Electrical data

|                         |     |                     |
|-------------------------|-----|---------------------|
| Operating voltage       | [V] | < 250 AC / < 300 DC |
| Protection class        |     | II                  |
| Max. current load total | [A] | 4                   |

## Operating conditions

|                                                                 |      |                             |
|-----------------------------------------------------------------|------|-----------------------------|
| Ambient temperature                                             | [°C] | -25...90                    |
| Note on ambient temperature                                     |      | cULus: ...75 °C             |
| Ambient temperature (moving)                                    | [°C] | -25...90                    |
| Note on ambient temperature (moving)                            |      | cULus: ...75 °C             |
| Storage temperature                                             | [°C] | -25...55                    |
| Storage humidity                                                | [%]  | 10...100                    |
| Other climatic conditions for storage according to stated class |      | 1K22/ DIN 60721-3-1         |
| Protection                                                      |      | IP 65; IP 67; IP 68; IP 69K |

## Mechanical data

|              |      |                      |
|--------------|------|----------------------|
| Weight       | [g]  | 77.2                 |
| Dimensions   | [mm] | 15.5 x 15.5 x 49.5   |
| Materials    |      | housing: TPU orange  |
| Material nut |      | brass, nickel-plated |

EVC183



Connecting cable with plug

ASTGH020MSS0002H02

|                        |                                 |                                                                                    |
|------------------------|---------------------------------|------------------------------------------------------------------------------------|
| Drag chain suitability | yes                             |                                                                                    |
| Drag chain suitability | bending radius for flexible use | min. 10 x cable diameter                                                           |
|                        | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s² |
|                        | bending cycles                  | > 5 Mio.                                                                           |
|                        | torsional strain                | ± 180 °/m                                                                          |

Remarks


|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 4.9 mm; 2 x 0.34 mm² (42 x Ø 0.1 mm )

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

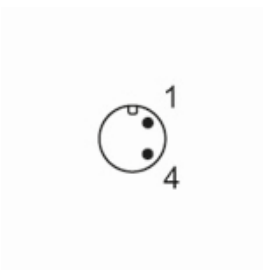

Connection

 

BK = Core colours :  
WH = black  
white