

EVC813



Wirable plug

SSTA040MSSFKPG



Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Protection class		II
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...90
Storage temperature	[°C]	-25...55
Storage humidity	[%]	10...100
Other climatic conditions for storage according to stated class		1K22/ DIN 60721-3-1
Protection		IP 65; IP 67; IP 68; IP 69K

Mechanical data

Weight	[g]	33.6
Moulded-body material		PA 6.6
Material nut		brass, nickel-plated
Sealing material		FKM

Remarks

Pack quantity		1 pcs.
---------------	--	--------



Wirable plug

SSTA040MSSFKPG

Electrical connection


screw terminals: 0.25...1 mm²; Cable sheath: Ø 3.5...6 mm; AWG 23...17

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6, orange; Locking: brass, nickel-plated; Sealing: FKM; Contacts: gold-plated; Tightening torque: 0.6...1.2 Nm; Take into account the maximum value of the counterpart!



Connection

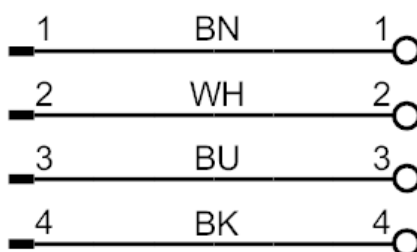

Core colours :
 BN = brown
 WH = white
 BU = blue
 BK = black
 colours to DIN EN 60947-5-2