


EVF565



Wirable socket

SDOGH040VASFKPG

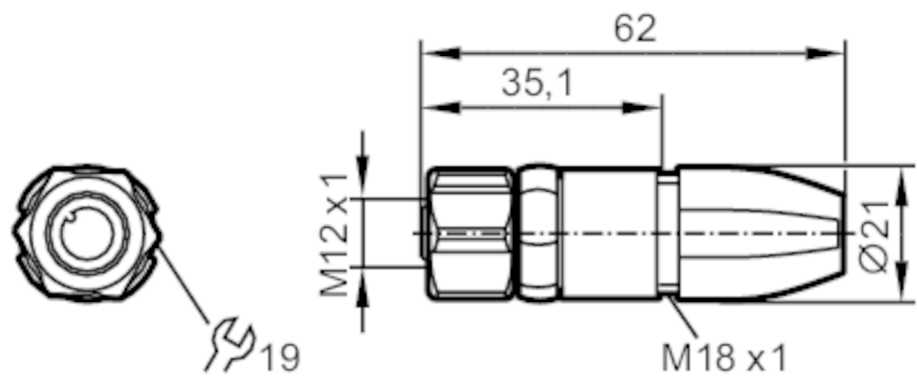

Application

Special feature	Free from silicone; Gold-plated contacts
Application	hygienic and wet areas in the food industry
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Protection class		II
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...100
Storage temperature	[°C]	-25...55
Storage humidity	[%]	10...100
Other climatic conditions for storage according to stated class		1K22/ DIN 60721-3-1
Protection		IP 65; IP 67; IP 68; IP 69K

Mechanical data

Weight	[g]	40.1
Moulded-body material		PA 6.6
Material nut		stainless steel (316L/1.4404)
Sealing material		EPDM

Remarks

Pack quantity		1 pcs.
---------------	--	--------

EVF565



Wirable socket

SDOGH040VASFKPG

Electrical connection


screw terminals: 0.25...1 mm²; Cable sheath: Ø 3.5...6 mm; AWG 23...17

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6, grey; Locking: stainless steel (316L/1.4404); Sealing: EPDM; Contacts: gold-plated; Tightening torque: 0.6...1.2 Nm; Take into account the maximum value of the counterpart!



Connection

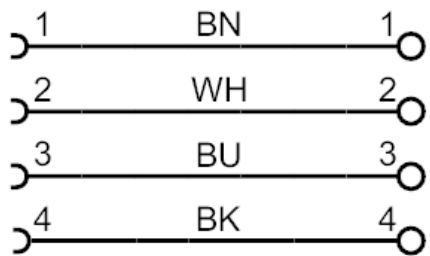

BK
BN
BU
WH

Core colours
black
brown
blue
white
colours to DIN EN 60947-5-2