


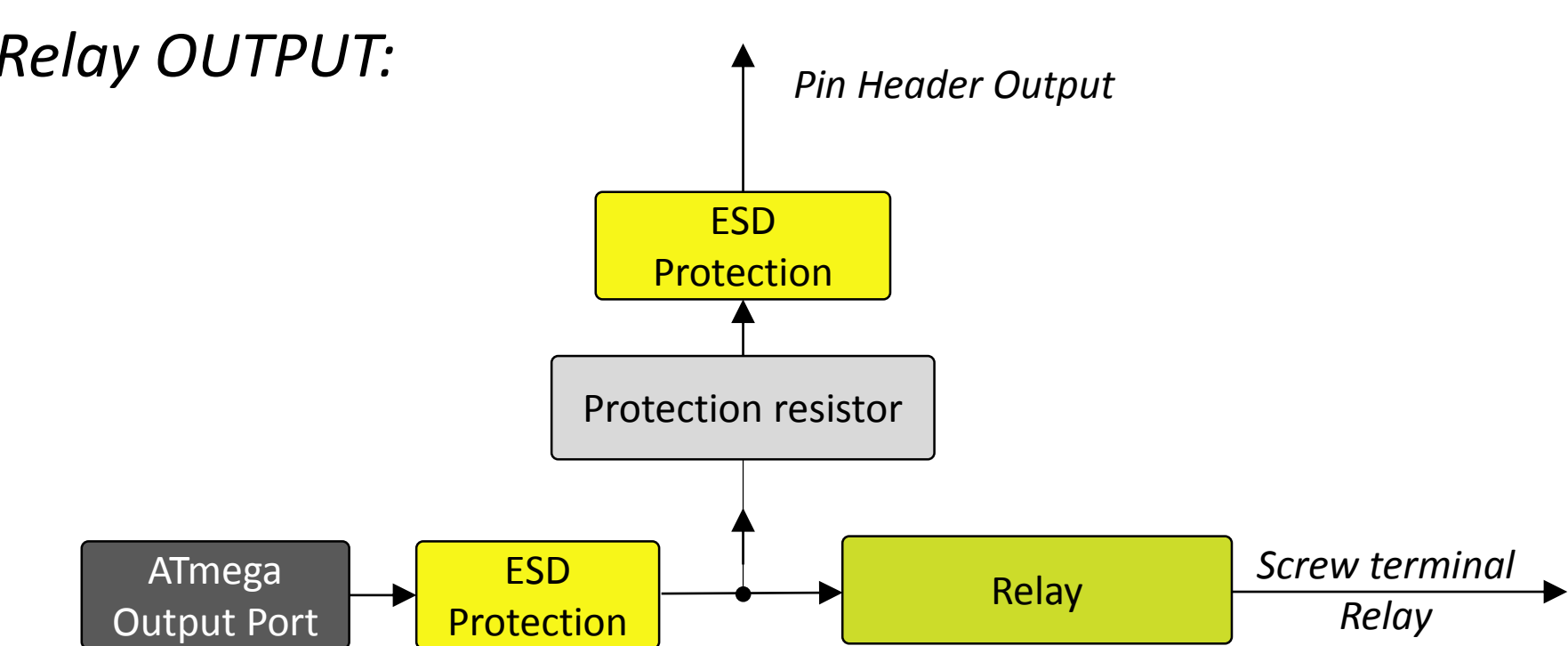
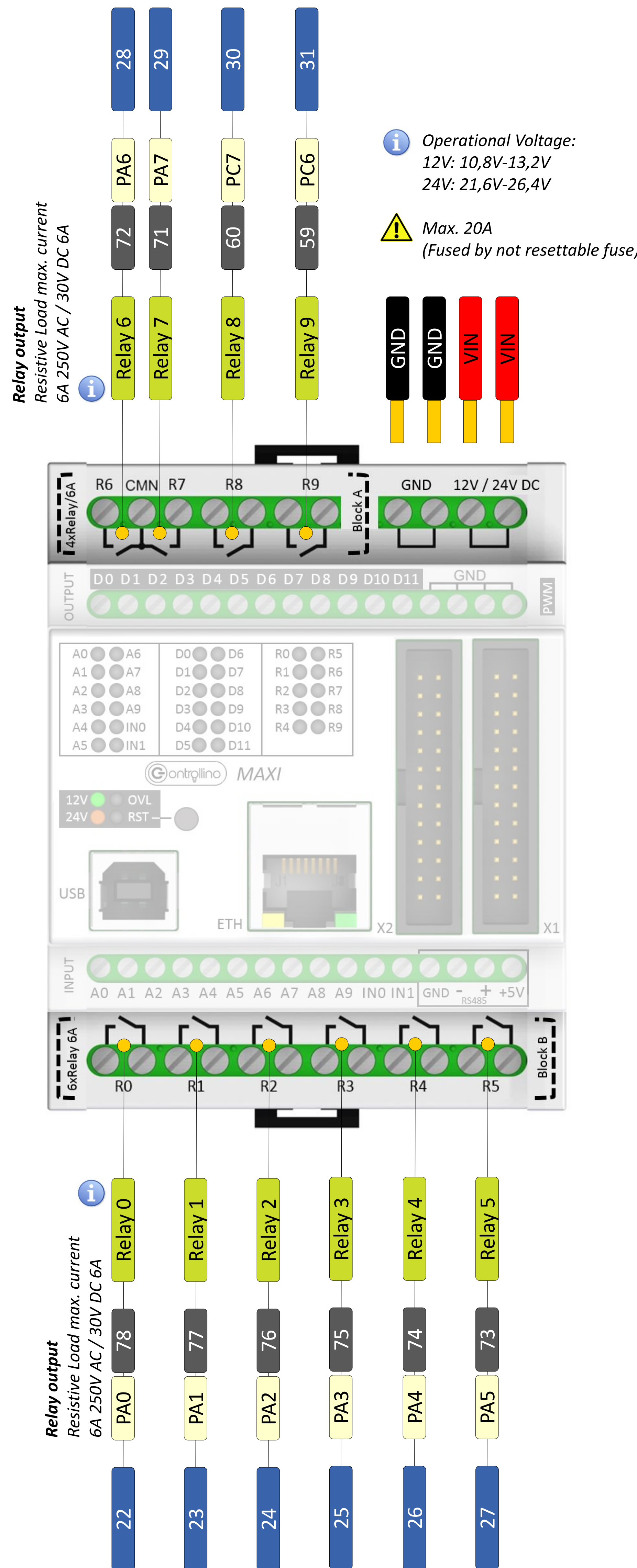


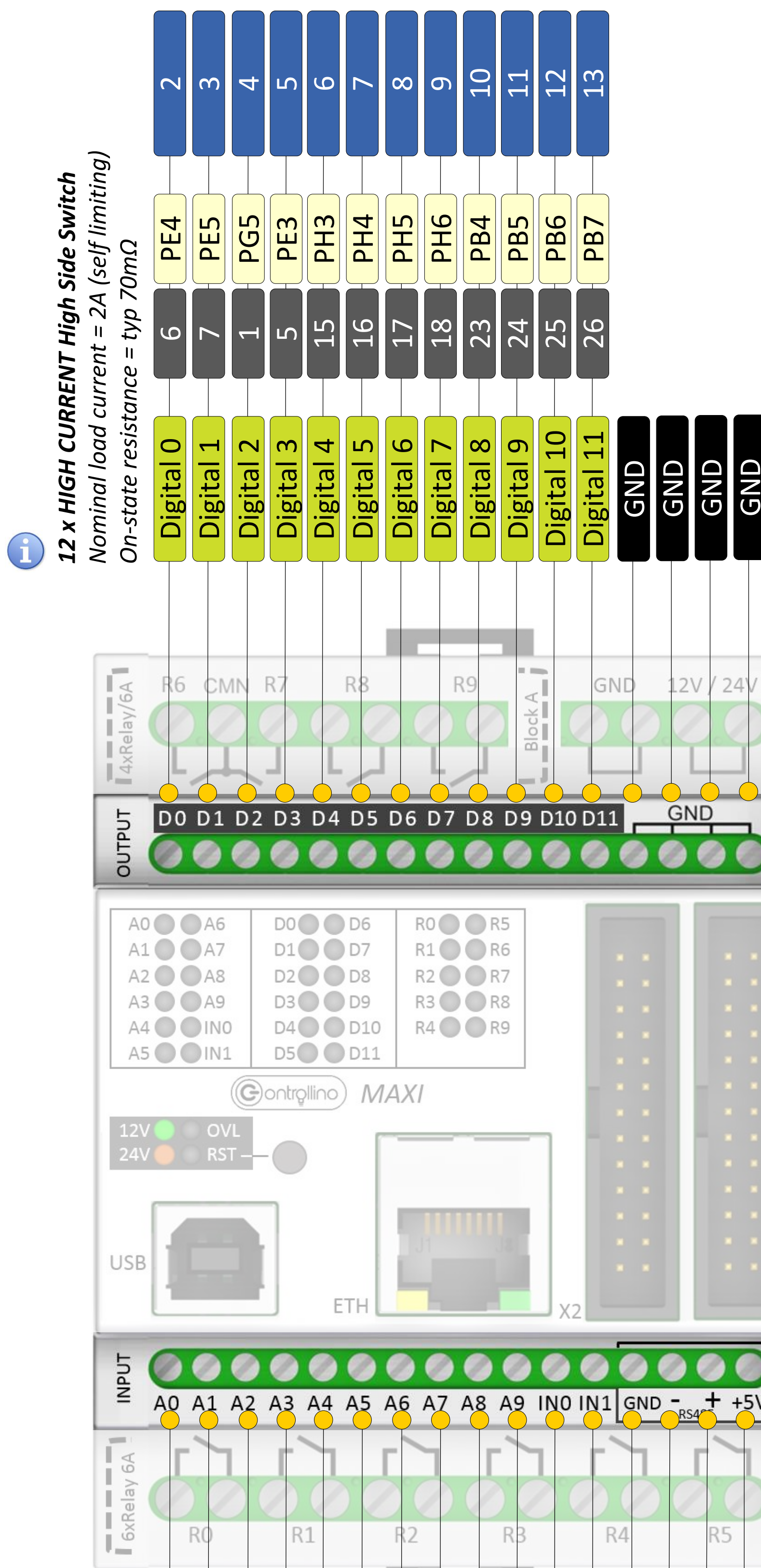

12 x HIGH CURRENT High Side Switch
Nominal load current = 2A (self limiting)
On-state resistance = typ 70mΩ

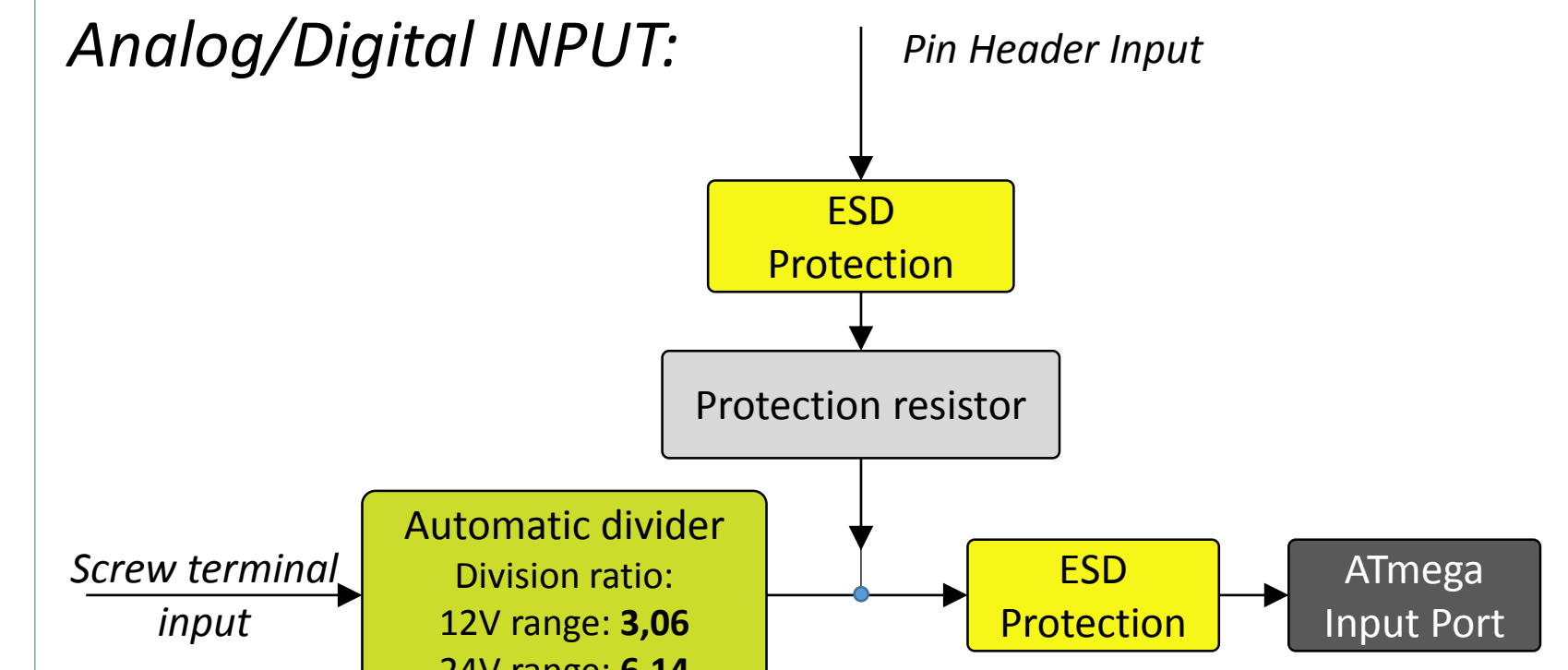

Signal Inputs
Logic "0" level: 0V – 3,6V (Vin=12V), 0V – 7,2V (Vin=24V)
Logic "1" level: 9V – 13,2V (Vin=12V), 18V – 26,4V (Vin=24V)
Maximum input current <3mA
Voltage range in case of analog input use
0 – 13,2V (Vin=12V) / 0 – 26,4V (Vin=24V)

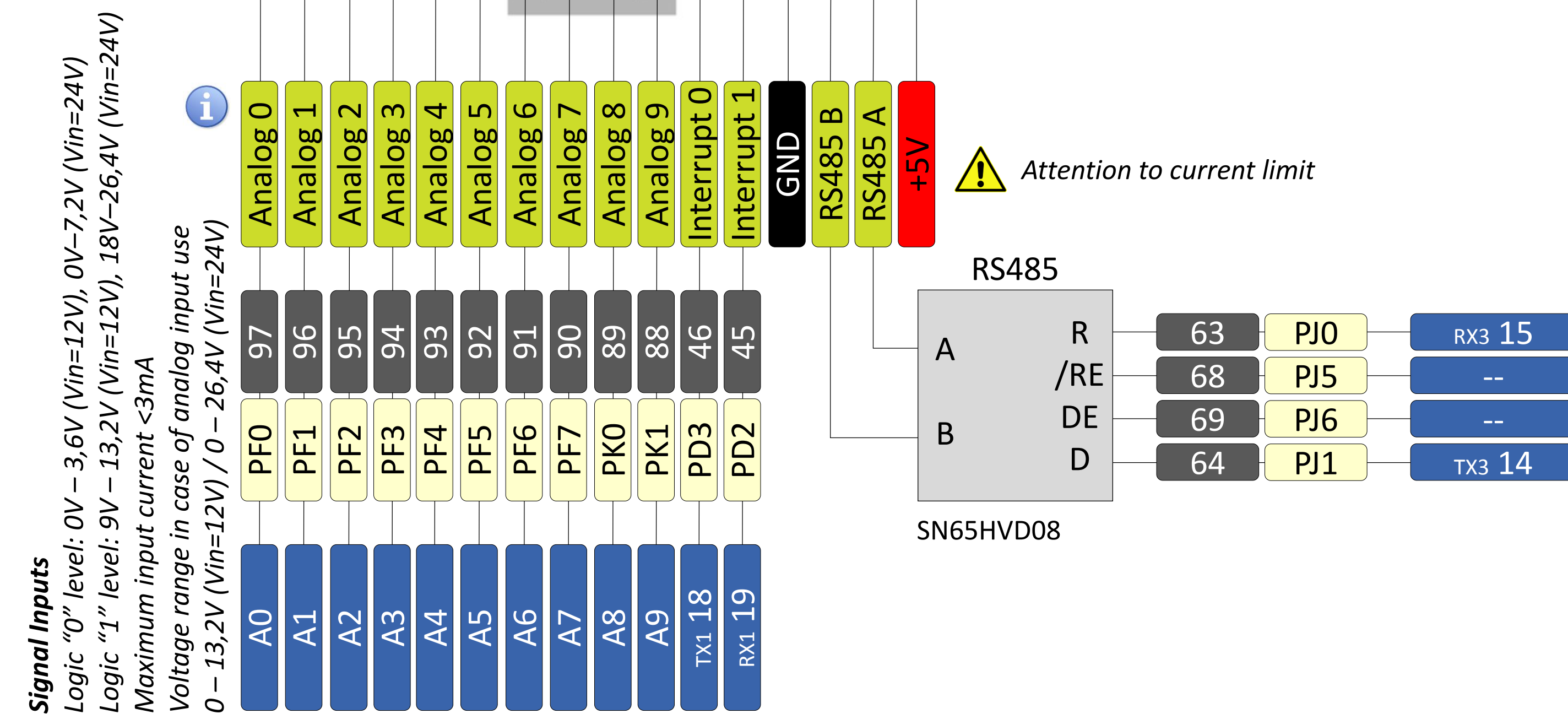

ontröllino

MAXI

PINOUT V1.1

