


PX0416/1M00 Datasheet

Product Name // Pre-Wired Flex SMB Connector 1M cable
PX0416 Series

 [View Product Page](#)

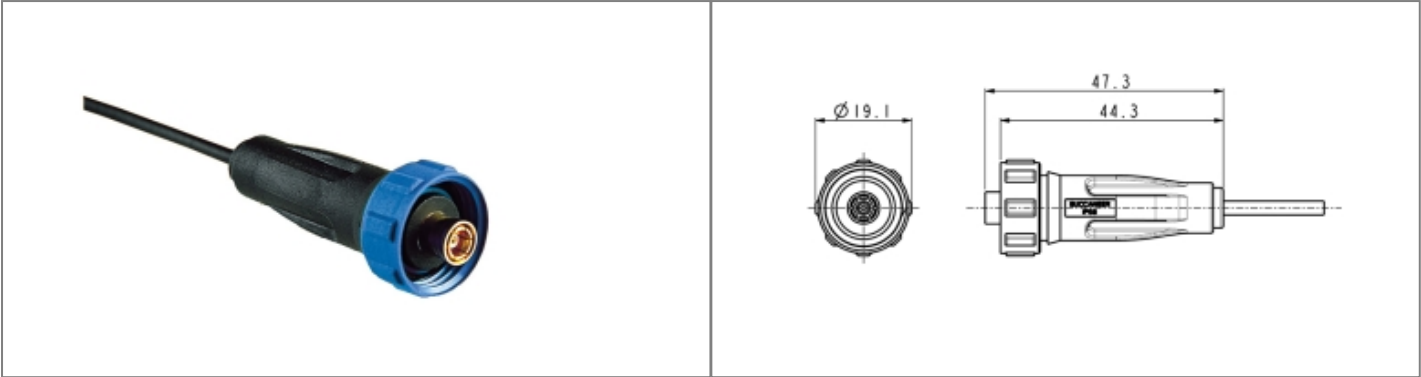

// Product Description:

- Pre-Wired Flex SMB Connectors
 - Water and dustproof to IP68 when mated with compatible connector
 - Frequency range 0-4GHz
- Overmoulded connector supplied with 50 Ohm impedance SMB plug terminated with RG-174 cable in a choice of lengths depending on part code
 - PX0485 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with PX0414 Panel Connector

// General Information:

Product Display Title:	Pre-Wired Flex SMB Connectors
Product Family:	Circular Data Connectors
Product Series:	400 Series - SMB Buccaneer
Change Notes:	PRODUCT-MOQ-ADJUSTMENT
Approvals:	CSA, UL, VDE
Body Material:	PVC
Cable Length:	1m
Contact Type:	Plug Contact
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	19.1mm
Flamability Rating:	UL94V-0
Function:	Flex Connector Single Ended Cable
Ip Rating:	IP68, IP69K
Max Operating Temperature:	+80°C
Min Operating Temperature:	-40°C
Number Of Contacts:	1 Contact

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)