


PX0837/3M00 Datasheet

Product Name // Overmould Flex Connector PX0837 Series
Pre-Wired Patch Cord IP68 RJ45 to Shielded RJ45 3M Cable

 [View Product Page](#)

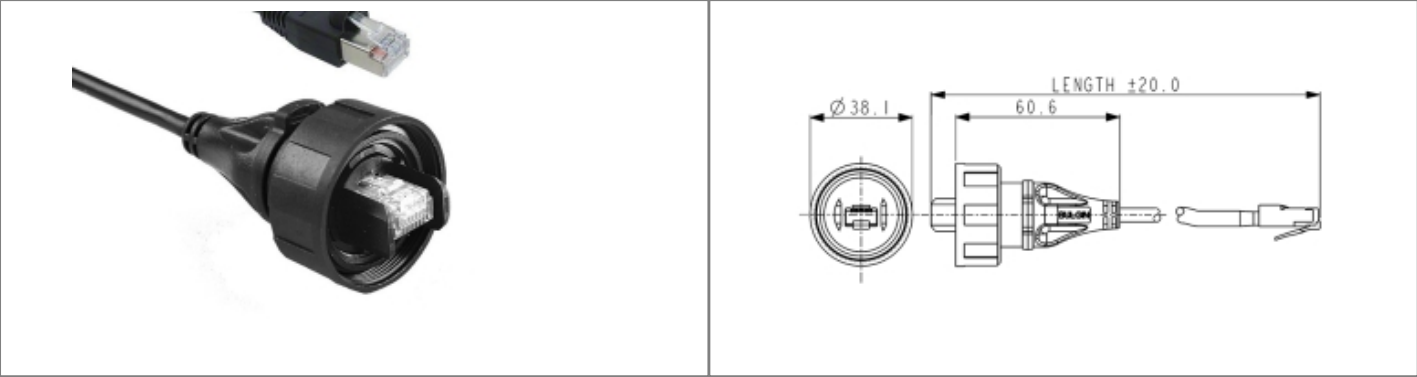

// Product Description:

- ⬢ Cat 5e and Cat 6a Options
 - ⬢ Pre-Wired Patch Cord with overmoulded connector(s)
 - ⬢ Water and dustproof to IP68 when mated with compatible connector
 - ⬢ Supplied with shielded RJ45 plug
 - ⬢ S-FTP cable construction
 - ⬢ PUR jacket cable in a choice of lengths depending on part code suffix
- ⬢ Choice of:
 - ⬢ IP68 RJ45 to bare end (part codes prefixed PX0836, PX0896)
 - ⬢ IP68 RJ45 to Shielded RJ45 (part codes prefixed PX0837, PX0897)
 - ⬢ IP68 RJ45 to IP68 RJ45 (part codes prefixed PX0838, PX0898)
 - ⬢ PX0835 Sealing Cap available separately to maintain IP rating of unmated connectors
 - ⬢ Mate with all PX08 Standard Series RJ45 Panel Mount Connectors

// General Information:

Product Display Title:	Cat 5e and Cat 6a Options
Product Family:	Circular Data Connectors
Product Series:	Standard Buccaneer - Ethernet
Change Notes:	PRODUCT-MOQ-ADJUSTMENT
Body Material:	PVC
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	1.5A
Data Cable Type:	IP68 RJ45 to Shielded RJ45
Diameter Over Coupling Ring Mm:	38.1mm
Flamability Rating:	UL94V-0
Function:	Flex to Standard Connector Double Ended Cable
Ip Rating:	IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	-20°C
Number Of Contacts:	8 Contacts
Rohs Compliant:	Yes
Voltage Max:	42V

// Product PDF Links



// Product 3D CAD Model Links

