


PX0840/B/3M00 Datasheet

Product Name // Overmoulded USB 2.0 Cable PX0840
Series USB Standard A Plug to Sealed B Plug 3m Cable

 [View Product Page](#)

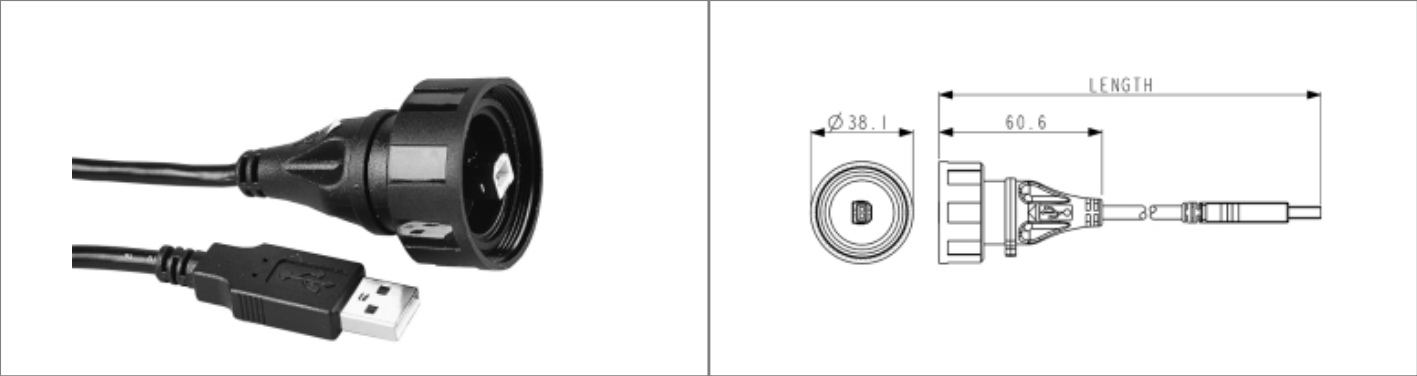

// Product Description:	
- Pre-Wired Overmoulded USB 2.0 Cable - Water and dustproof to IP68 when mated with compatible connector - Standard USB 2.0 Type A plug to Sealed Standard USB 2.0 Type B plug	3m Cable Length - PX0835 Sealing Cap available separately to maintain IP rating of unmated connectors - Mate with PX08 Standard USB 2.0 Series Panel Mount Connectors

// General Information:	
Product Display Title: Product Family: Product Series: Change Notes: Approvals: Body Colour: Body Material: Cable Length: Contact Type: Coupling Type: Current Max: Data Cable Type: Diameter Over Coupling Ring Mm: Flamability Rating: Function: Ip Rating: Max Operating Temperature: Min Operating Temperature: Number Of Contacts: Rohs Compliant: Voltage Max:	Pre-Wired Overmoulded USB 2.0 Cable Circular Data Connectors Standard Buccaneer - USB PRODUCT-MOQ-ADJUSTMENT CSA, UL, VDE Black PVC 3m Plug Contact Screw 1A USB 2.0 Standard A Plug to Sealed B Plug 38.1mm UL94V-0 Flex to Standard Connector Double Ended Cable IP68, IP69K +70°C 0°C 4 Contacts Yes 5V

// Product PDF Links

 [Standard Series USB connectors...](#)

// Product 3D CAD Model Links

 [PX0840/B/3M003D CAD Model](#)