


PXP4040/B/2M00 Datasheet

 [View Product Page](#)

Product Name // Fully Overmoulded USB Cable PXP4040
Series USB Standard A Plug To Sealed Micro B Plug 2M
Cable

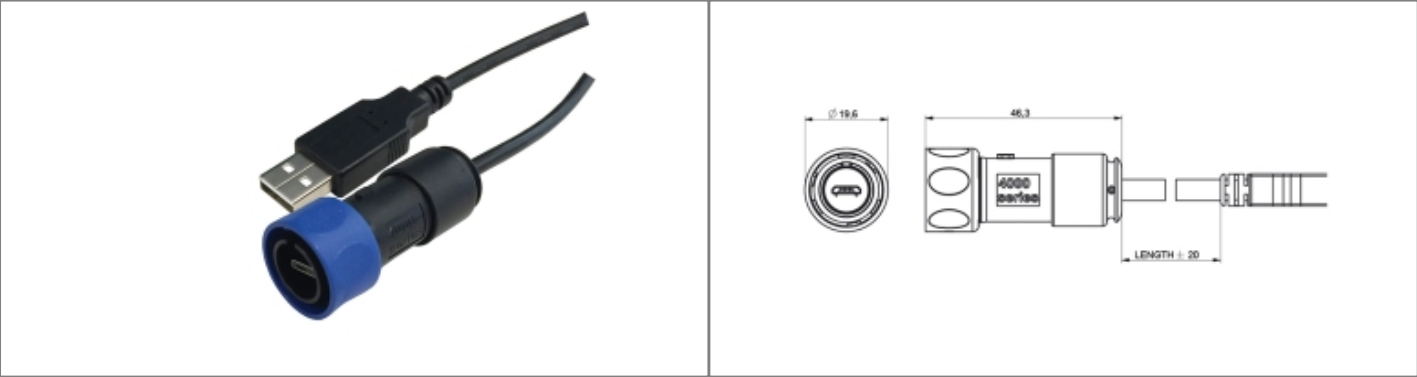

// **Product Description:**

- Pre-Wired Fully Overmoulded USB V2.0 Cable
 - Sealed to IP66, IP68, IP69K when mated with compatible connector
 - Standard USB Type A plug to Sealed Micro USB Type B plug
- Choice of cable lengths depending on part code
 - PXP4081 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with PXP4043 Rear Panel Mount Connector

// **General Information:**

Product Display Title:	Pre-Wired Fully Overmoulded USB V2.0 Cable
Product Family:	Circular Data Connectors
Product Series:	4000 Series - Micro USB Buccaneer
Body Material:	PVC
Cable Length:	2m
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	1A
Data Cable Type:	USB Standard A Plug To Sealed Micro B Plug
Diameter Over Coupling Ring Mm:	19.7mm
Flamability Rating:	UL94V-0
Function:	Flex to Standard Connector Double Ended Cable
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	0°C
Number Of Contacts:	5 Contacts
Voltage Max:	42V

// **Product PDF Links**



// **Product 3D CAD Model Links**



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)