


PXP4040/B/3M00 Datasheet

Product Name // Fully Overmoulded USB Cable PXP4040
Series USB Standard A Plug To Sealed Micro B Plug 3M
Cable

 [View Product Page](#)

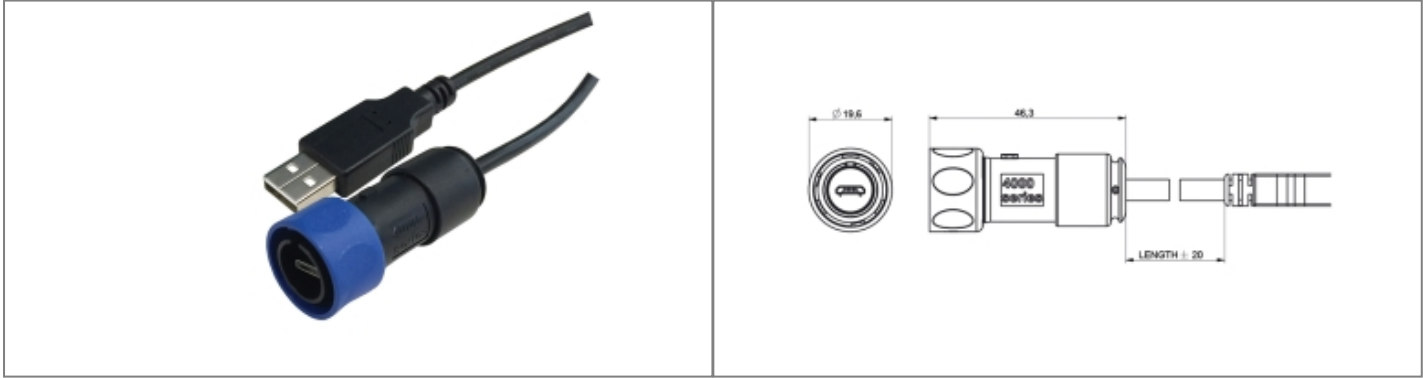

// Product Description:

- Pre-Wired Fully Overmoulded USB V2.0 Cable
 - Sealed to IP66, IP68, IP69K when mated with compatible connector
 - Standard USB Type A plug to Sealed Micro USB Type B plug
- Choice of cable lengths depending on part code
 - PXP4081 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with PXP4043 Rear Panel Mount Connector

// General Information:

Product Display Title:	Pre-Wired Fully Overmoulded USB V2.0 Cable
Product Family:	Circular Data Connectors
Product Series:	4000 Series - Micro USB Buccaneer
Body Material:	PVC
Contact Type:	Plug Contact
Coupling Type:	Screw
Current Max:	1A
Data Cable Type:	USB Standard A Plug To Sealed Micro B Plug
Diameter Over Coupling Ring Mm:	19.7mm
Flamability Rating:	UL94V-0
Function:	Flex to Standard Connector Double Ended Cable
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	0°C
Number Of Contacts:	5 Contacts
Voltage Max:	42V

// Product PDF Links

 [4000 Series USB data connectors...](#)

// Product 3D CAD Model Links

 [PXP4040/B/3M003D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)