



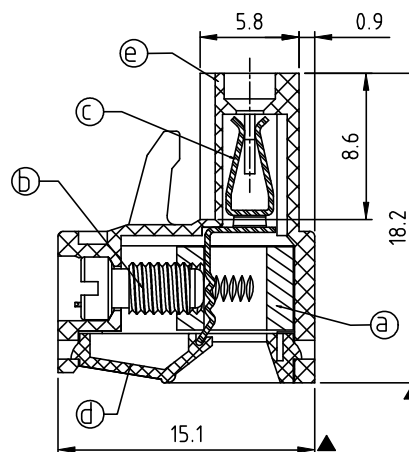

SECTION P-P

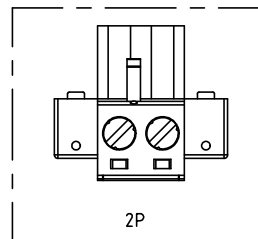

Dim L	N×5.08	Poles	Tolerance Dim L/B/C/D
Dim B	(N-1)×5.08	2P-7P	±0.15
Dim C	(N+2)×5.08	8P-12P	±0.25
Dim D	(N+1)×5.08	13P-18P	±0.30
N= Number of poles		19P-24P	±0.40

N= Number of poles

Material

- Item **(a)** Clamp: Brass(CuZn) Ni plated
 - Item **(b)** Terminal screw: Steel Zinc plating “-” slot type
 - Item **(c)** Female contact: PhBz ,Bright Tin plated over Nickel plated
 - Item **(d)** Terminal Cover: Thermoplastic (UL94V-0)
 - Item **(e)** Terminal housing: Thermoplastic (UL94V-0)
 - Item **(f)** With flange screw: Steel Zinc plating M2.5“+/-” slot type
- Electrical cULus/VDE/TUV
- Voltage rating: 300VAC/300VAC/300VAC
 - Current rating: 12A/20A/20A
 - Wire range: 2.5mm²/0.34-2.5mm²
 - Solid wire(AWG): 12-24
 - Stranded wire(AWG): 12-24
 - Torque: 5Lb-In/0.5Nm/0.56Nm
 - Screw: M3
 - Wire strip length: 7-8mm
 - Withstanding Voltage: 1.6KV/2.5KV/2.5KV
 - Operating temperature: -40°C to +115°C
 - Safety Approval: cULus  
 - Use with OQ10.1x10mm square pin, Withdrawal force:200 - 500gf /pole
 - Critical dimension: 

TJ xx 51x 2 xxxx G

No. OF POLES

02: 2 POLES

24: 24 POLES

Color

S 0 Black (RAL9005)
2 Red (RAL3001/D)
3 Orange(RAL2011/P)
4 Yellow(RAL1018/A)
5 Green(RAL6018/T)
6 Blue (RAL5015/A)
8 Grey(RAL7035/D)
9 White(RAL1102)
C Green(RAL6018/U)

→ G RoHS compliant
(lead<4%)
In copper Alloy

▶ 000 0 Standard @ Logo
 000 A Standard ANY Logo
 0091 Standard ANY Logo
 Any special item by
 customer request,
 please contact sales
 department.

Amphenol **ANYTEK**

CUSTOMER COPY

ALL RIGHTS RESERVED. REPRODUCTION OR ISSUE TO THIRD PARTIES IN ANY FORM WHATEVER IS NOT PERMITTED WITHOUT WRITTEN AUTHORITY FROM THE PROPRIETOR. PROPERTY OF ANYTEK TECHNOLOGY CO., LTD

TITLE	TJ-5.08 mm Series 2P-24P (With flange)						
PART NO.	TJxx51x2xxxxG			DWG NO.	8TJ0009		
APPROVED	CHECKED	DESIGNED	DRAWN	CUST NO.			Tolerance
		Chen Bo 04/12-21	Chen Bo 04/12-21		UNIT: mm/in		X. ±0.50
					SCALE: NONE		X.X ±0.30
					REV: H		X.XX ±0.10
				SHEET: 01/01			X° ±1°