

55501850	DATA SHEET	
Valid from: 06.06.2023	SILVYN® SSVZ-M	

By the SILVYN® SSVZ-M bargain it a conduit clamp gland which is made of nickel-plated brass, with cable strain relief and cable sealing. By the special bosh lugs is a simply assembling and strain relief of the conduit warranted.

For a additional protection the conduit can combined with a clamp SILVYN® SCH. The cable gets clamped by the incised sealing ring.



Material:

Body

Brass, nickel plated

Special ribs

Brass, nickel plated

Flat washer

Steel, nickel plated

Incised Sealing Ring

CR

O-Ring

NBR

Technical Features:

Connecting thread

M16x1,5 up to M63x1,5 acc. to EN 60423

Conduit wide

10x14 mm up to 50x56 mm

Protection class

IP54 up to IP68 acc. to EN 60529

Temperature range

Depending on the used conduit

-20°C up to +80°C

Reference standards:



EN 61386-1

Suitable conduits:

SILVYN® SI

SILVYN® SP


SILVYN® SP-PU

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Creator: FICE1/PDP Released: VACH1/PDP	Document: DB55501850EN Version: 04	Page 1 of 2
---	---------------------------------------	-------------

55501850	DATA SHEET	
Valid from: 06.06.2023	SILVYN® SSVZ-M	

Product drawing:

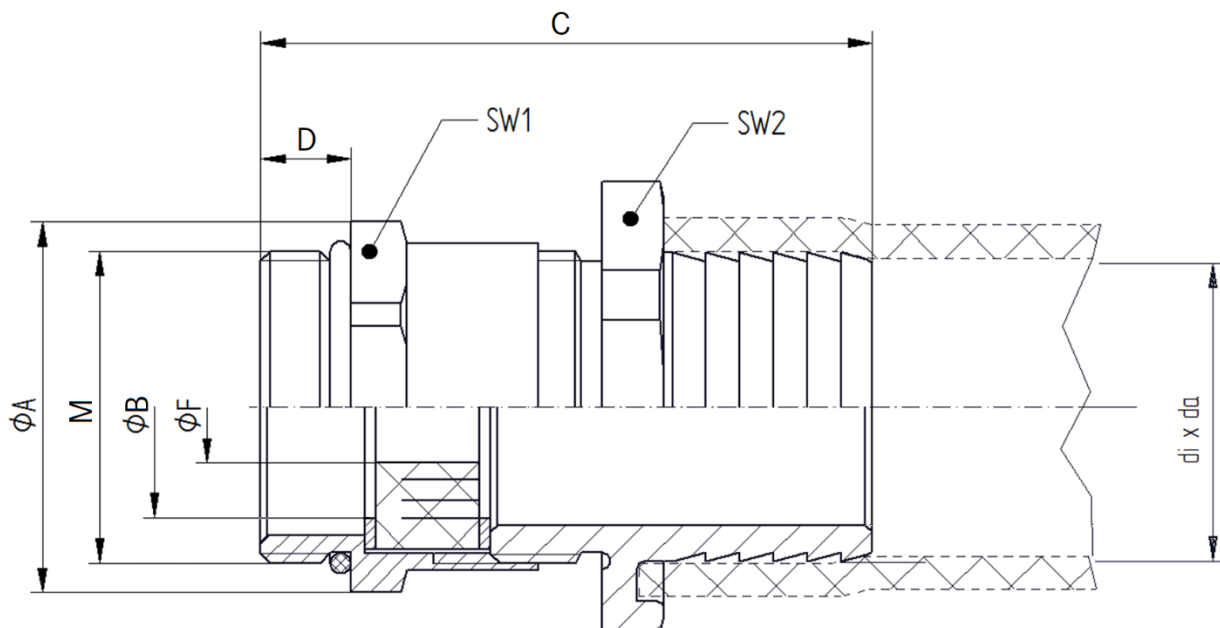

Dimension table:

Article No.	di x da	M	D [mm]	C [mm]	ØF [mm] Incised sealing ring	ØB [mm]	ØA [mm]	SW1	SW 2
55501850	10 x 14	M16x1,5	5,0	39,0	5 / 8	8	20,0	18	19
55501860	12 x 16	M16x1,5	5,0	39,0	5 / 8	10	22,2	18	19
55501870	14 x 18	M20x1,5	6,0	39,6	7 / 10 / 12,5	12	24,0	22	22
55501880	16 x 20	M20x1,5	6,0	39,6	7 / 10 / 12,5	12	24,0	22	22
55501890	18 x 23	M20x1,5	6,0	43,0	7 / 10,5 / 13 / 16	14	24,0	22	25
55501900	22 x 27	M20x1,5	6,0	44,0	8 / 10,5 / 13,5 / 16	15	26,2	24	30
55501910	23 x 28	M25x1,5	7,0	48,0	11 / 15 / 18 / 20	20	33,0	30	32
55501920	30 x 36	M32x1,5	8,0	53,6	18 / 23 / 27 / 31	27	42,5	40	40
55501930	32 x 38	M32x1,5	8,0	53,6	18 / 23 / 27 / 31	27	42,5	40	40
55501940	38 x 44	M40x1,5	8,0	61,6	24 / 28 / 31 / 35	34	54,0	50	52
55501950	45 x 51	M50x1,5	9,0	68,6	30 / 35,5 / 39 / 42,5	41	60,0	57	57
55501960	50 x 56	M63x1,5	10,0	71,6	36 / 40 / 44 / 47	46	70,0	66	66

Creator: FICE1/PDP Released: VACH1/PDP	Document: DB55501850EN Version: 04	Page 2 of 2
---	---------------------------------------	-------------