


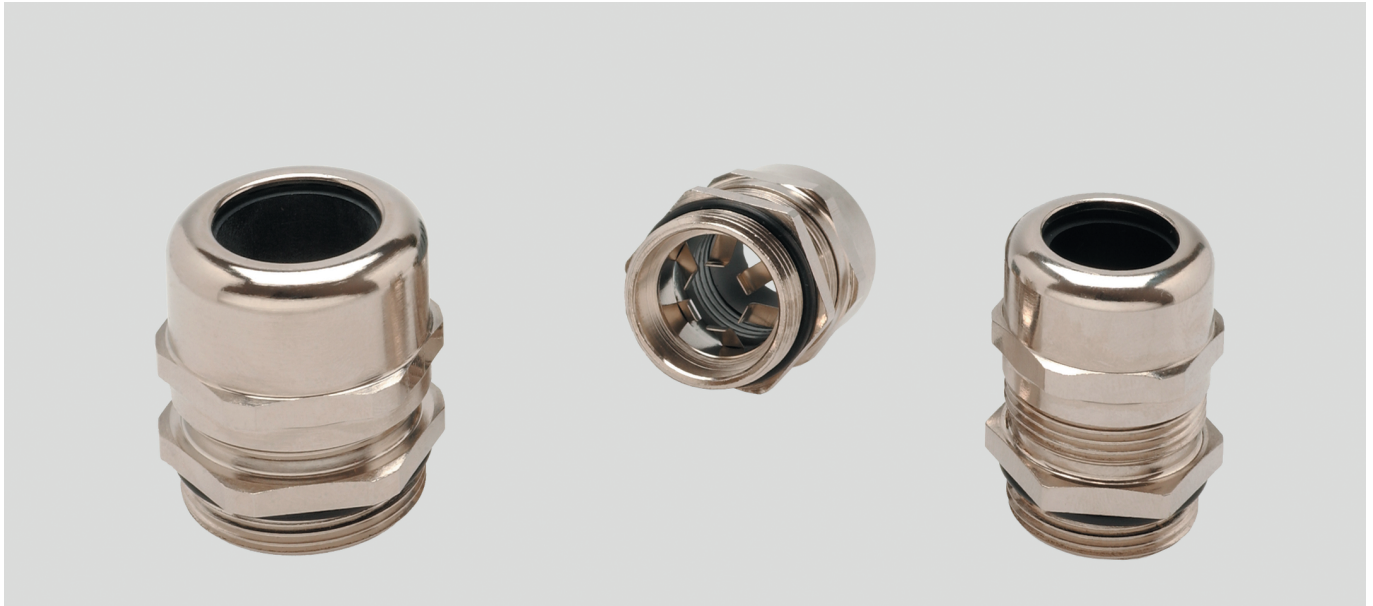

HELUTOP® MS-E

EMC cable gland with clamping fingers from spring steel for quick assembly and contacting.

Material

Brass, nickel plated
Contact system: Copper-Beryllium
Clamp: Polyamide PA 6
Seal: Chloroprene-rubber (CR)
O-ring: NBR


Note

Details on the individual tests appear in section "Technical Information".

Technical data

Protection class: IP 68 - 5 bar

Temperature range: -40°C up to +100°C

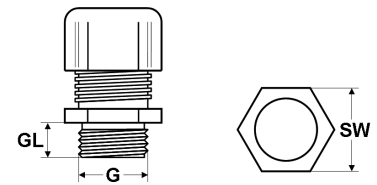

Dimensions

G Thread size
GL Thread length
SW Spanner size

PG thread

Part no.	Size PG	Cable Ø from / to mm	Thread length mm	Spanner size mm	Unit	Net EUR/ 100 items at a purchase of		
						up to 100	101 - 500	501 - 1000
90770	7	3,0 - 6,5	6,0	14	50	o. r.	o. r.	o. r.
90771	9	4,0 - 8,0	6,0	17	50	o. r.	o. r.	o. r.
90772	11	5,0 - 10,0	6,0	20	50	o. r.	o. r.	o. r.
90773	13,5	6,0 - 12,0	6,5	22	50	o. r.	o. r.	o. r.
90774	16	10,0 - 14,0	6,5	24	25	o. r.	o. r.	o. r.
90775	21	13,0 - 18,0	7,2	30	25	o. r.	o. r.	o. r.
90776	29	18,0 - 25,0	8,0	40	20	o. r.	o. r.	o. r.
90777	36	22,0 - 32,0	9,0	50	5	o. r.	o. r.	o. r.
90778	42	30,0 - 38,0	12,0	58	5	o. r.	o. r.	o. r.
90779	48	34,0 - 44,0	14,0	64	5	o. r.	o. r.	o. r.

NPT thread

Part no.	Size NPT	Cable Ø from / to mm	Thread length mm	Spanner size mm	Unit	Net EUR/ 100 items at a purchase of		
						up to 100	101 - 500	501 - 1000
99808	3/8"	5,0 - 10,0	11,5	20	50	o. r.	o. r.	o. r.
99809	1/2"	6,0 - 12,0	13,0	22	50	o. r.	o. r.	o. r.
99810	3/4"	13,0 - 18,0	13,0	30	25	o. r.	o. r.	o. r.
99811	1"	18,0 - 25,0	13,0	40	10	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request