

# DIGITUS Lightning silicone connection cable, USB-C - Lightning, 1m, white

AK-600110-010-W  
EAN 4016032495970



## USB Silicone charging cable, USB-C - Lightning 1m, USB 2.0, 60W, white

Reliable and easy connection to your USB-C devices with your PC thanks to the soft and flexible silicone cable. Data transfer rate of 480 Mbits/s for synchronization, data transfer and a power delivery specification of 60W for charging.

### Fast charging and synchronization with the high-quality and soft silicone connection cable


- Supports data transfer rates of 480 Mbit/s
- Backwards compatible with USB 2.0 and USB 1.1
- Supports the USB power delivery function with 20V, 3A and 60W



- Durable cable with a service life of up to 25,000 bends (based on internal tests)
- Type C plug can be used on both sides
- MFI-certified
- AWG: 22
- Color cable: white
- Connector 1: Apple Lightning 8-pin, plug
- Connector 2: USB C, plug
- Connector surface: nickel-plated
- Hoods: molded
- Wire material: CU
- Length: 1 m
- Shielding: single shielding

## Logistics

|                              | Number (pcs) | Weight (kg) | Depth (cm) | Width (cm) | Height (cm) | cm³       |
|------------------------------|--------------|-------------|------------|------------|-------------|-----------|
| Packaging Unit Carton        | 200          | 7.90        | 21.00      | 32.00      | 50.00       | 33,600.00 |
| Packaging Unit Inside        | 10           | 0.40        | 3.60       | 24.00      | 30.00       | 2,592.00  |
| Packaging Unit Single        | 1            | 0.04        | 1.00       | 21.00      | 11.50       | 240.29    |
| Net single without Packaging | 1            | 0.03        | 1.00       | 21.00      | 11.50       | 240.29    |

## More images:

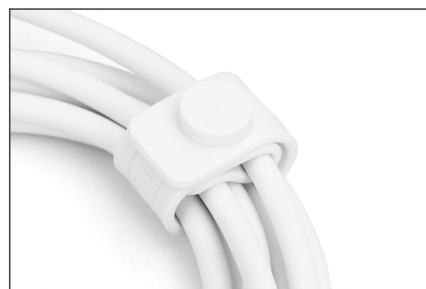

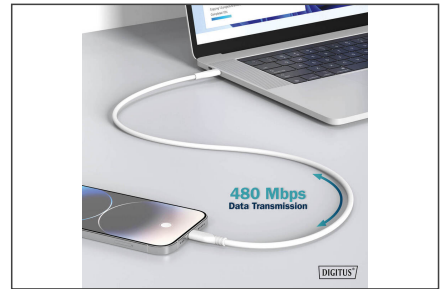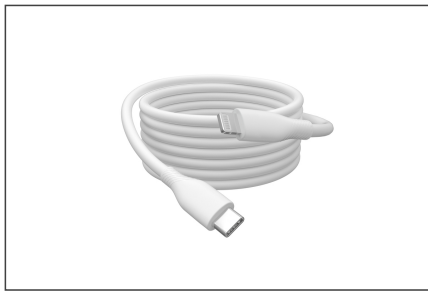

#### EU responsible person

EU based economic operator ensuring the product complies with the required regulations.

ASSMANN Electronic GmbH  
Auf dem Schöffel 3  
Lüdenscheid, Germany  
<https://www.assmann.com>  
[info@assmann.com](mailto:info@assmann.com)