 


HELUTOP® HT-PA-EX-Plus

Explosive area



HELUTOP® HT-PA-EX-Plus

For use in explosive areas.

Application

- Zone 1, Zone 2, Zone 21, Zone 22, IIA, IIB, IIC

Material

Polyamide PA 6
Seal: Chloroprene-rubber (CR)
Flat seal: Chloroprene-rubber (CR)

- phosphor-free
- silicone-free
- cadmium-free

Note

For intrinsically safe area type "i", in blue on request.

Certificate of Conformity:

IMQ 13 ATEX 010 X
IECEx IMQ 13.0003X

Approval:


EX II 2GD
Ex e IIC Gb/Ex tb IIIC Db IP 66/68

Technical data

Protection class: IP 66 / IP 68
Impact-resistant: 7 Joule

Temperature range: -40°C up to +70°C

Test standard: EN 60079-0:2012 / EN 60079-7:2007 / EN 60079-11:2012 / EN 60079-31:2014 / IEC 60079-0:2011 / IEC 60079-7:2006 / IEC 60079-11:2011 / IEC 60079-31:2013

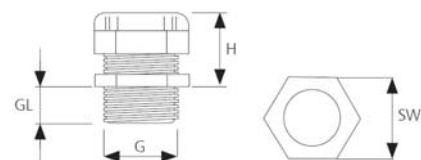

Dimensions

G Thread size
GL Thread length
H Height

Chloroprene sealing

Part no. black	Size Metr.	Cable Ø from / to mm	Thread length mm	Spanner size mm	Height mm	Unit	Net EUR/ 100 items at a purchase of		
							up to 100	101 - 500	501 - 1000
908080	M12 x 1,5	4,0 - 6,5	10,0	15	22	100	o. r.	o. r.	o. r.
908081	M12 x 1,5	4,0 - 6,5	15,0	15	22	100	o. r.	o. r.	o. r.
908082	M16 x 1,5	5,0 - 8,0	10,0	19	26	50	o. r.	o. r.	o. r.
908083	M16 x 1,5	6,0 - 10,0	10,0	22	29	50	o. r.	o. r.	o. r.
908084	M16 x 1,5	6,0 - 10,0	15,0	22	29	50	o. r.	o. r.	o. r.
908085	M20 x 1,5	6,0 - 10,0	10,0	24	29	50	o. r.	o. r.	o. r.
908086	M20 x 1,5	7,0 - 12,0	10,0	24	29	50	o. r.	o. r.	o. r.
908087	M20 x 1,5	7,0 - 12,0	15,0	24	29	50	o. r.	o. r.	o. r.
908088	M20 x 1,5	7,0 - 13,0	10,0	25	30,5	50	o. r.	o. r.	o. r.
908089	M20 x 1,5	11,0 - 14,0	10,0	27	29	50	o. r.	o. r.	o. r.
908090	M20 x 1,5	11,0 - 14,0	15,0	27	29	50	o. r.	o. r.	o. r.
908091	M25 x 1,5	11,0 - 14,0	10,0	27	29	25	o. r.	o. r.	o. r.
908092	M25 x 1,5	11,0 - 14,0	15,0	27	29	25	o. r.	o. r.	o. r.
908093	M25 x 1,5	12,0 - 17,0	15,0	29	35	25	o. r.	o. r.	o. r.
908094	M25 x 1,5	12,0 - 17,0	10,0	29	35	25	o. r.	o. r.	o. r.
908095	M25 x 1,5	14,0 - 18,0	10,0	33	37	25	o. r.	o. r.	o. r.
908096	M25 x 1,5	14,0 - 18,0	15,0	33	37	25	o. r.	o. r.	o. r.
908098	M32 x 1,5	16,0 - 21,0	10,0	36	42	20	o. r.	o. r.	o. r.
908099	M32 x 1,5	16,0 - 21,0	15,0	42	41	20	o. r.	o. r.	o. r.
908468	M32 x 1,5	19,0 - 25,0	15,0	42	40,5	20	o. r.	o. r.	o. r.
908100	M40 x 1,5	20,0 - 28,0	10,0	46	46	10	o. r.	o. r.	o. r.
908101	M40 x 1,5	20,0 - 28,0	15,0	46	46	10	o. r.	o. r.	o. r.
908102	M40 x 1,5	23,0 - 32,0	18,0	53	51,5	10	o. r.	o. r.	o. r.
908103	M50 x 1,5	31,0 - 38,0	18,0	60	53	10	o. r.	o. r.	o. r.
908104	M63 x 1,5	35,0 - 44,0	18,0	65	53,5	10	o. r.	o. r.	o. r.

Dimensions and specifications may be changed without prior notice.

o. r. = on request