

Type No. :

F12S1-□21□□D□002

RoHS
Compliant

Mark———002: Ring

□: Material / Finish

S: Stainless Steel
P: Brushed Stainless Steel

A: Aluminum
B: Dark Aluminum

□: LED Color

G: Green
R: Red
A: Amber
B: Blue
W: White


□: LED Voltage

2: 6V
3: 12V


□: Function

1: Momentary
2: Maintained

Dimensions

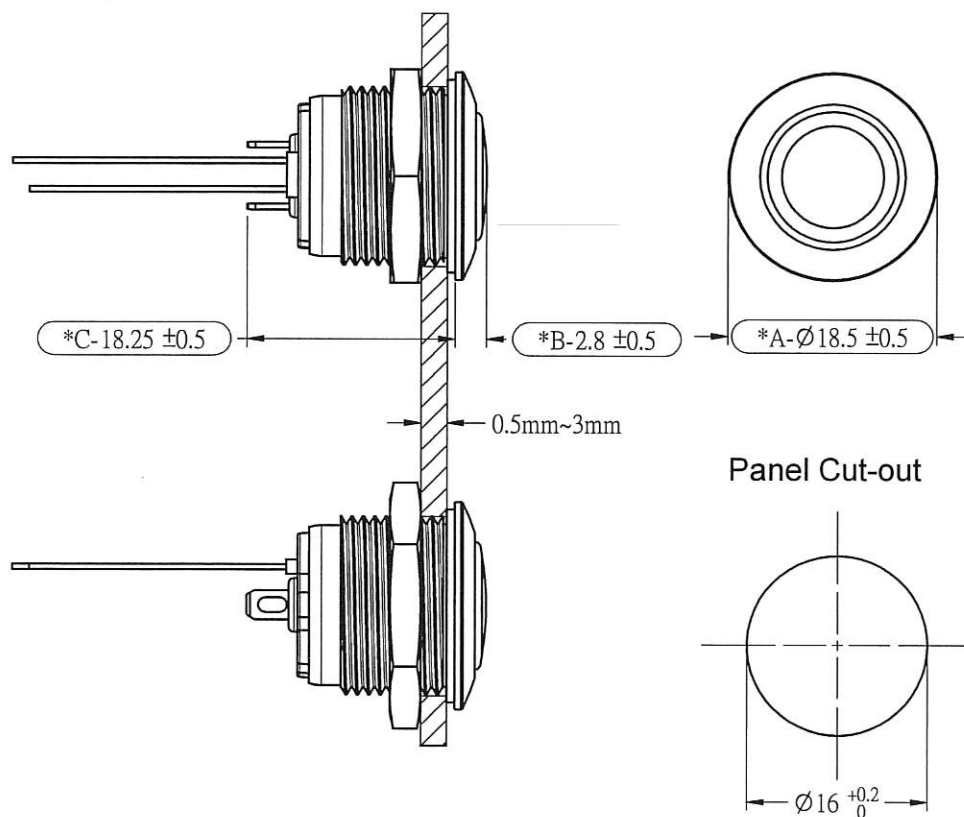

Electrical Diagram

 

Terminal : Solder
Mechanical lifetime : >50,000 operations
Electrical lifetime : >50,000 operations
Electric rating : 48V DC 100mA
Dielectric Strength : 1000V AC 60Hz 1min.
Insulation Resistance : 100MΩ
Panel thickness : 0.5mm~3mm
Degree of protection : IP67
Operating temperature : -25°C to 50°C
Contact resistance : 50mΩ (initial)



B
REV.

DECA® SwitchLab Inc.

PART NAME

UNIT

SCALE

F12S1-x21xxDx002

MM

1/1

DESIGN

CHECK

APPROVE

DRAWING NO.

SHEET

DATE

DATE

DATE

F12S1-x21xxDx002

1/1