

Type No. :

F13S1-□21□□D□001

c **AL** us RoHS
Compliant

Mark 001: Dot

□: Material / Finish

S: Stainless Steel
P: Brushed Stainless Steel

A: Aluminum
B: Dark Aluminum

□: LED Color

G: Green
R: Red
A: Amber
B: Blue
W: White

□: LED Voltage


2: 6V
3: 12V

□: Function

1: Momentary
2: Maintained

Dimensions

Electrical Diagram

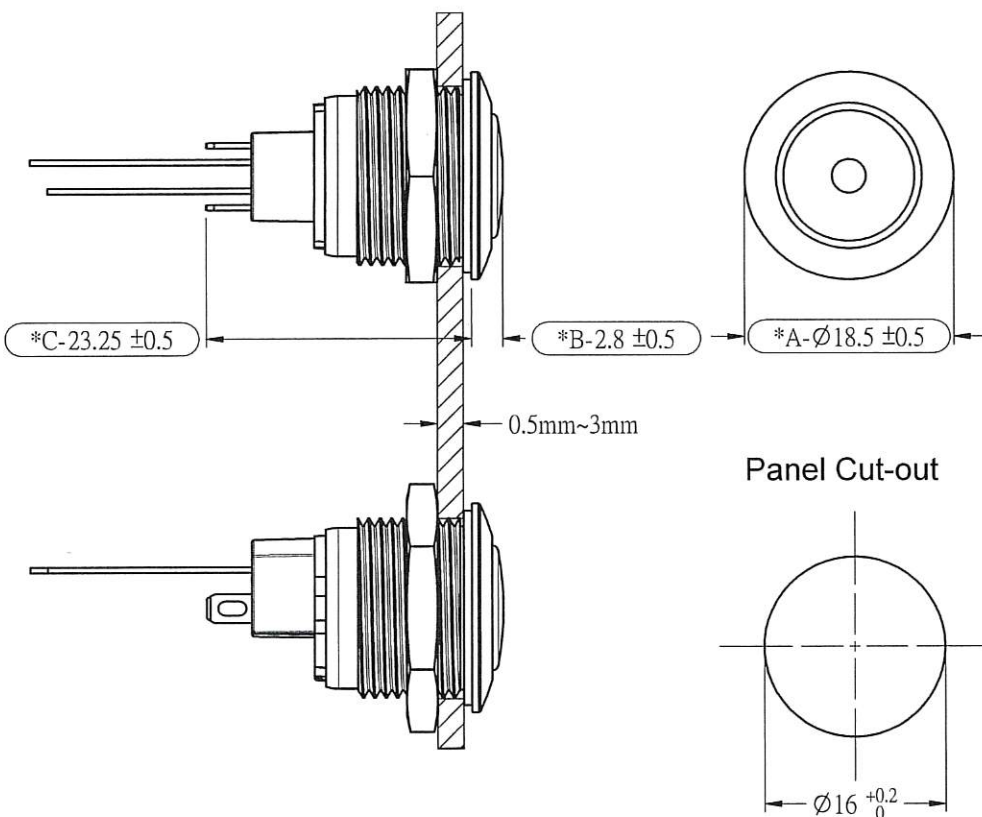

Terminal : Solder
Mechanical lifetime : >50,000 operations
Electrical lifetime : >50,000 operations
Electric rating : 48V DC 100mA
Dielectric Strength : 1000V AC 60Hz 1min.
Insulation Resistance : 100MΩ
Panel thickness : 0.5mm~3mm
Degree of protection : IP67
Operating temperature : -25°C to 50°C
Contact resistance : 50mΩ (initial)



DECA [®] SwitchLab Inc.			PART NAME	UNIT	SCALE
DESIGN: <i>[Signature]</i>			F13S1-x21xxDx001	MM	
CHECK: <i>[Signature]</i>			DRAWING NO.		SHEET
APPROVE: <i>[Signature]</i>			F13S1-x21xxDx001		1 / 1
DATE	DATE	DATE			
2018/10/19	2018/10/19	2018/10/19			