

Data Sheet

Universal Plug NG with screwed strain relief and LED 7.5 A

Art. Nr. 67762100 (BP)

Art. Nr. 67772100 (SP)

24.06.2019

Voltage range:	12 - 24 V DC
Current load:	max. 7.5 A
Connection:	screw terminals
tightening torque of the terminal screws:	25 – 35 cNm
strain relief screws:	25 – 35 cNm
Cable:	max. 2.5 mm ² , max. 7mm total Ø
Temperature range:	-25° C bis +85° C
Mating cycles:	up to 5000
LED:	green
Series resistor LED:	1.2 kΩ

Material:



Housing:	Polycarbonate
Temperature load:	Max. 135 °C
Connection spring:	Cu Fe2 P
Surface:	shiny pickled
Contact spring:	Cu Zn 37 F45
Surface:	gal. Ni 5
Plug pin:	Cu Zn 40 Pb 2
Surface:	gal. Ni 5

Universal Plug NG with screwed strain relief and LED 7.5 A

Art. Nr. 67762100 (BP)

Art. Nr. 67772100 (SP)

24.06.2019

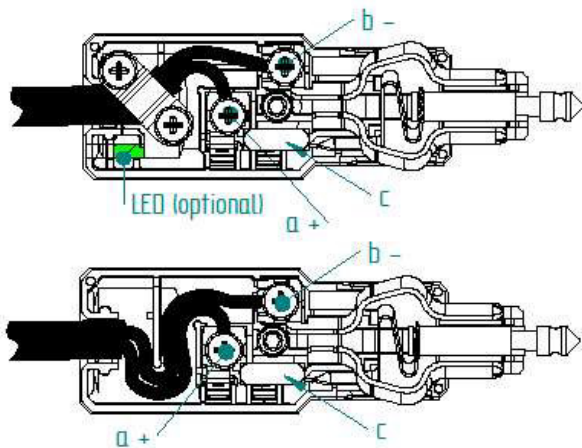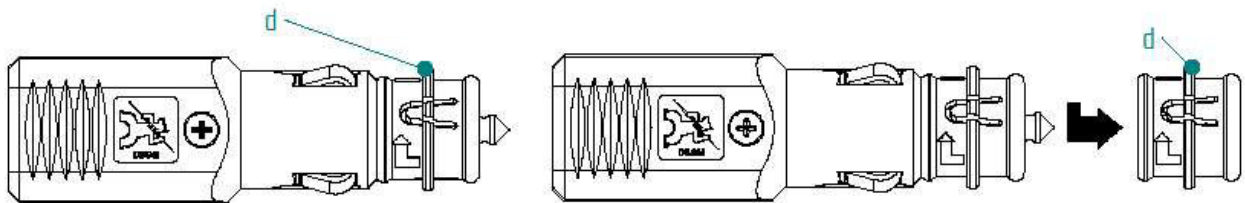

I	P _{max} [W]	
	@ 12V	@ 24V
7,5 A	90	180