


BDFL (ANL) Bolt Down Fuse

Specifications:

- Ampere: 40A to 400A
- Voltage Rating: 32/48/72Vdc
- Material: Bakelite, Copper-Alloy
- Color: Black

Dimensions:

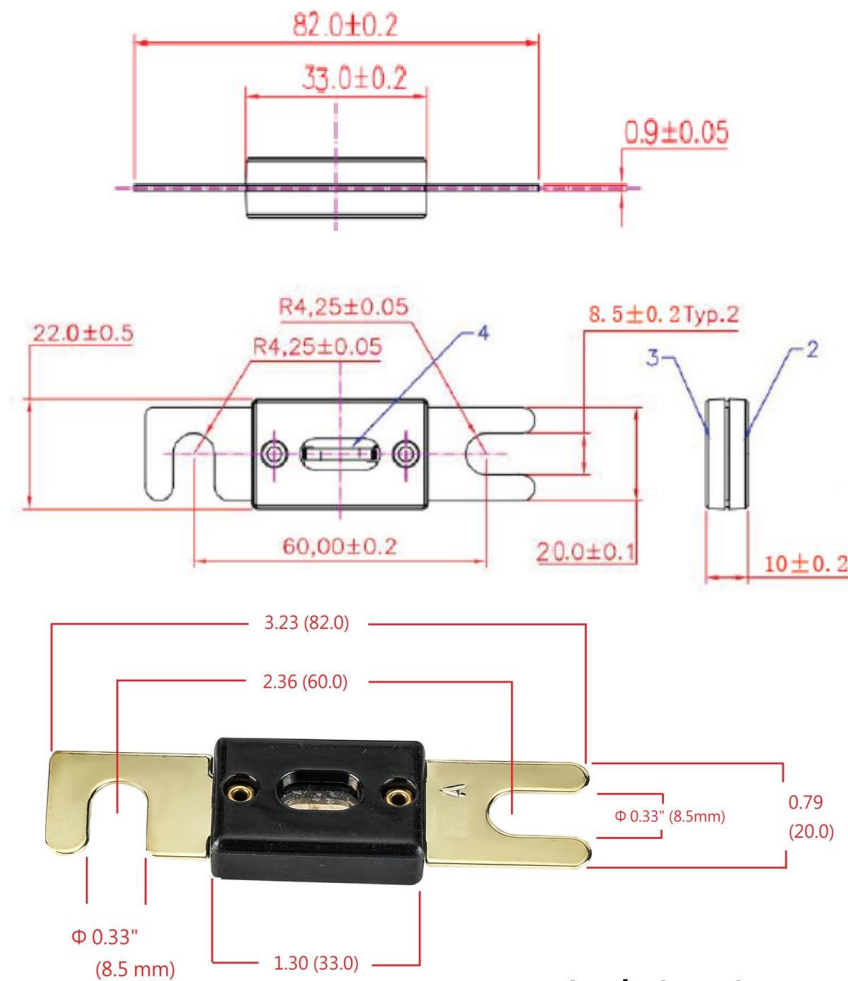

Inch (mm)

Time Current Characteristics:

% of Rating	Opening Time Min/Max (seconds)	
	40-200A	250A-400A
150%	3,600 / -	N/A
160%	N/A	60 / -
220%	- / 60	- / 60
250%	0.8 / 10	0.8 / 10
400%	0.2 / 2	0.2 / 2

Product Information:

Part Number	Voltage Rating	Rated Current
BDFL-040	32V/48V/72V	40A
BDFL-050	32V/48V/72V	50A
BDFL-060	32V/48V/72V	60A
BDFL-070	32V/48V/72V	70A
BDFL-080	32V/48V/72V	80A
BDFL-100	32V/48V/72V	100A
BDFL-125	32V/48V/72V	125A
BDFL-150	32V/48V/72V	150A
BDFL-175	32V/48V/72V	175A
BDFL-200	32V/48V/72V	200A
BDFL-250	32V/48V/72V	250A
BDFM-300	32V/48V/72V	300A
BDFM-350	32V/48V/72V	350A
BDFM-400	32V/48V/72V	400A