




尺寸 Dimensions (mm)

尺寸单位: mm, 误差 ± 0.2mm

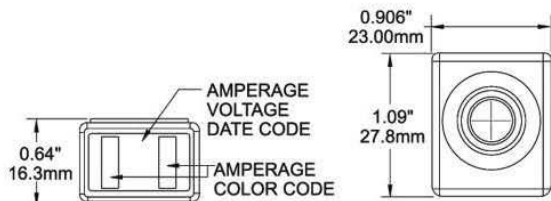

Specifications

Amperage	30A-300A
Ignition Protected ⓘ	Yes
Maximum Voltage	58V DC
Interrupt Capacity ⓘ	10000A @ 14V DC 5000A @ 32V DC 2000A @ 58V DC
Weight	0.06lb (0.03 kg)

Ignition protected (conforming to SAE J1171)-
safe for installation aboard gasoline powered boats
(30-300 Amp only)

Operating Times

Rating	100%	135%		200%		350%		600%
		min	max	min	max	min	max	
30A - 300A	> 100 hrs	-	900s	-	60s	0.1s	1s	< 0.2s



IGNITION PROTECTED BATTERY FUSE

陶瓷保險絲 Waterproof Type

目录编号Catalog No.	额定电压Voltage Rating	额定电流Ampere Rating
IPBF-30	58V	30Amp
IPBF-40	58V	40Amp
IPBF-50	58V	50Amp
IPBF-60	58V	60Amp
IPBF-75	58V	75Amp
IPBF-80	58V	80Amp
IPBF-90	58V	90Amp
IPBF-100	58V	100Amp
IPBF-125	58V	125Amp
IPBF-150	58V	150Amp
IPBF-175	58V	175Amp
IPBF-200	58V	200Amp
IPBF-250	58V	250Amp
IPBF-300	58V	300Amp



Temperature Derating / Time Current Curves

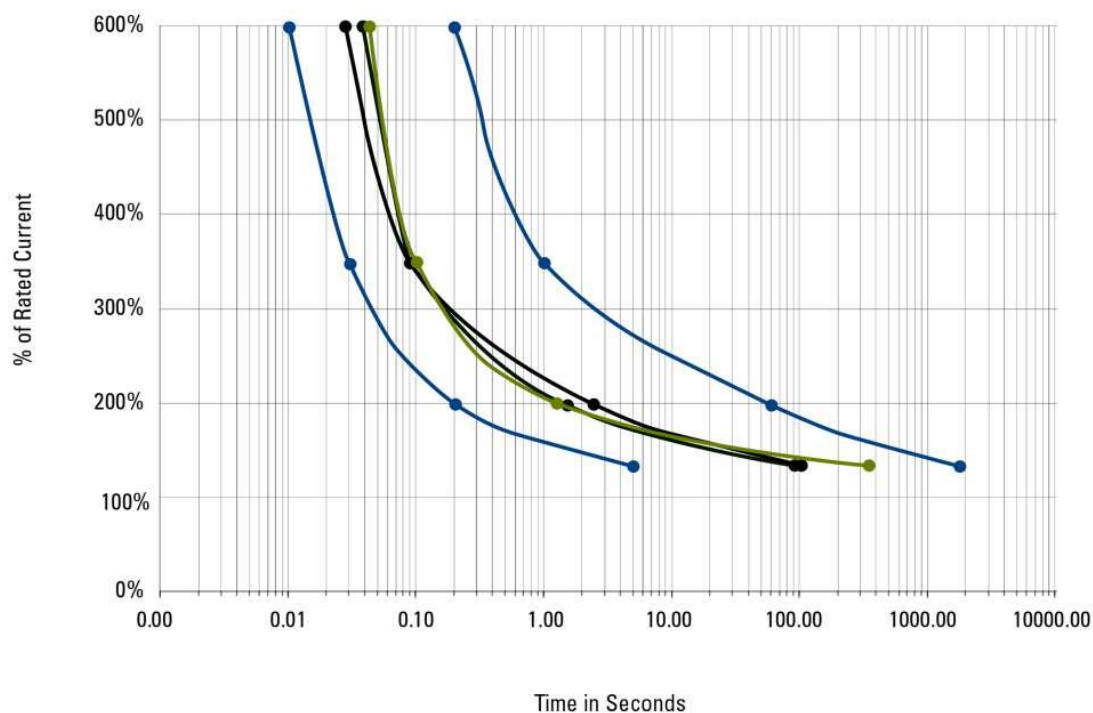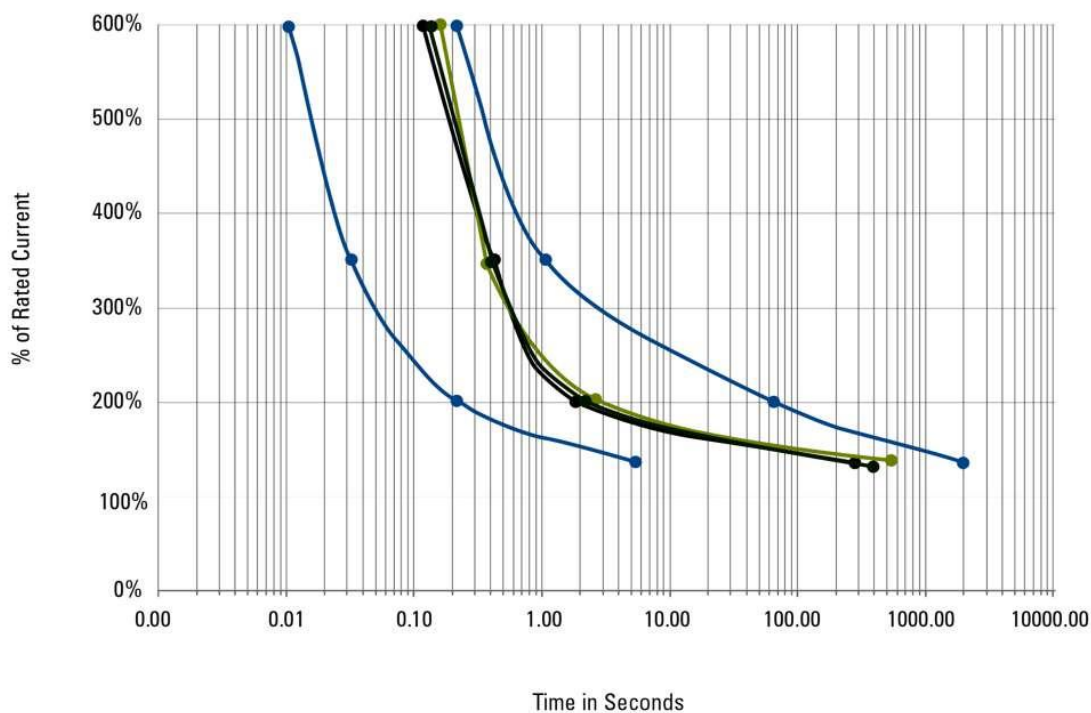

Temperature Derating / Time Current Curves

