



E83, T3-manual reset

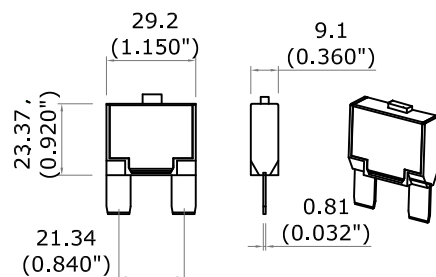


Max. rate current: 60A

E87, T1-auto reset (gold metal cover)
E88, T2-modified (silver metal cover)

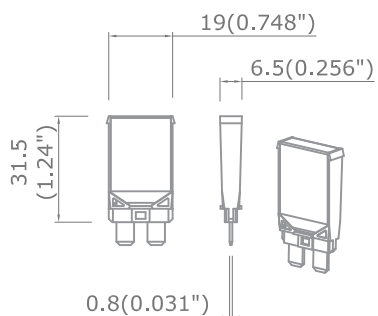

E89, T3-manual reset (silver cover)

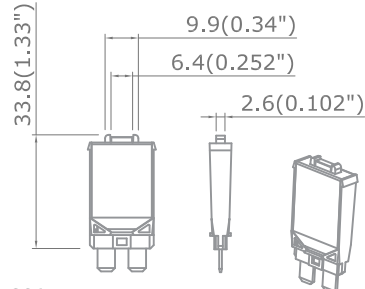


max. rate current: 30A




discontinued end 2023
replaced by E3_ATO
cross to 22X

Terminal code


2-wide ATC

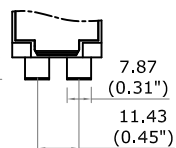


1-maxi

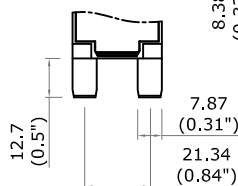

4-ATC, no dimple

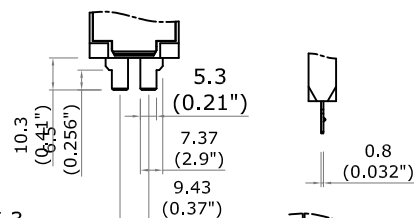

5- short ATC

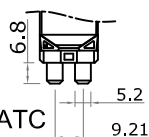

3-ATC w/dimple



E 8 – – –

for special marking

5-30A, E87/E88 14Vdc, E88 14/28Vdc, 5A (medium delay, must trip @ 150%)

Temperature: -40F(-40C) to 185F(85C)

* Meet S.A.E. J553

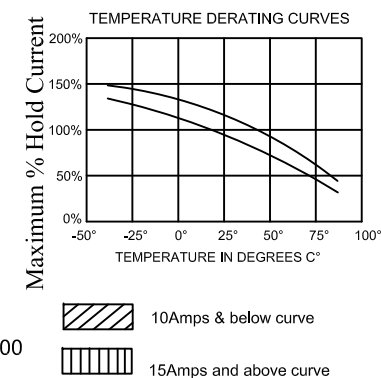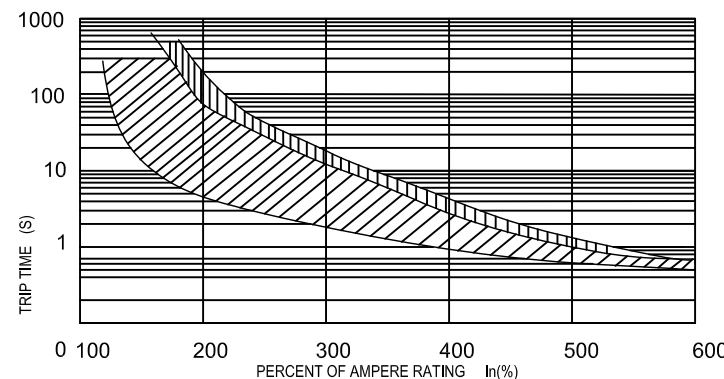

0<6 ±0.2	50<120 ±0.5	Material		Parts no	E8TYPE	 GLOSOTECH YOUR POWER, PROTECTED			
6<18 ±0.3	120<250±0.6			Drawing by	宋铁强				
18<50 ±0.4	250<400 ±0.7	Date	03/03/14	Check by	万文				
Tolerance unless otherwise specified,unit in mm		Issue	A/4	Approve by	Jerry	Drawing no	E8-1	Model code	E8系列