



3-ports USB(C+C+A) GaN Charger(65W/30W/30W)

One charger for all needs

3-port USB(C+C+A) GaN Charger

Fast charge for laptop/tablet/phone, etc.



GaN cutting-edge technology

Multiple fast charge protocols

Three ports charge in Sync

Portable design

Gallium nitride Technology

3rd generation cutting-edge semiconductor material
with advantages of small size, light weight, etc.,
compared to traditional silicon-based chargers



GaN

Note: the internal structure is a rendering
please refer to the actual product

65W High-efficiency Charging

USB-C1 support 65(MAX) single-port output, fast charge for laptop, Switch and other high power devices

Around **1.5Hrs**
Full of MacBook Air13

100%



3-Port Fast Charge

Support mutiple fast charge protocols



USB-C1 port

Supports
PPS/PD3.0/QC4+
SCP/FCP/AFC/MTK PE
BC1.2/Apple2.4A

65w

USB-C2 port

Supports
PPS/PD 3.0/QC4+
SCP/FCP/AFC/MTK PE
BC1.2/Apple 2.4A

30w


USB port

Supports
QC3.0/SCP/FCP
AFC/BC1.2
Apple2.4A


30w

Power Supply Diagram


Single port

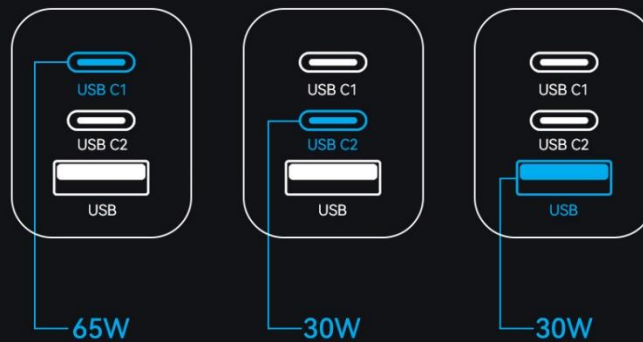

Dual ports

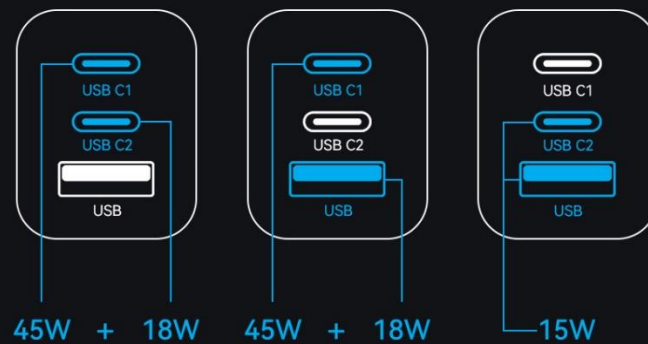


Three ports

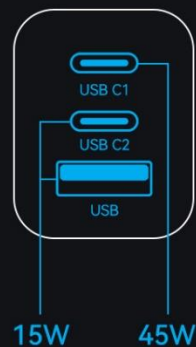

Three Ports Simultaneous Charging

Fully loaded with three devices charging
at the same time

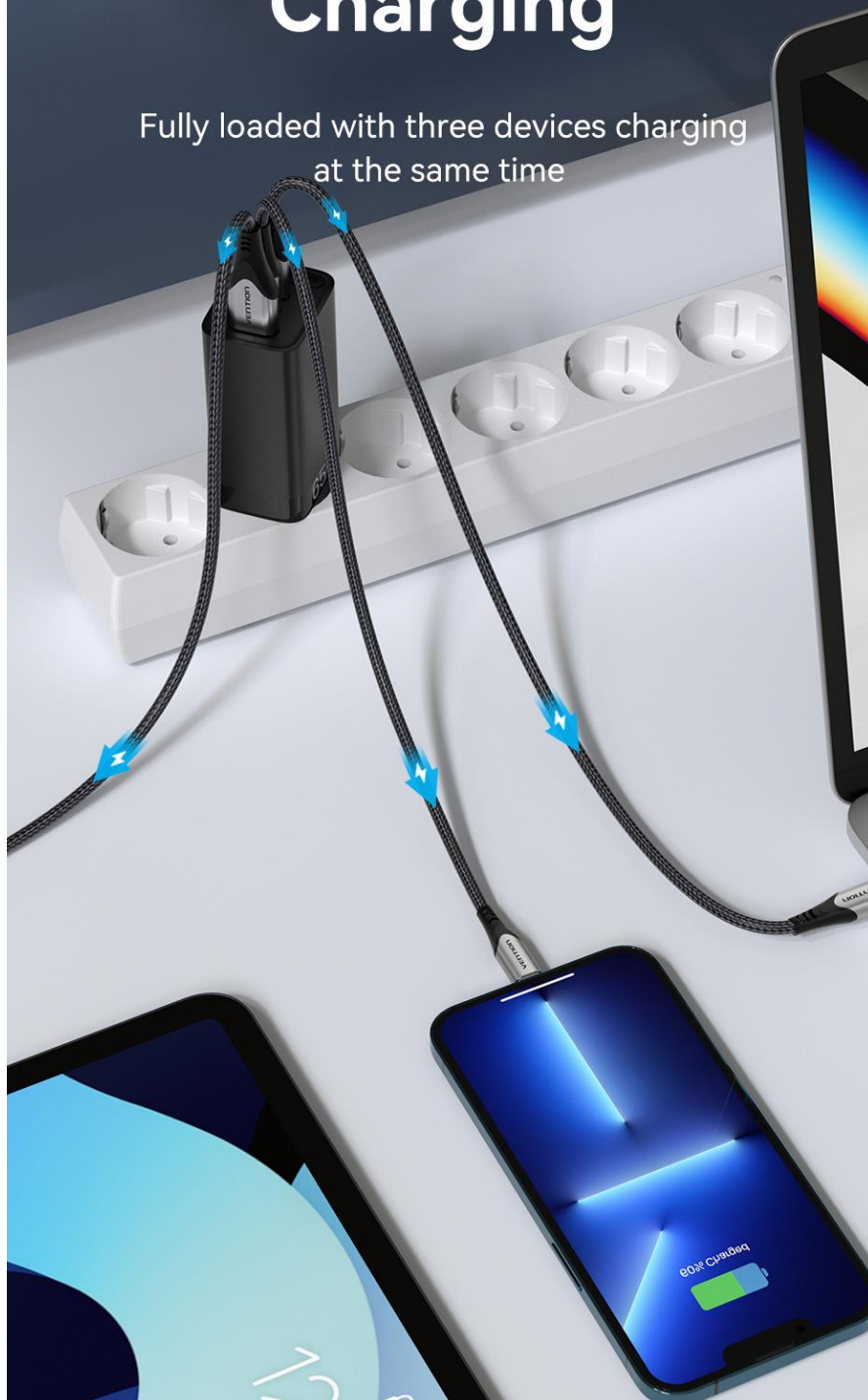

Six Charging Protections

With internal smart chip, intelligently identify different models and provide related current and charging protections



Note: The internal structure is a rendering please refer to the actual product.

Portable Size

Easy to put it into your luggage for long distance
business travelling



Product Parameters

Brand	Vention
Name	3-port USB(C+C+A) GaN Charger
	(65W/30W/30W)
Model	FEDB0-EU
Color	Black
Input	100-240V~50/60Hz 1500mA
Output(USB C1)	5V=3A,9V=3A,12V=3A,15V=3A
	20V=3.25A
Output(USB C2)	5V=3A,9V=3A,12V=2.5A,15V=2A
	20V=1.5A
Output(USB)	4.5V=5A,5V=4.5A,9V=3A,12V=2.5A
	20V=1.5A
USB C+USB A	USB C1+USB C2: 45W+18W
	USB C1+USB: 45W+18W
	USB C2+USB: 15W (5V=3A)
USB C1+USB C2+USB	45W (USB C1) +15W (USB C2+USB)
Protocols	USB C1: PPS/PD 3.0/QC4+/SCP/FCP
	AFC/MTK PE/BC1.2/Apple 2.4A
	USB C2: PPS/PD 3.0/QC4+/SCP/FCP
	AFC/MTK PE/BC1.2/Apple 2.4A
	USB A: QC 3.0/SCP/FCP/AFC/BC1.2
	Apple 2.4A
Interface Technics	Nickel-plated
Shell	PC Fire-retardant Material
Warranty	1 Year
Packing	Color Box



Package Display



Note: Packing difference exists for different meters or batches.
The photo is for reference only



3-ports USB(C+C+A) GaN Charger(65W/30W/30W)

Technical Features

Color	Black/White
Interface	USB-A+C
Shell	PC
Input	100-240V~50/60Hz, 1500mA
Output/Single-Port	Output (USB-C 1): 5V $\equiv$ 3A; 9V $\equiv$ 3A; 12V $\equiv$ 3A; 15V $\equiv$ 3A; 20V $\equiv$ 3.25A (65W) Output (USB-C 2): 5V $\equiv$ 3A; 9V $\equiv$ 3A; 12V $\equiv$ 2.5A; 15V $\equiv$ 2A; 20V $\equiv$ 1.5A (30W) Output (USB): 4.5V $\equiv$ 5A; 5V $\equiv$ 4.5A; 9V $\equiv$ 3A; 12V $\equiv$ 2.5A; 20V $\equiv$ 1.5A (30W)
Output/Two-Ports	Output (USB-C 1 + USB-C 2): 45W + 18W Output (USB-C 1 + USB): 45W + 18W Output (USB-C 2 + USB): 15W (5V/3A)
Output/Three-Ports	Output (USB-C 1 + USB-C 2 + USB): 45W (USB-C 1) + 15W (USB-C 2 + USB)
Protocols (USB-C 1/2)	PPS/PD 3.0/QC 4+/SCP/FCP/AFC/MTK PE/BC 1.2/Apple 2.4A
Protocols (USB)	QC 3.0/SCP/FCP/AFC/BC 1.2/Apple 2.4A

Color	Art.No.	EAN Code
White	FEDW0-EU	6922794763005
Black	FEDB0-EU	6922794762961



Package Contents

3-ports USB(C+C+A) GaN Charger(65W/30W/30W) x 1

Packaging Information

Packing Dimension	13.2*7.2*5.2cm
Packing Weight	0.172kg
Carton Dimension	48*29*31cm
Carton Qty	72pcs
Carton Weight	12.4kg

<https://ventiontech.com/>