


30W GaN Double Your Charge

Compatible with iPhone 8-16 Series/Android Phone.



GaN Nitride III

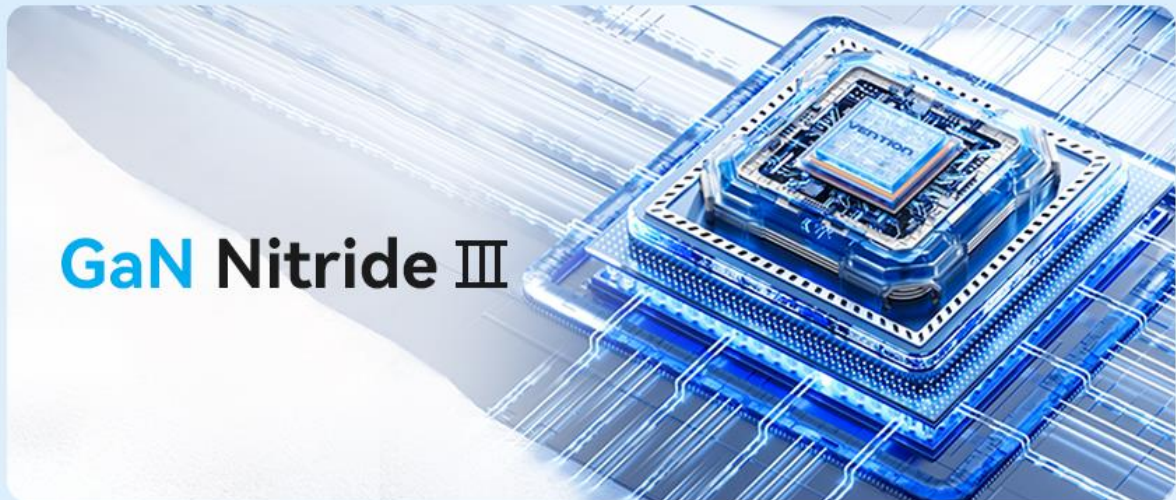

30W PD
Fast Charging PPS



Smaller
53%




USB-C + USB-A
Dual Ports Fast Charging



Low Temperature
Tech



GaN Nitride III Technology

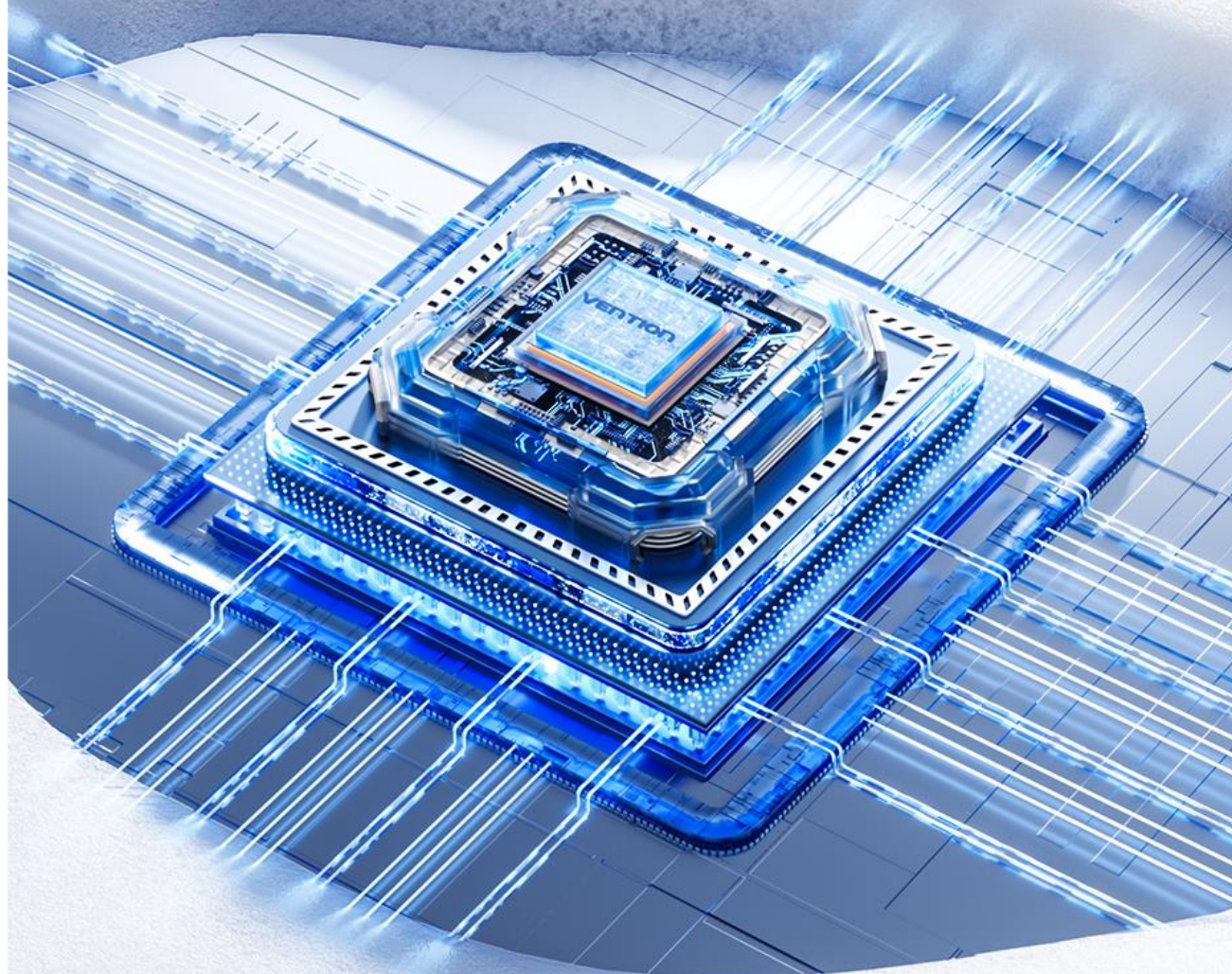


Note: The internal structure is a rendering. Please refer to the actual product.

Phone Camera Size

53% Smaller than the original 30W charger.



-53%

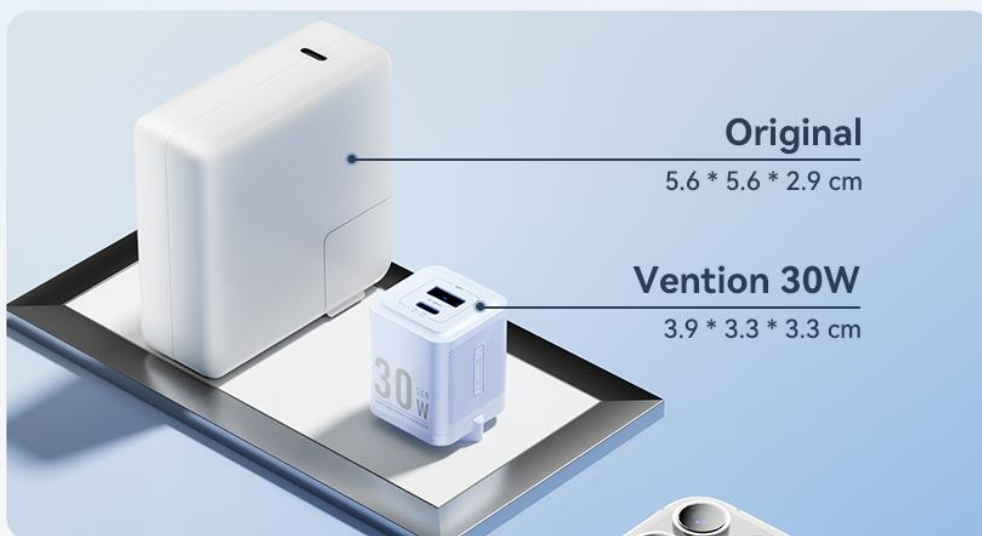

Original

5.6 * 5.6 * 2.9 cm

Vention 30W

 
3.9 * 3.3 * 3.3 cm

30W PD Fast Charging PPS

High speed charging for tablet, switch, phones and etc.



Compatible with Apple




28 mins

iPhone 14 Pro

60%

 Compatible with Android



60 mins

Samsung S22

98%

Note: All data are from Vention lab.

Fast Charge 2 at Once

Enhanced efficiency.



Low Temperature Technology

Safe charging with real-time protection all night.



Temperature Protection



Overvoltage Protection



Over Current Protection



Flame-Retardant Protection



Short Circuit Protection



Note: The internal structure is a rendering. Please refer to the actual product.

One Charger Nails it



Specifications

Brand	Vention
Name	GaN Charger
Model	FEQ
Color	Black/White/Pink/Blue
Interface	USB/USB-C
Input	100-240V~50/60Hz,0.8A
Output (USB-C)	5.0V=3.0A (15.0W); 9.0V=3.0A (27.0W); 12.0V=2.5A (30.0W); 15.0V=2.0A (30.0W); 20.0V=1.5A (30.0W) (PPS): 3.3V-11.0V=3.0A (30.0W Max)
Output (USB)	5.0V=3.0A (15.0W); 9.0V=3.0A (27.0W); 12.0V=2.5A (30.0W); 20.0V=1.5A (30.0W Max)
Total Output	5.0V=3.0A (15.0W)
Protocols (USB-C)	PPS/PD 3.0/QC 3.0/FCP/AFC/Apple 2.4A
Protocols (USB)	QC 3.0/FCP/SCP/AFC/Apple 2.4A
Shell	PC
Fire Rating	UL94-V0
Packing	Color Box



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.

Packaging Display

New Packing



Old Packing



Note: The packing has upgraded, two different packings will be dispatched randomly and won't affect the actual use



2-Ports USB (C + A) GaN Charger (30W/30W)

Technical Features

Color	Black/White/Pink/Blue
Interface	USB-A+C
Shell	PC
Input	100-240V~50/60Hz, 0.8A
Output	Output (USB-C): 5.0V= 3.0A (15.0W); 9.0V= 3.0A (27.0W); 12.0V= 2.5A (30.0W); 15.0V= 2.0A (30.0W); 20.0V= 1.5A (30.0W) Output (PPS): 3.3V~11.0V= 3.0A (30.0W Max) Output (USB): 5.0V= 3.0A (15.0W); 9.0V= 3.0A (27.0W); 12.0V= 2.5A (30.0W); 20.0V= 1.5A (30.0W Max) Total output: 5.0V= 3.0A (15.0W)
Protocols	Protocols (USB-C): PPS/PD 3.0/QC 3.0/FCP/AFC/Apple 2.4A Protocols (USB): QC 4.0/QC 3.0/FCP/SCP/AFC/Apple 2.4A

Color	Art.No.	EAN Code
White	FEQW0-EU	6922794782211
Pink	FEQP0-EU	6922794782235
Black	FEQB0-EU	6922794782204
Blue	FEQL0-EU	6922794782228



Package Contents

2-Ports USB (C + A) GaN Charger (30W/30W) x 1

Packaging Information

Packing Dimension	11.5*7*3.5cm
Packing Weight	0.07kg
Carton Dimension	48*29*31cm
Carton Qty	120pcs
Carton Weight	8.4kg

<https://ventiontech.com/>