




2-Ports USB (C + A) GaN Charger (30W/30W) with USB-C to USB-C Cable (1M)

GaN 30W Dual-Port PD Fast Charging Kit

Compatible with iPhone 15/16 Series/Android Phones.



GaN Tech III

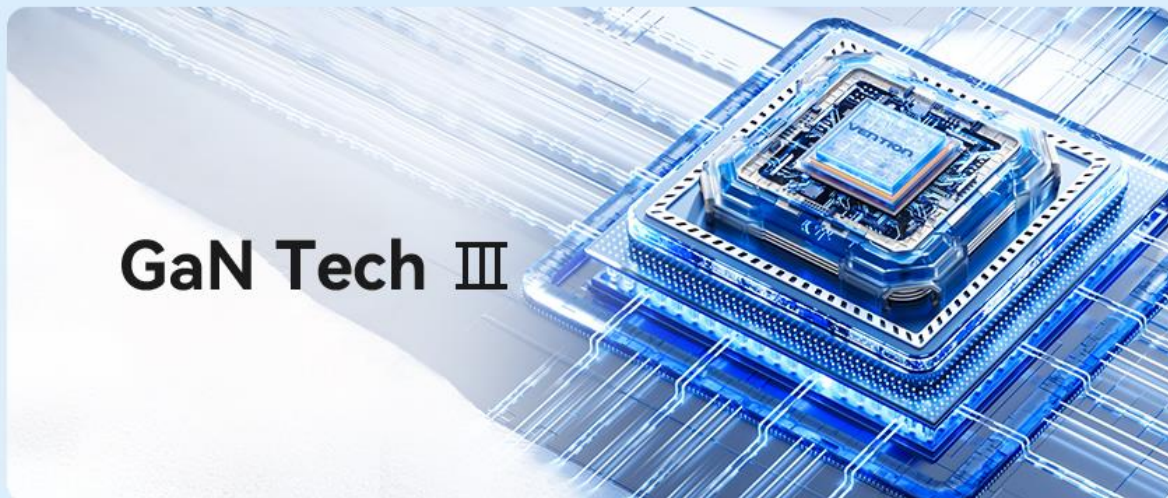

**30W PD Fast
Charging with PPS**



**Smaller
53%**




**USB-C + USB-A
Dual Ports**



**Low Temperature
Tech**



GaN Nitride III

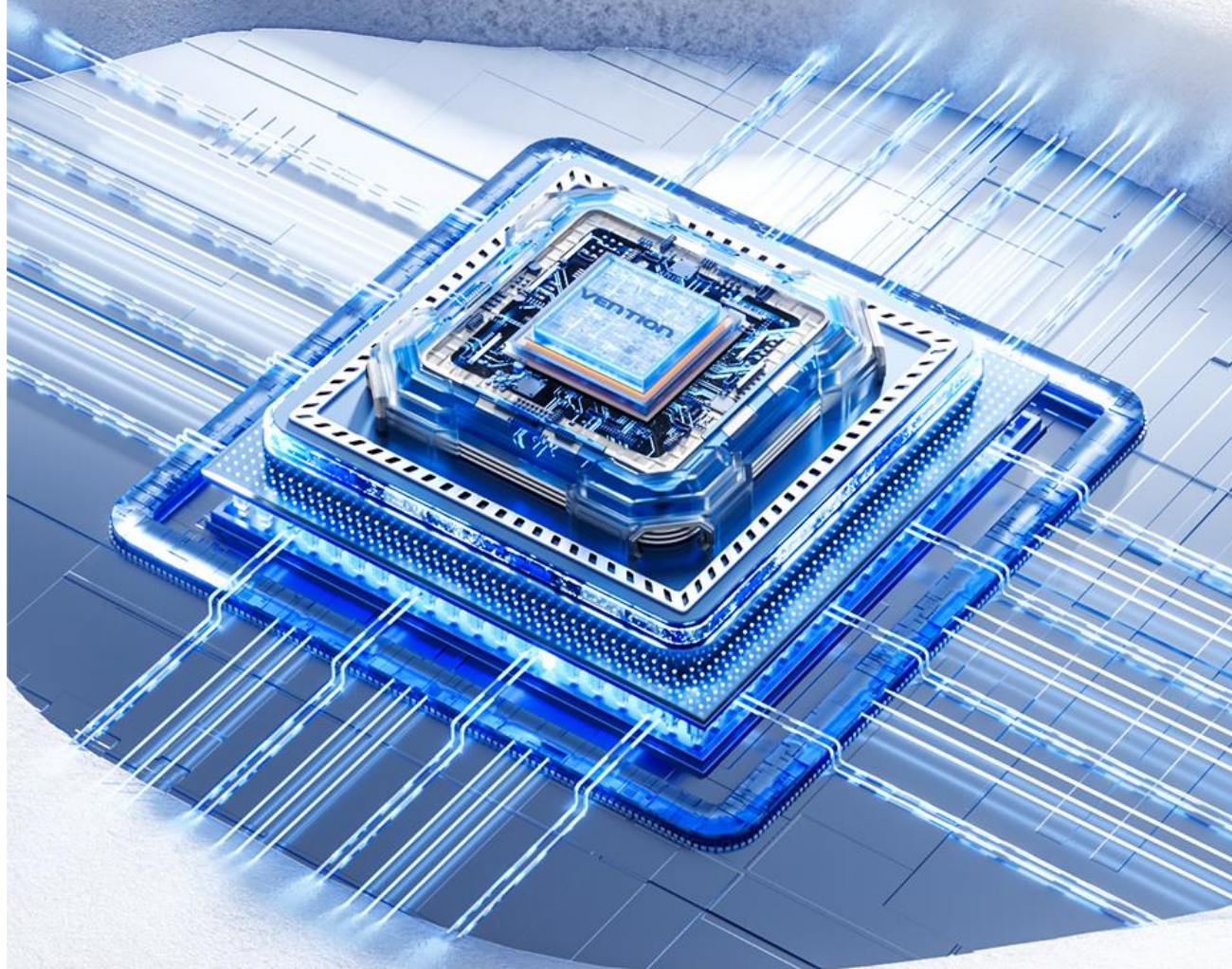


Note: The internal structure is a rendering. Please refer to the actual product.

Phone Camera Size

53% Smaller than the original 30W charger.



-53%

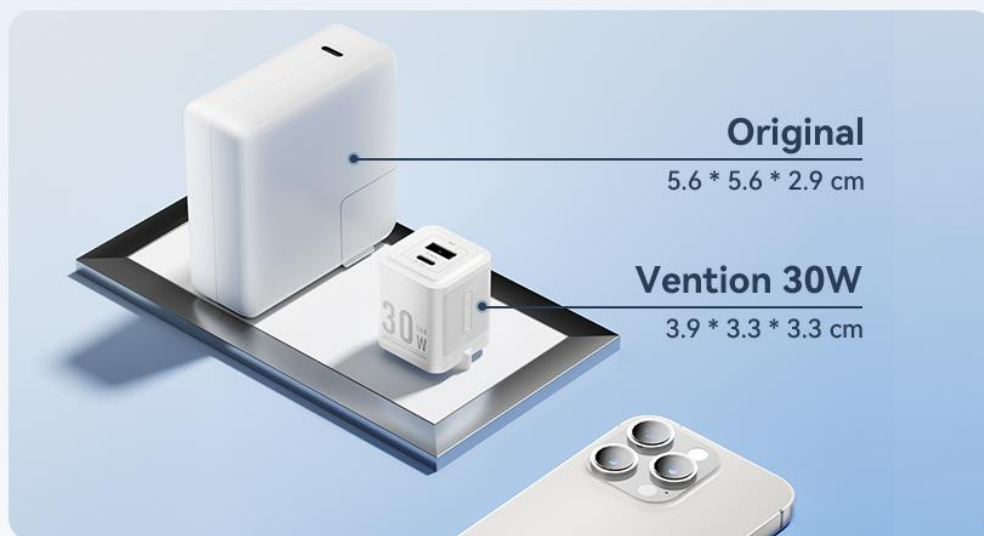

Original

5.6 * 5.6 * 2.9 cm

Vention 30W

 
3.9 * 3.3 * 3.3 cm

30W PD Fast Charging PPS

High speed charging for tablet, switch, phones and etc.



Compatible with Apple




28 mins

iPhone 14 Pro

60%

 Compatible with Android



60 mins

Samsung S22

98%

Note: All data are from Vention lab.

Fast Charge 2 at Once

Enhanced efficiency.



Total Output

5.0V $\Rightarrow$ 3.0A (15.0W)

Low Temperature Technology

Safe charging with real-time protection all night.



Temperature Protection



Overvoltage Protection



Over Current Protection



Flame-Retardant Protection



Short Circuit Protection




24hrs

Note: The internal structure is a rendering. Please refer to the actual product.

Includes 3A Type-C Fast Charging Cable

Flexible and durable.

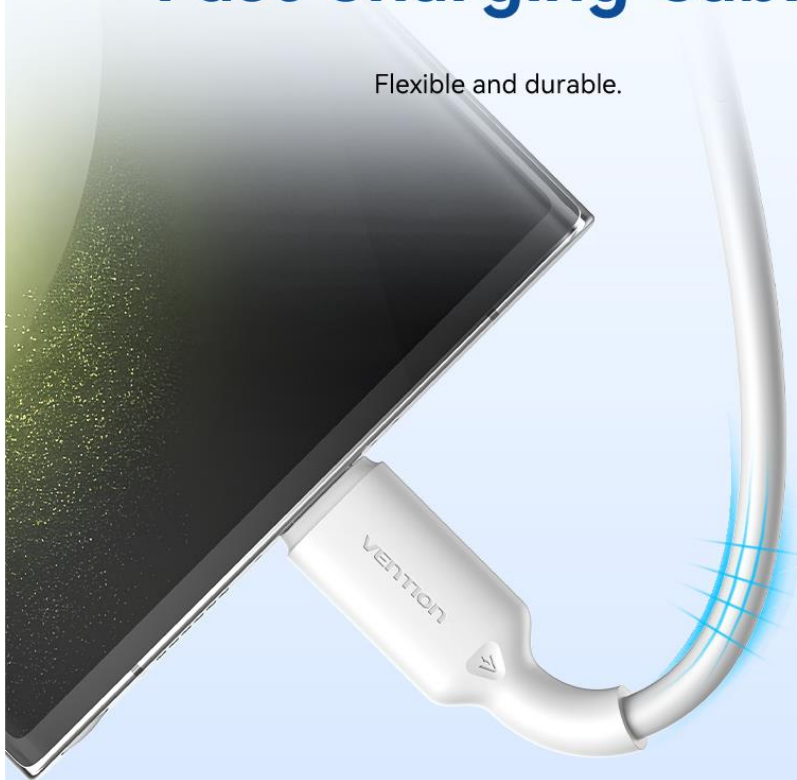

Wear-Resistant Over
10,000 Bend
Tests

Full-Wrap Braided
Connector



PVC Jacket
Long-Lasting



Note: All data are from Vention Lab.


One Charger Nails it



Specifications


Brand	Vention
Name	2-Port USB (C + A) GaN Charger (30W/30W) with USB-C to USB-C Cable (1m) EU-Plug
Model	TZ-FEQ-EU-01
Color	Black/White
Charger	
Interface	USB-A/USB-C
Input	100-240V~50/60Hz, 0.8A
USB-C Output	5.0V $\equiv$ 3.0A 15.0W; 9.0V $\equiv$ 3.0A 27.0W; 12.0V $\equiv$ 2.5A 30.0W; 15.0V $\equiv$ 2.0A 30.0W; 20.0V $\equiv$ 1.5A 30.0W
PPS	3.3V-11.0V-3.0A(30.0W Max)
USB-A Output	5.0V $\equiv$ 3.0A 15.0W; 9.0V $\equiv$ 3.0A 27.0W; 12.0V $\equiv$ 2.5A 30.0W; 20.0V $\equiv$ 1.5A (30.0W Max)
Total Output	5.0V $\equiv$ 3.0A 15.0W
USB-C Protocol	PPS/PD 3.0/QC 3.0/FCP/AFC/Apple 2.4A
USB-A Protocol	QC 3.0/FCP/SCP/AFC/Apple 2.4A
Shell	PC
Fire Rating	UL94-V0 Cable
Cable	
Interface	USB-C
Output Current	3A Max
Rated Power	60W Max
Data Transfer Rate	480Mbps
OD	3.8mm
Length	1 m
Packing	Color Box

Dimensions

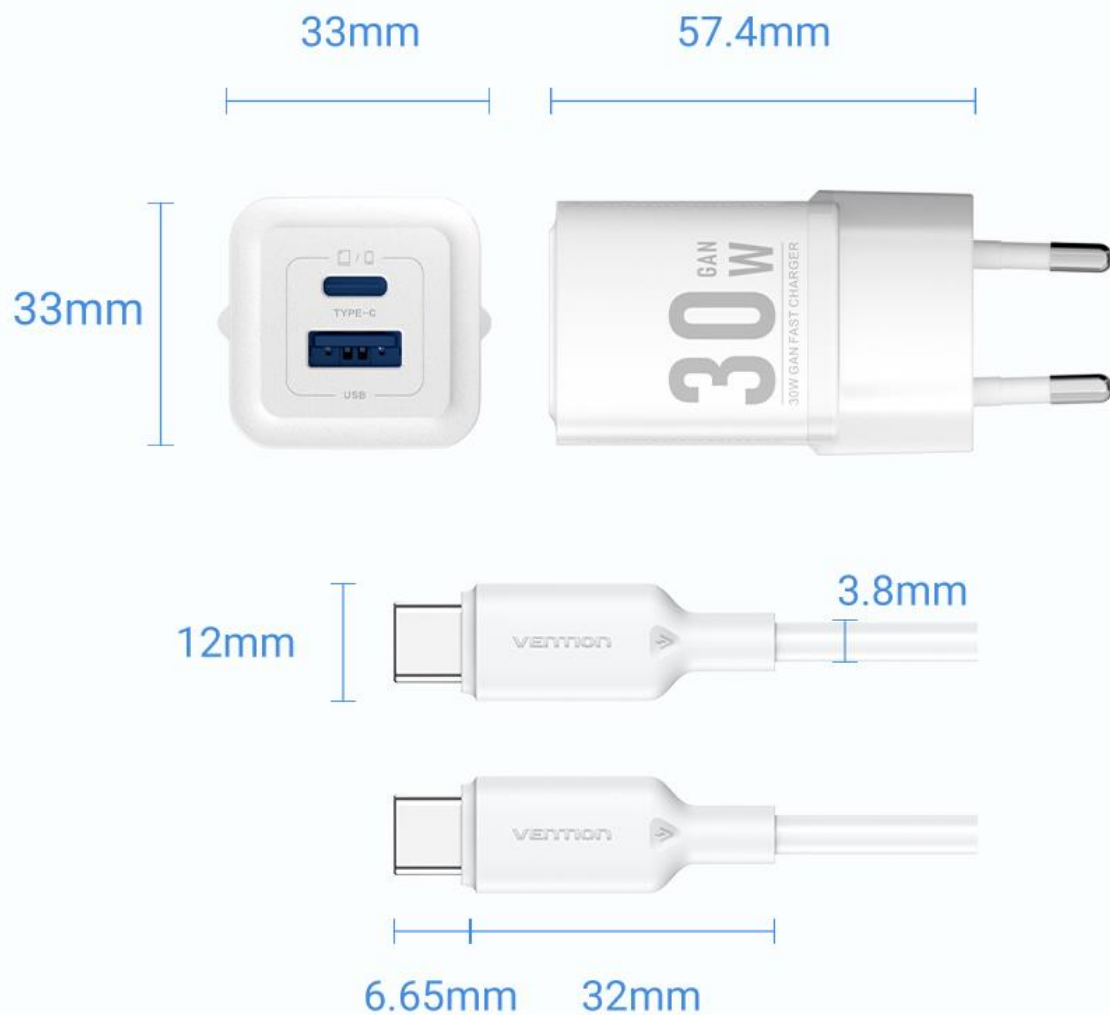

Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.

Accessories & Packaging

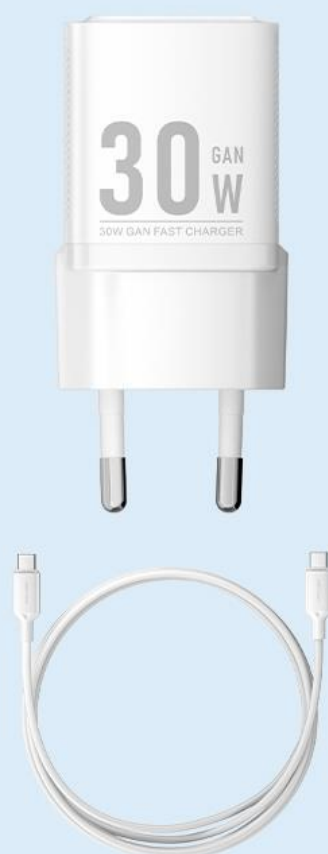

Note: Packing difference exists for different meters or batches.
The photo is for reference only.



2-Ports USB (C + A) GaN Charger (30W/30W)

Technical Features

Charger

Color	Black/White
Interface	USB-A+C
Shell	PC
Input	100-240V~50/60Hz, 0.8A
Output	Output (USB-C): 5.0V $\Rightarrow$ 3.0A (15.0W); 9.0V $\Rightarrow$ 3.0A (27.0W); 12.0V $\Rightarrow$ 2.5A (30.0W); 15.0V $\Rightarrow$ 2.0A (30.0W); 20.0V $\Rightarrow$ 1.5A (30.0W) Output (PPS): 3.3V~11.0V $\Rightarrow$ 3.0A (30.0W Max) Output (USB): 5.0V $\Rightarrow$ 3.0A (15.0W); 9.0V $\Rightarrow$ 3.0A (27.0W); 12.0V $\Rightarrow$ 2.5A (30.0W); 20.0V $\Rightarrow$ 1.5A (30.0W Max) Total output: 5.0V $\Rightarrow$ 3.0A (15.0W)
Protocols	Protocols (USB-C): PPS/PD 3.0/QC 3.0/FCP/AFC/Apple 2.4A Protocols (USB): QC 4.0/QC 3.0/FCP/SCP/AFC/Apple 2.4A

Cable

Interface	USB-C
Electroplating Process	Nickel-Plated
Jacket	PVC
Shell	PVC
OD	3.8mm
Data Transfer Rates	480Mbps
Rated Current	3A Max
Rated Power	60W Max

Color	Art.No.	EAN Code
Black	TZ-FEQB0-EU-01	6922794786356
White	TZ-FEQW0-EU-01	6922794786387



Package Contents

2-Ports USB (C + A) GaN Charger (30W/30W) x 1, USB-C to USB-C Cable (1M) x1

Packaging Information

Packing Dimension	11.5*7*3.5cm
Packing Weight	0.07kg
Carton Dimension	48*29*31cm
Carton Qty	120pcs
Carton Weight	8.4kg

<https://ventiontech.com/>