

Intelligent fast charging

USB-C PD 30W Fast Charger

For iPhone 13 Pro/Pro Max/iPad Pro 2021



Fast charge
iPhone 8-13

Phone/tablet
applicable

Trickle
charging

Multiple
charging
protocols

Upgraded PD 30W Power

Full speed charging for iPad Pro



Around 2.5 Hrs
Full of iPad Pro 2021

100%

Note: All data are from Vention Lab

PD 27W/20W Backward Compatible

Intelligently identify 5V $\equiv$ 3A/9V $\equiv$ 3A/12V $\equiv$ 2.5A power,
design for iPhone 13 series


Rated power	Device list
20W	iPhone 13 Mini/iPhone 13
27W	iPhone 13 Pro/iPhone 13 Pro Max
30W	iPad Pro 2021



Note: All data are from Vention Lab

Three Times Faster

Three times faster than original iPhone charger

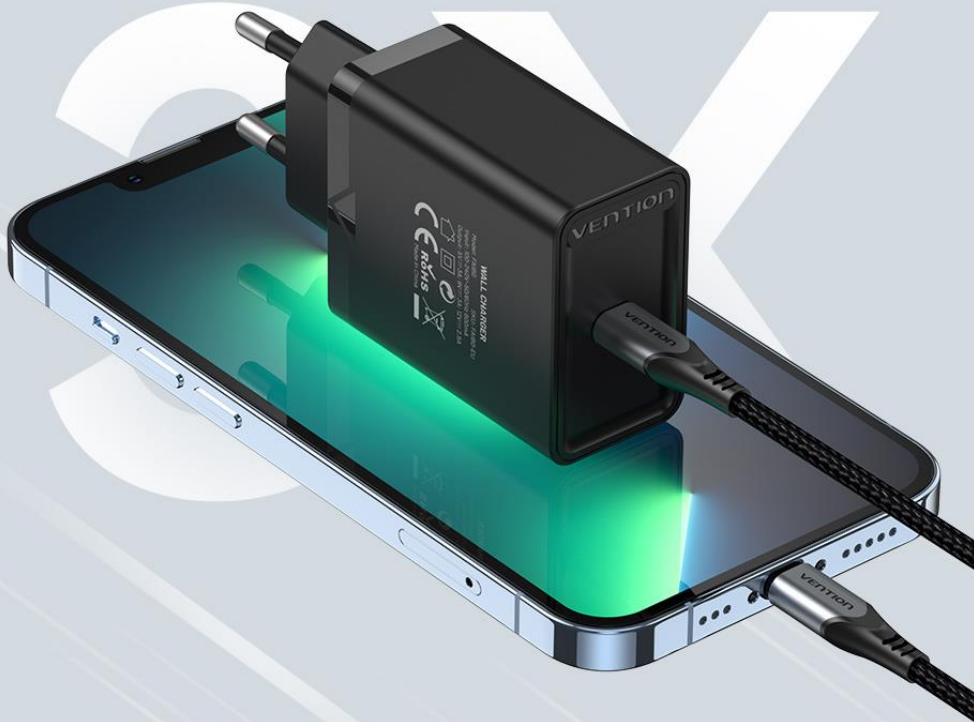

iPhone 13
30min charging test



Note: All data are from Vention Lab

Available for Laptop

Powerful chip with a maximum 30W output,
emergency charging for MacBook




Around 2.5 Hrs
Full of MacBook 12"

100%

Note: All data are from Vention Lab

PD Certification Chip

Adopted with PD certificated chip, intelligently
identify multiple charging protocols

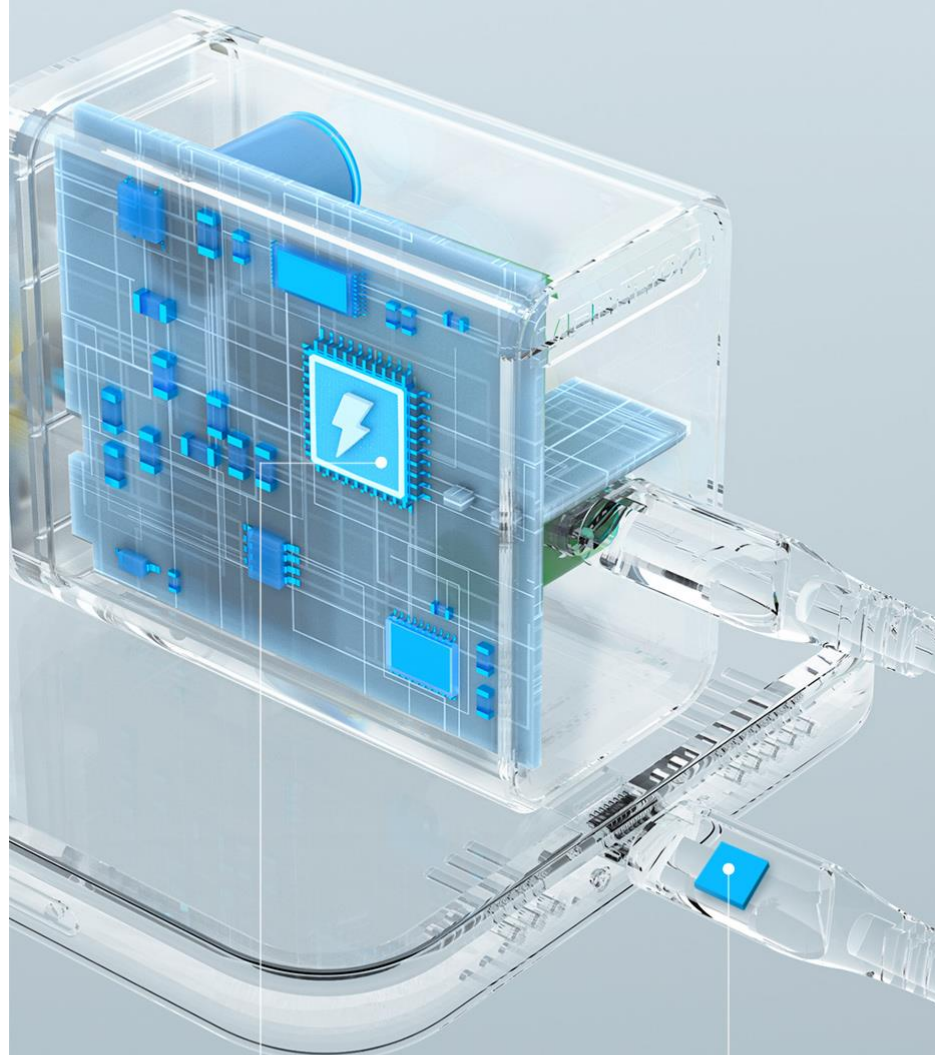

PD

PD certificated
Intelligent charging

MFi

MFi Apple certificated chip
No pop-up

Note: This product is not equipped with cable, customers are recommended to purchase
Vention MFi certificated PD fast charge cable. The internal structure is rendering,
please refer to the actual product

Multiple Protocols Compatible


Support PPS/PD3.0/QC4.0/SCP/FCP/AFC/BC1.2/Apple 2.4A
and other main stream charging protocols



Phone | Tablet | Laptop | Bluetooth | earphone | Watch

Charging Safety Guarantee

When battery reaches 80%, automatically switch to trickle charging mode for safe charging status

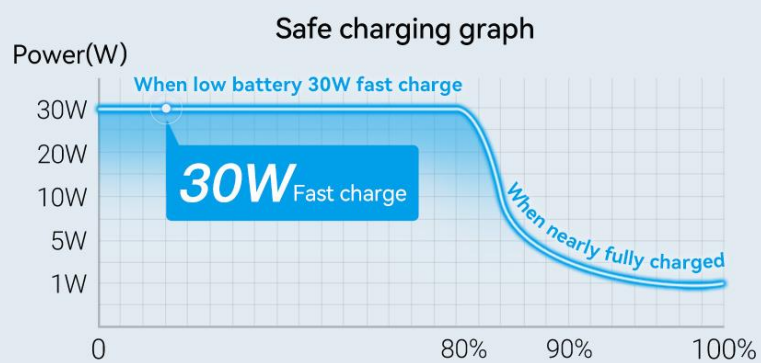

Note: All data are from Vention Lab

Excellent Temperature Control

With high performance transformer MOS tube, capacitance, etc., ensures a safe and low-temperature charging



Note: The internal structure is a rendering,
please refer to the actual product

Premium Shell Material

Tough PC fire retardance shell with features of high temperature durability, anti-pressure, and fire durability



High
temperature
durability



Anti
pressure



Fire
retardance



Tiny and Portable

Easy to carry around



Six Major Protections



Over-pressure
protection



Over-current
protection



Circuit
protection



Short-circuit
protection




Over temperature
protection



Thunder
protection

Product Parameters

Brand:	Vention
Name:	Fast Charger
Model:	FAIB0-EU
Color:	Black
Interface:	USB-C
Power Input:	100-240V~50/60Hz 800mA
Power Output:	5V=3A/9V=3A/12V=2.5A
Protocols:	PPS/PD3.0/QC4.0/SCP/FCP/AFC/ BC1.2/Apple 2.4A
Total Output:	30W Max
Shell:	PC
Warranty:	1 Year
Packing:	Color Box

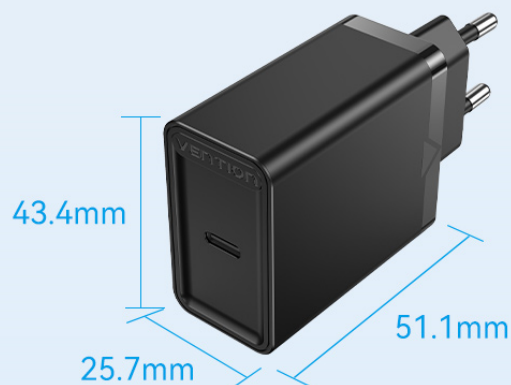

Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance

Package Display



Note: Packing difference exists for different meters or batches.
The photo is for reference only



1-port USB-C Wall Charger(30W)

Technical Features

Color	Black/White
Interface	USB-C
Shell	PC
Input	100-240V~50/60Hz, 800mA
Output	5V $\overline{=}$ 3A; 9V $\overline{=}$ 3A; 12V $\overline{=}$ 2.5A; 15V $\overline{=}$ 2A; 20V $\overline{=}$ 1.5A
Protocols	PPS/PD 3.0/QC 4.0/AFC/FCP/BC 1.2/Apple 2.4A

Color	Art.No.	EAN Code
White	FAIW0-EU	6922794762787
Black	FAIB0-EU	6922794762749



Package Contents

1-port USB-C Wall Charger(30W) x 1

Packaging Information

Packing Dimension	12*7*3cm
Packing Weight	0.088kg
Carton Dimension	48*29*31cm
Carton Qty	120pcs
Carton Weight	10.5kg

<https://ventiontech.com/>