

PD3.0+QC3.0

2-port USB Fast Charger

Two devices charge at the same time



Dual ports
18W+PD20W

Trickle charging
For battery safety

Wide compatibility
For Apple/Android

Tiny and portable
Travelling convenient

Two Ports Fast Charge

Support multiple charging protocols



18W

USB-A port

Support QC3.0/FCP/AFC/BC1.2/Apple 2.4A

20W

USB-C port

Support PD3.0/QC4.0/FCP/AFC/BC 1.2/
Apple 2.4A

38W

USB-A+USB-C

Two port simultaneous in use


USB-C

iPhone 12/13 Full Speed Charge

USB-C supports PD20W, with compatible MFi certificated PD fast charge cable



iPhone 13 30min charging test

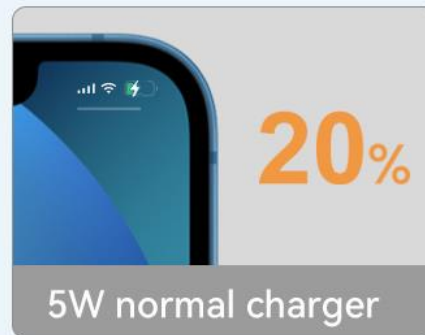

Note: All data are from Vention Lab

USB-A

Support Various Charging Protocols

USB-A output 3A(Max) current, support QC3.0, FCP, AFC and other fast charge technology



Around **100min**
Full of Xiaomi 11



Around **94min**
Full of Huawei P30

Note: All data are from Vention Lab

USB-A+USB-C

Full Speed Charging

Full speed charging for two devices at the same time



Trickle Charging Mode

Intelligently switch to trickle mode when battery reaches 80% for battery life extension



When low battery situation

Switch to fast charge



When battery reaches to 80%


Switch on to trickle mode



Note: All data are from Vention Lab

Six Charging Protections

With internal smart chip, intelligently identify different models and provide related current and charging protections

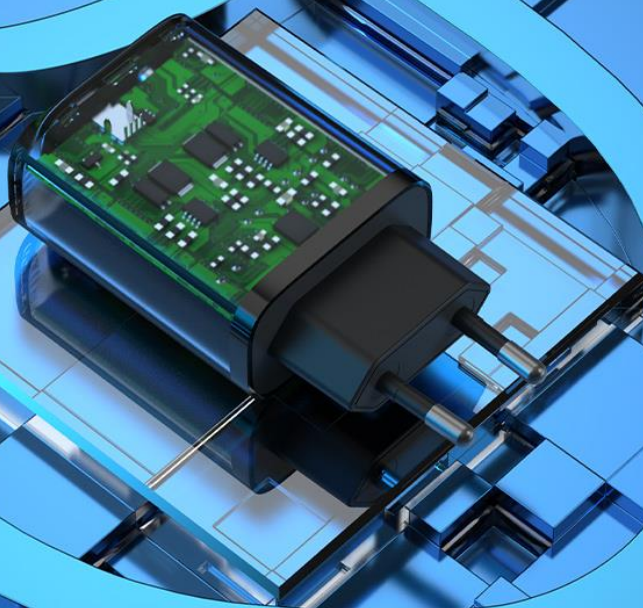

Over-temperature protection



Over power protection



Over voltage protection



Over current protection




Short circuit protection



Lightning protection

Note: The internal structure is a rendering, please refer to the actual product.

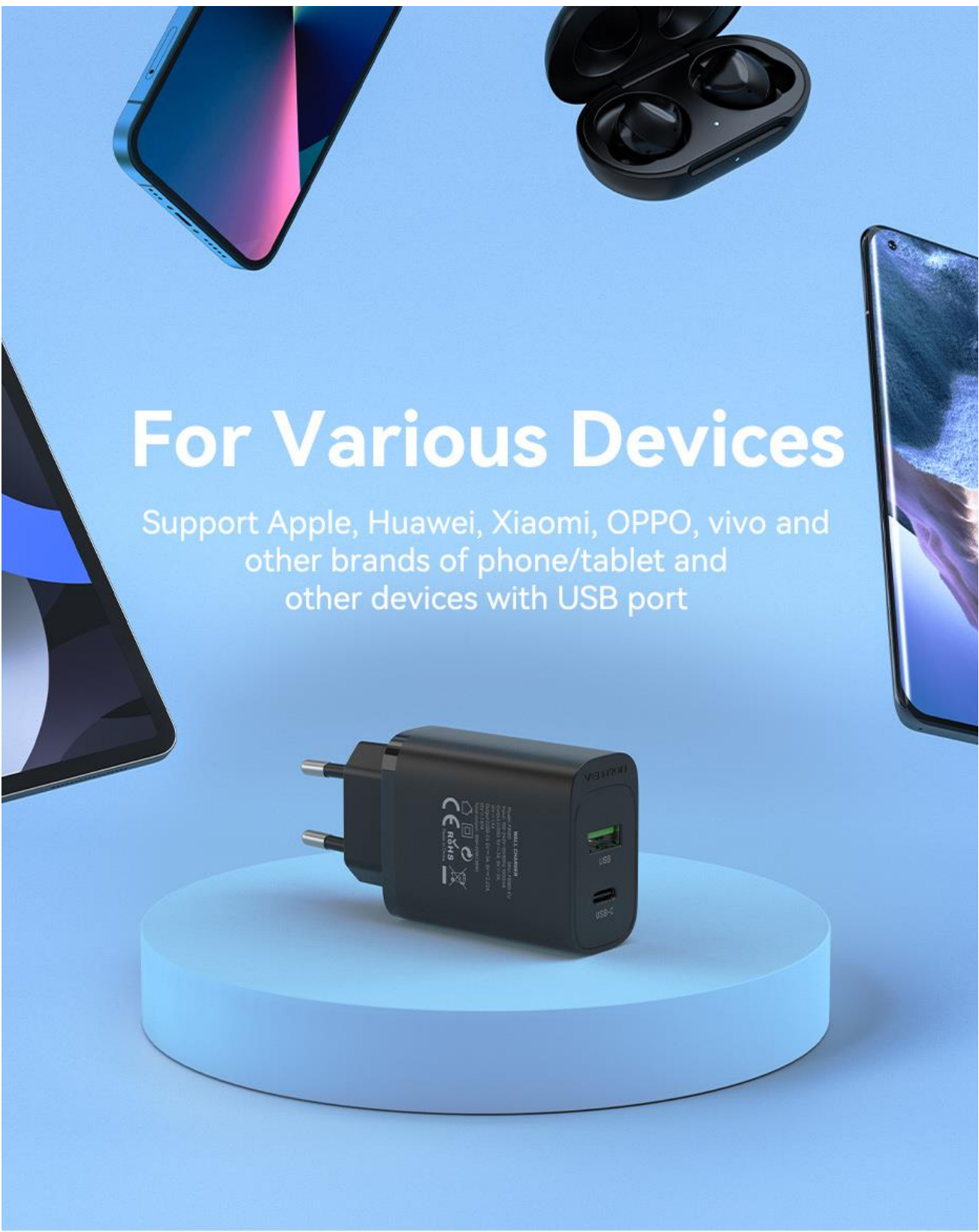

For Various Devices

Support Apple, Huawei, Xiaomi, OPPO, vivo and other brands of phone/tablet and other devices with USB port

Tough Quality

Premium PC material for mutiple protections and abilities



Fire
retardance



Anti
pressure



High temperature
durability



Tiny and Portable

Convenient and tiny size, easy for carrying around



Product Parameters

Brand	Vention
Name	2-port USB A+C (18W+20W) Charger
Model	FBIB0-EU
Color	Black
Protocol	USB: QC3.0/FCP/AFC/BC1.2/Apple 2.4A USB-C: PD3.0/QC4.0/FCP/AFC/BC 1.2/Apple 2.4A
Rated Output	USB: 5V=3A/9V=2A/12V=1.5A USB-C: 5V=3A/9V=2.22A/12V=1.67A
Simultaneous Output	18W+20W (38W)
Interface Technics	Nickel-plated
Fire Rating	UL94 V-0
Shell	PC Fire-retardance Material
Warranty	1 Year
Packing	Color Box





2-ports USB(A+C) Wall Charger (18W+20W)

Technical Features

Color	Black
Interface	USB-A+C
Shell	PC
Input	100-240V~50/60Hz, 500mA
Output	USB A: 5V $\equiv$ 3A; 9V $\equiv$ 2A; 12V $\equiv$ 1.5A (18W Max) USB C: 5V $\equiv$ 3A; 9V $\equiv$ 2.22A; 12V $\equiv$ 1.67A (20W Max)
Protocols	USB A: QC 3.0/FCP/AFC/BC 1.2/Apple 2.4A USB C: PD 3.0/QC 4.0/QC 3.0/FCP/AFC/BC 1.2/Apple 2.4A

Color	Art.No.	EAN Code
Black	FBIB0-EU	6922794761834



Package Contents

2-ports USB(A+C) Wall Charger (18W+20W) x 1

Packaging Information

Packing Dimension	12*7*3cm
Packing Weight	0.124kg
Carton Dimension	48*29*31cm
Carton Qty	120pcs
Carton Weight	14.9kg

<https://ventiontech.com/>