

4-Ports USB (C + C + A + A) GaN Universal Travel Adapter (65W/65W/60W/5W)

65W GaN Universal Travel Adapter

Explore the world, conquer business trips,
and ace your studies abroad—all with just one adapter



Five Key Strengths



GaN Technology



Safety 10A fuse



PD 65W & QC 60W
Fast laptop charging



Compact and
Worldwide use



AC + USB
5 Devices charging simultaneously

GaN Technology

Eight layer protection



Temperature
protection



Over Current
Protection



Overvoltage
Protection



Overcharge
Protection



Under Voltage
Protection



Short Circuit
Protection



Overload
Protection



Chip
protection



Note: The internal structure is a rendering.
Please refer to the actual product.


Upgraded 10A Fuse



Safer



Easier to purchase

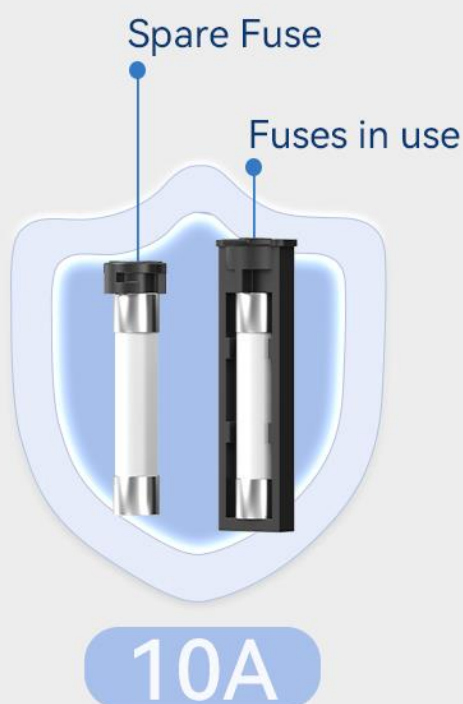

Supports **2500W** power for various equipment.



laptop



hair dryer



kettle



induction cooker



fan



iron



desk lamp



razor



projector



PD 65W & QC 60W Fast Charging

Rapid laptop recharge




USB-C1
Single port
65W Max



USB-C2
Single port
65W Max



USB-A1
Single port
60W Max

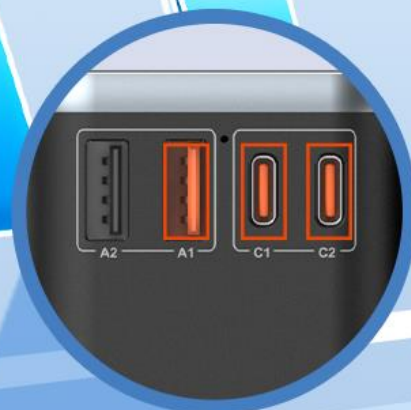

Charge 5 Devices at Once

Save your clustered desktop.



USB Power Output

Power up fast without risking your device with dynamic charging.

Single-port mode



USB-C1: 65.0W



USB-C2: 65.0W



USB-A1: 60.0W



USB-A2: 5.0W

Dual-port mode



USB-C1 + USB-C2:



20.0W + 45.0W



USB-C1 + USB-A1:



5.0V $\Rightarrow$ 3.0A (15.0W)



USB-C1 + USB-A2:



60.0W + 5.0W



USB-C2 + USB-A1:



45.0W + 18.0W



USB-C2 + USB-A2:



60.0W + 5.0W

Three-port mode



(USB-C1 + USB-A1)
+ USB-C2:



(5.0V $\Rightarrow$ 3.0A)



+ 45.0W



USB-C1 + USB-C2
+ USB-A2:



20.0W + 45.0W



+ 5.0W



(USB-C1+USB-A1)
+ USB-A2:



(5.0V $\Rightarrow$ 3.0A)



+ 5.0W



USB-C2 + USB-A1
+ USB-A2:



45.0W + 18.0W



+ 5.0W

Four-port mode



(USB-C1 + A1)
+ C2 + A2:



(5.0V $\Rightarrow$ 3.0A)



+ 45.0W + 5.0W

Four Plug Types

An all-in-one charging solution.



Addressing all Your Charging Requirements

The adapter is compatible with most countries worldwide.

US plug



AU plug



UK plug



EU plug



2 pin plug China



3 pin plug China



Note: Please confirm that the rated voltage matches before using.

100-250V World-wide Voltage



Note:

1. AC appliances can be directly plugged in, with a maximum load capacity of 10A 2500W.
2. This product does not have a voltage conversion function. When using the AC interface, the device voltage needs to be consistent with the local voltage.

Easy to Use

Only one plug can be introduced at a time.



Attentions:

1. Please make sure that the button is reset when the button is pushed out and retracted to the bottom, and if the button is not reset, it means that the pug has not been pushed in place and will affect the normal use.
2. Only one plug-type can be used at one time by sliding the knob selection, other plug-pins are locked automatically.

Global Adapter

Light as **195g** $\approx$ Mouse weight



Specifications

Brand	Vention
Name	4-Port USB (C + C + A + A) GaN Universal Travel Adapter (65W/65W/60W/5W) Black
Model	FJF
Color	Black
Interface	USB-C*2/USB-A*2
Rated Output	100-250V~10A Max, 2500W Max
Single-port output mode	USB-C1/C2: 5.0V $\Rightarrow$ 3.0A 15.0W; 9.0V $\Rightarrow$ 3.0A 27.0W; 12.0V $\Rightarrow$ 3.0A 36.0W; 15.0V $\Rightarrow$ 3.0A 45.0W; 20.0V $\Rightarrow$ 3.25A 65.0W USB-A1: 4.5V $\Rightarrow$ 5.0A 22.5W; 5.0V $\Rightarrow$ 4.5A 22.5W; 5.0V $\Rightarrow$ 3.0A 15.0W; 9.0V $\Rightarrow$ 3.0A 27.0W; 12.0V $\Rightarrow$ 3.0A 36.0W; 20.0V $\Rightarrow$ 3.0A 60.0W USB-A2: 5.0V $\Rightarrow$ 1.0A 5.0W
Multiple-port output mode	USB-C1 + C2: 20.0W + 45.0W (USB-C1 + A1) + C2: (15.0W) + 45.0W (USB-C1 + A1) + C2 + A2: (15.0W) + 45.0W + 5.0W
Total output	65.0W
Protocols	USB-C1/C2: PD 3.0/PPS/ AFC/FCP/Apple 2.4A USB-A1: QC 3.0/SCP/ AFC/Apple 2.4A USB-A2: BC1.2
Shell	PC
Fire Rating	UL 94V-0
Packing	Color Box



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.

Packaging Display



Note: Packing difference exists for different meters or batches.
The photo is for reference only.



65W GaN Universal Travel Adapter

Technical Features

Color	Black
Interface	USB-A+C
Shell	PC
Rated output	100-250V~10A Max, 2500W Max
Output/Single-Port	Output (USB-C 1/2): 5.0V $\equiv$ 3.0A (15.0W); 9.0V $\equiv$ 3.0A (27.0W); 12.0V $\equiv$ 3.0A (36.0W); 15.0V $\equiv$ 3.0A (45.0W); 20.0V $\equiv$ 3.25A (65.0W) Output (USB-A 1): 4.5V $\equiv$ 5.0A (22.5W); 5.0V $\equiv$ 4.5A (22.5W); 5.0V $\equiv$ 3.0A (15.0W); 9.0V $\equiv$ 3.0A (27.0W); 12.0V $\equiv$ 3.0A (36.0W); 20.0V $\equiv$ 3.0A (60.0W) Output (USB-A 2): 5.0V $\equiv$ 1.0A (5.0W)
Output/Two-Ports	USB-C 1 + USB-C 2: Output (USB-C 1): 5.0V $\equiv$ 3.0A (15.0W); 9.0V $\equiv$ 2.22A (20.0W); 12.0V $\equiv$ 1.67A (20.0W) Output (USB-C 2): 5.0V $\equiv$ 3.0A (15.0W); 9.0V $\equiv$ 3.0A (27.0W); 12.0V $\equiv$ 3.0A (36.0W); 15.0V $\equiv$ 3.0A (45.0W); 20.0V $\equiv$ 2.25A (45.0W)
Output/Three-Ports	USB-C 1 + USB-C 2 + USB-A 1: Output (USB-C 1 + USB-A 1): 5.0V $\equiv$ 3.0A (15.0W) Output (USB-C 2): 5.0V $\equiv$ 3.0A (15.0W); 9.0V $\equiv$ 3.0A (27.0W); 12.0V $\equiv$ 3.0A (36.0W); 15.0V $\equiv$ 3.0A (45.0W); 20.0V $\equiv$ 2.25A (45.0W)
Output/Four-Ports	USB-C 1 + USB-C 2 + USB-A 1 + USB-A 2: Output (USB-C 1 + USB-A 1): 5.0V $\equiv$ 3.0A (15.0W) Output (USB-C 2): 5.0V $\equiv$ 3.0A (15.0W); 9.0V $\equiv$ 3.0A (27.0W); 12.0V $\equiv$ 3.0A (36.0W); 15.0V $\equiv$ 3.0A (45.0W); 20.0V $\equiv$ 2.25A (45.0W) Output (USB-A 2): 5.0V $\equiv$ 1.0A (5.0W)
Total output	65W
Protocols	Protocols (USB-C 1/2): PD 3.0/PPS/AFC/FCP/Apple 2.4A Protocols (USB-A 1): QC 3.0/SCP/AFC/Apple 2.4A Protocols (USB-A 2): BC 1.2

Color	Art.No.	EAN Code
Black	FJFB0	6922794784345



Package Contents

65W GaN Universal Travel Adapter x 1

Packaging Information

Packing Dimension	12*8*5.5cm
Packing Weight	0.241kg
Carton Dimension	48*29*31cm
Carton Qty	50pcs
Carton Weight	12kg

<https://ventiontech.com/>