


GaNDash Series

30W GaN Dual-Port Fast Charger

Made for iPhone 15-16 Series/Android



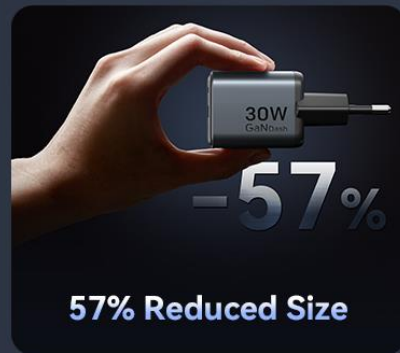

Charge iPhone 16 Pro Max in **30** minutes



GaN V Technology



Reduced
Size



Overheat
Protection



Safer
Charging



Higher
Efficiency




Note: The internal structure is a rendering. Please refer to the actual product.

Phone Camera Size

57% smaller than the original 30W charger.



-57%

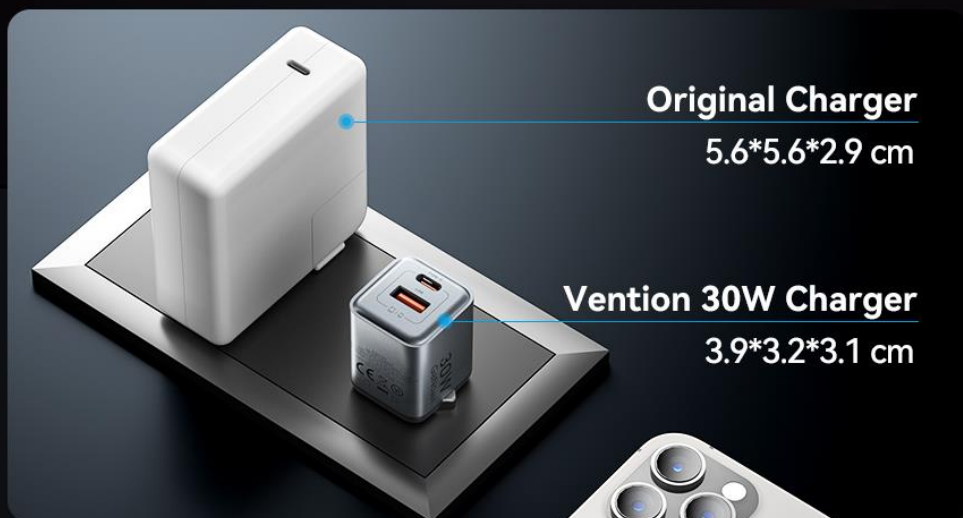

Original Charger

5.6*5.6*2.9 cm

Vention 30W Charger

3.9*3.2*3.1 cm

Note: All data are from Vention lab.

30W Max Fast Charging

Compatible with PPS protocol for fast charging tablets, Switches, phones, and more.

 


iPhone



30 Min ⚡
50%
16 Pro Max

Android



60 Min ⚡
98%
Samsung S22

Note: All data are from Vention lab.

Share Between Two Devices

One charger for two devices.



Single USB-C Output

⚡ **30W** Max

Single USB-A Output

⚡ **18W** Max

Superior Safety Protection

Safeguard your charging safety all night long.



Temperature
Control



Over Power
Protection



Overvoltage
Protection



Anti-interference
Protection



Over Current
Protection



Short Circuit
Protection



Lightning
Protection



Flame-Retardant
Protection

Note: The internal structure is a rendering.
Please refer to the actual product.

Universal Compatibility



Specifications

Brand	Vention
Name	30W GaN Charger
Model	FEW-EU
Color	Gray
Interface	USB-A/USB-C
Material	PC
Input	100-240V~ 50/60Hz, 0.8A Max
Output (USB-C)	5.0V $\equiv$ 3.0A (15.0W); 9.0V $\equiv$ 3.0A (27.0W); 12.0V $\equiv$ 2.5A (30.0W); 15.0V $\equiv$ 2.0A (30.0W); 20.0V $\equiv$ 1.5A (30.0W)
Output (USB-A)	5.0V $\equiv$ 3.0A (15.0W); 9.0V $\equiv$ 2.0A (18.0W); 12.0V $\equiv$ 1.5A (18.0W)
Output (USB-C + USB-A)	5.0V $\equiv$ 3.0A (15.0W)
Protocols (USB-C)	PPS/PD 3.0/QC 3.0/FCP/SCP/AFC/DCP
Protocols (USB-A)	QC 3.0/FCP/SCP/AFC/Apple 2.4A/DCP
Warranty	1 Year
Packaging	Color Box

Dimensions



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.

Packaging Display



Note: Packing difference exists for different meters or batches.
The photo is for reference only.



30W GaN Charger

Technical Features

Color	Gray
Interface	USB-A+C
Shell	PC
Input	100-240V~ 50/60Hz, 0.8A Max
Output	Output (USB-C): 5.0V≐ 3.0A (15.0W); 9.0V≐ 3.0A (27.0W); 12.0V≐ 2.5A (30.0W); 15.0V≐ 2.0A (30.0W); 20.0V≐ 1.5A (30.0W) Output (USB-A): 5.0V≐ 3.0A (15.0W); 9.0V≐ 2.0A (18.0W); 12.0V≐ 1.5A (18.0W) Output (USB-C + USB-A): 5.0V≐ 3.0A (15.0W)
Total Output	30.0W Max

Color	Art.No.	EAN Code
Gray	FEWH0-EU	6922794789074



Package Contents

30W GaN Charger x 1

Packaging Information

Packing Dimension	13.5*10*3.6cm
Packing Weight	0.115kg
Carton Dimension	48*29*30cm
Carton Qty	62pcs
Carton Weight	8.1kg

<https://ventiontech.com/>