

VENTION[®]
Innovation for life

3-Ports USB (C+C+A) GaN Charger (70W/70W/22.5W)






GaN Nitride V

Smaller Safer
More Efficient

iPhone 16 Pro Max
Charge About 50%



Samsung Galaxy S24
Charge About 50%

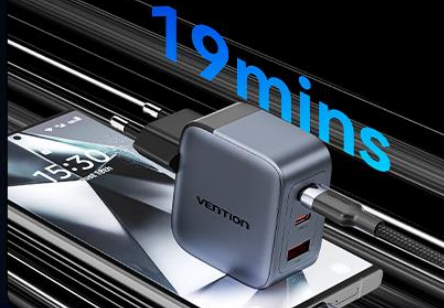

Smaller



70W

Turbo Speed



Fast Charging on 3 Ports



Wide Compatibility
Charges Laptops, Tablets
and Phones



70W PD & PPS Turbo Charging for Laptops



 
30mins ⚡



Charge **50%**

MacBook Air M2


43mins ⚡



Charge **50%**

Google Pixelbook

 48mins ⚡



Charge **50%**

Dell XPS 13 9360

Note: All data are from Vention lab.

70W Fast Charging

Compatible with fast charging technologies, PPS, PD 3.0, QC 3.0, AFC, SCP, FCP, Apple 2.4A, and BC 1.2.

Supports full-speed fast charging for iPhone 16 Pro Max



Supports Samsung 45W Super Fast Charging



Charge About
50%
iPhone 16 Pro Max



Charge About
50%
Samsung Galaxy S24

Note: All data are from Vention lab.

Powerful Yet Space-Saving

About 31% smaller compared to Apple's
original 70W charger.



Smaller
31%



Others

64.9 * 64.9 * 28.7mm

Vention

31 * 54 * 50mm

Note: All data are from Vention lab.

GaN Nitride V Smaller Safer More Efficient



Note: The internal structure is a rendering. Please refer to the actual product.

One Charger for All




Charge Three Devices Simultaneously




Smart Power Distribution


Single Port

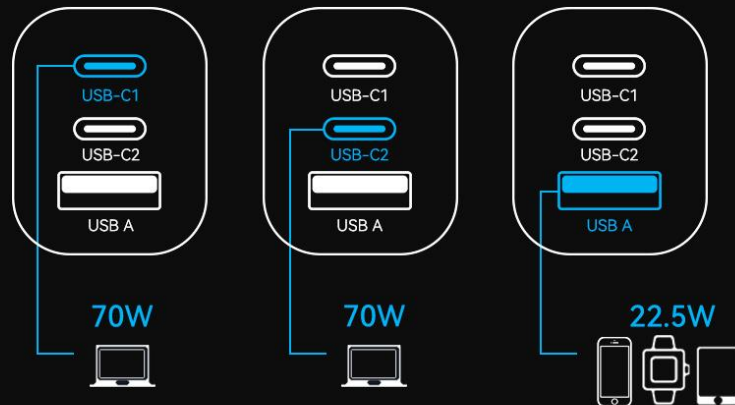

Dual Ports

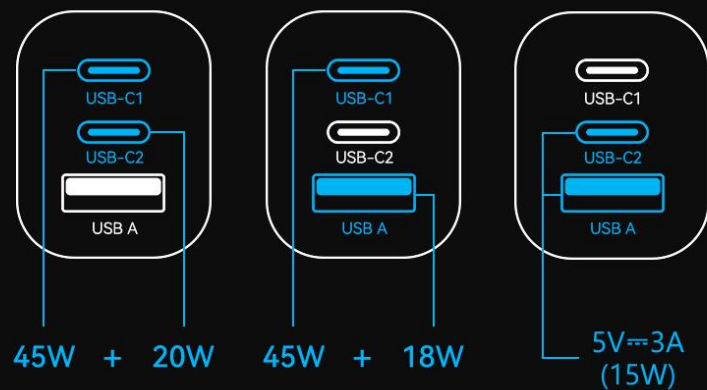

Three Ports

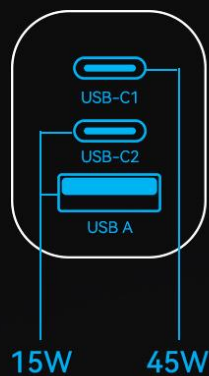

Low Temperature Technology

Safe charging with real-time protection all night.



Temperature
Protection



Overvoltage
Protection



Over Current
Protection



Short Circuit
Protection



Flame-Retardant
Protection

Note: The internal structure is a rendering. Please refer to the actual product.

Universal Compatibility



Specifications

Brand	Vention
Name	3-Port USB (C+C+A) GaN Charger (70W/70W/22.5W) EU-Plug Gray
Model	FEX-EU
Color	Gray
Charger	
Interface Type	USB-A/USB-C * 2
Shell	PC
Input	100-240V~ 50/60Hz 1.5A Max
Output	5.0V $\equiv$ 3.0A 15.0W; 9.0V $\equiv$ 3.0A 27.0W;
USB-C1/USB-C2	12.0V $\equiv$ 3.0A 36.0W; 15.0V $\equiv$ 3.0A 45.0W; 20.0V $\equiv$ 3.5A 70.0W
Output USB-A	5.0V $\equiv$ 3.0A 15.0W; 9.0V $\equiv$ 2.0A 18.0W; 12.0V $\equiv$ 1.5A 18.0W; 10.0V $\equiv$ 2.25A 22.5W
Total Output	70.0W Max
Supported Protocols	QC 3.0/QC 2.0/PD 3.0/PD 2.0/PPS/PE 2.0 /SCP/FCP/Apple 2.4A/AFC/BC 1.2/DCP
Warranty	1Year
Packaging	Color Box

Dimensions



Note: All data are from Vention Lab.
Sizes above are manually measured. There might be slight tolerance.

Packaging Display



Note: Packing difference exists for different meters or batches.
The photo is for reference only.



70W GaN Charger

Technical Features

Color	Gray
Interface	USB-A+C
Shell	PC
Input	100-240V~ 50/60Hz, 1.5A Max
Output	Output (USB-C1/USB-C2): 5.0V≡3.0A (15.0W); 9.0V≡3.0A (27.0W); 12.0V≡3.0A (36.0W); 15.0V≡3.0A (45.0W); 20.0V≡3.5A (70.0W) Output (USB-A): 5.0V≡3.0A (15.0W); 9.0V≡2.0A (18.0W); 12.0V≡1.5A (18.0W); 10.0V≡2.25A (22.5W) Output (USB-C1 + USB-C2): 45.0W + 20.0W Output (USB-C1 + USB-A): 45.0W + 18.0W Output (USB-C2 + USB-A): 15.0W Output (USB-C1 + USB-C2 + USB-A): 45.0W + 15.0W
Total Output	70.0W Max

Color	Art.No.	EAN Code
Gray	FEXH0-EU	6922794789081



Package Contents

70W GaN Charger x 1

Packaging Information

Packing Dimension	13.5*10*3.9cm
Packing Weight	0.176kg
Carton Dimension	48*29*30cm
Carton Qty	62pcs
Carton Weight	12kg

<https://ventiontech.com/>