

Receptacle

KS-103 23

Item KS-10323

 


GO TO PRODUCT


ingun[®]

Partner for Future Technology

INGUN SELECTION



1:1

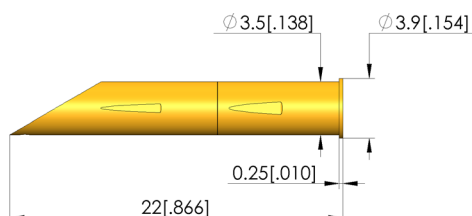

General data

Product group:
Series:
Sub-series:
Type of receptacle connection:
Press ring:
Surface area:
Collar diameter:
Collar height:
Knurl:
Vacuum-tight:
RoHS-compliant:

Receptacles (KS)
KS-103
KS-103 23 press-in version
Solder / open
No
Gold
3.9 mm [.153 in]
0.25 mm [.009 in]
No
No
RoHS-3;6c

Mounting hole

Mounting hole in CEM1:
Mounting hole in FR4:

3.48 - 3.49 mm [.137 - .137 in]
3.48 - 3.49 mm [.137 - .137 in]

Mechanical data

Total length:
Outer diameter:

22 mm [.866 in]
3.5 mm [.137 in]

INGUN Prüfmittelbau GmbH

Max-Stromeyer-Straße 162
78467, Constance, Germany
Phone +49 7531 8105-0
Customer hotline +49 7531 8105-888
Fax +49 7531 8105-65
info@ingun.com



Prices and delivery times on request.
Technical changes reserved. 02/25_GB