


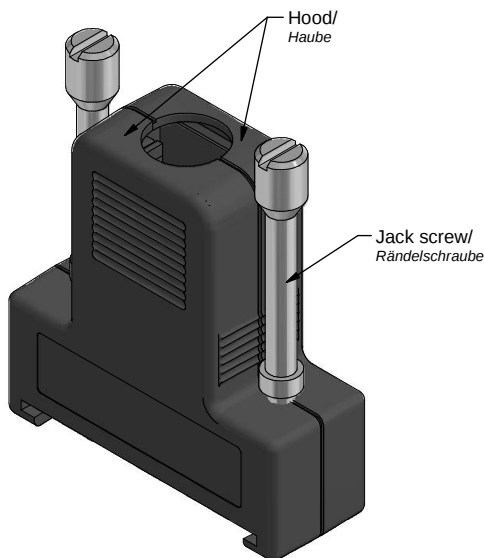

Technical specification/

Technische Daten:

Temperature range/ - 35 °C ... + 85 °C
 Temperaturbereich:

Materials/

Werkstoffe:



Hood/ ABS UL 94 V-0, black/schwarz
 Haube:

Jack screw/ Brass, nickel plated/
 Rändelschraube Messing, vernickelt

Installation specification/

Montagedaten:

Cable outlet/ straight/Gerade
 Kabelausgang:

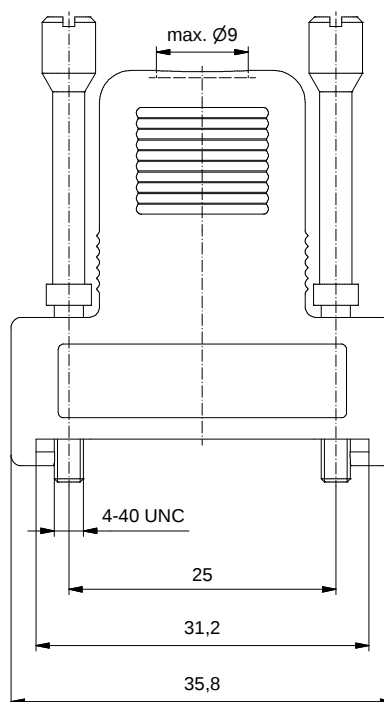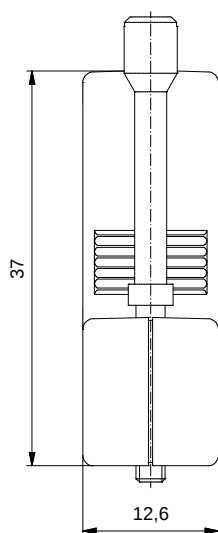

Part no./
 Art.-Nr.
 165X16219X

				dim. in mm		Plastic Hood 9pos. with straight cable exit Kunststoffhaube 9pol. mit gerader Kabelausgang	
general tolerance/ $\pm 0,40$ <i>Allgemeintoleranz:</i>		drawn/ <i>gez.</i>	Date/ <i>Datum</i>	Name			
		appd./ <i>gepr.</i>	04.11.2019	Unkrüer			
			05.11.2019	Fischer			
Index: a Original	scale/Maßstab: 2:1			dwg no /		16K1A4180	DIN-A3
Status: InBearbeitung				Z.-nr.:			
RoHS compliant/ <i>konform</i>							
						1 / 1	