
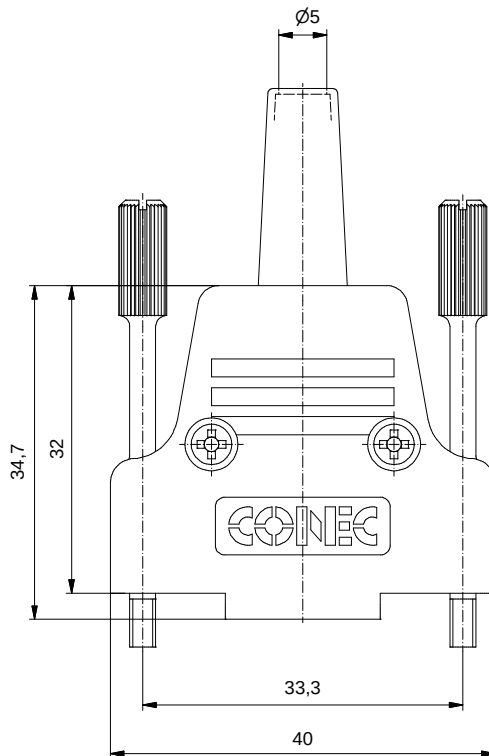
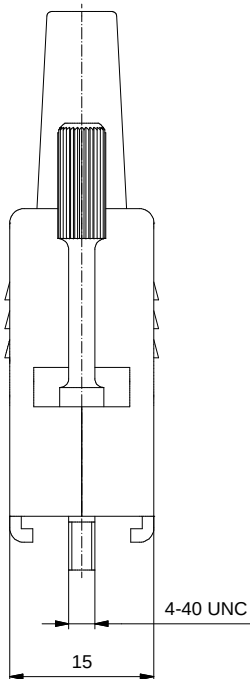
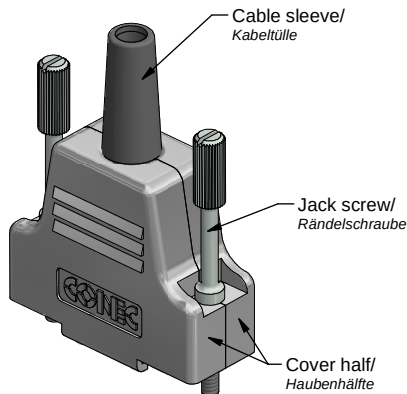


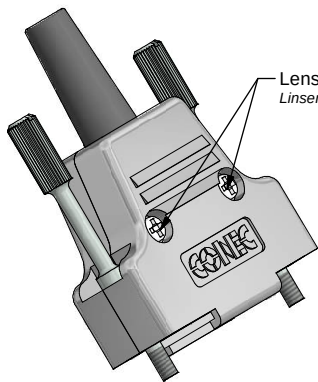

(b) Technical specification:

Technische Daten:

Temperature range/ - 35 °C ... + 90 °C
Temperaturbereich:

Materials/

Werkstoffe:

Cover half/ GD-Zn, Ni
Haubenhälfte:
Cable strain relief/ Steel, Ni
Kabel Zugentlastung:
Cable sleeve/ Rubber
Kabeltülle:
Jack screw/ Steel, Ni
Rändelschraube:
Lens head screw/ Steel, Ni
Linsenkopfschraube:

Installation specification/

Montagedaten:

Cable outlet/ straight/ gerade
Kabelausgang:

Part no./ Art.-Nr.	
165X17319X	Bulk package/ Massenverpackung
165X17319XE	Single package/ Einzelverpackung

				dim. in mm		Full metal hood 15pos. with straight cable exit Vollmetallhaube 15pol. mit gradem Kabelausgang	
		drawn/ gez.	Date/Datum	Name			
		appd./ gepr.	16.04.2018	Unkrüer			
			17.04.2018	Schmidt			
Index: b Ä7223 16.04.18 L.U.	Scale/Maßstab: 2:1			dwg no / Z.-nr.:		16K1A4047	DIN-A3
Status: InBearbeitung							
RoHS compliant/ konform							1 / 1