



F I E D C B A

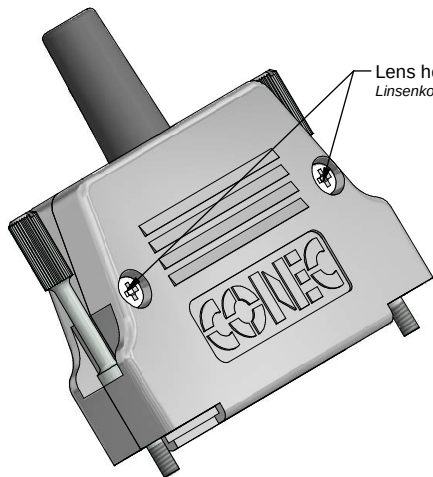



Lens head screw/
Linsenkopfschraube

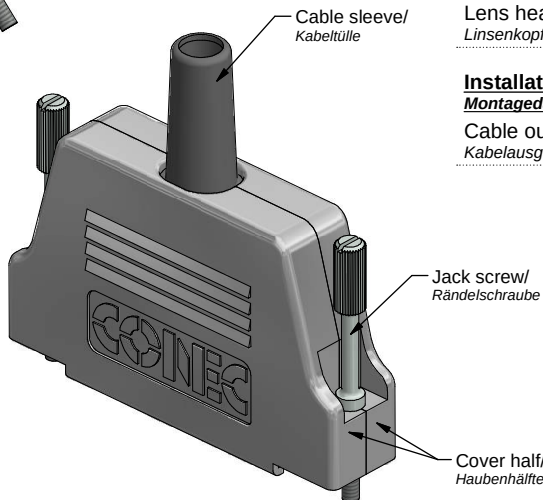

Cable sleeve/
Kabeltülle

Jack screw/
Rändelschraube

Cover half/
Haubenhälfte

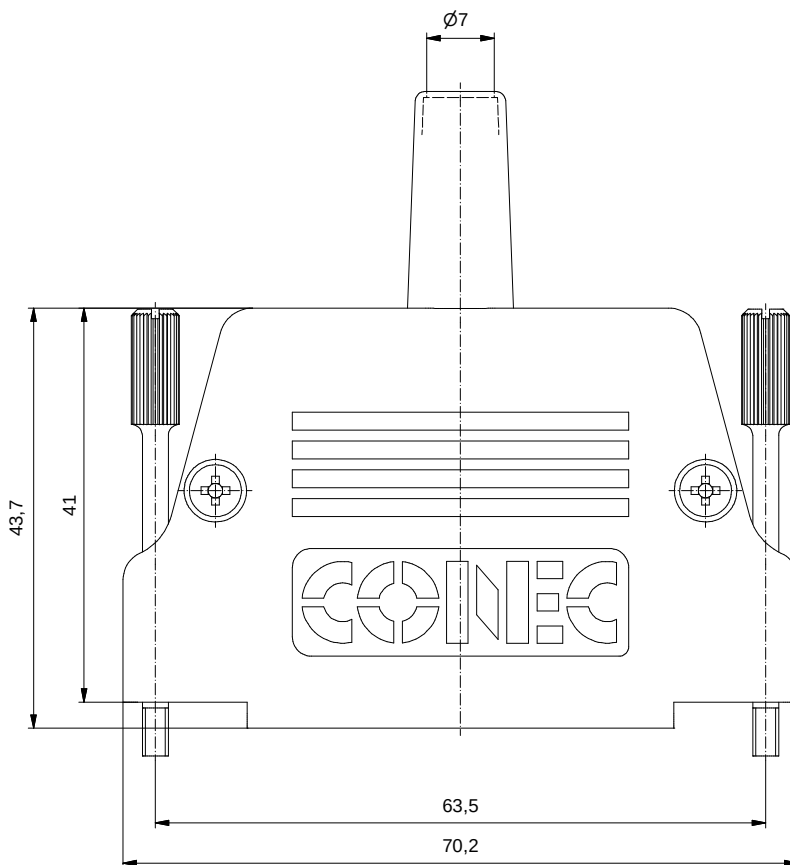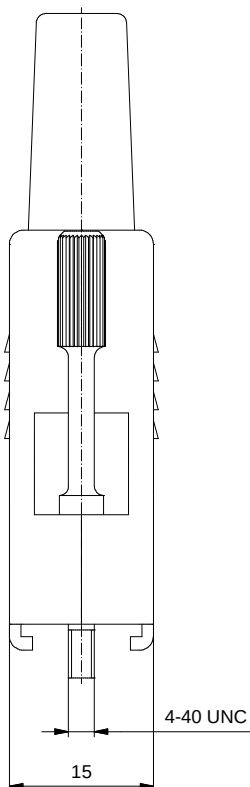

(b) **Technical specification:**

Technische Daten:

Temperature range/ - 35 °C ... + 90 °C
Temperaturbereich:

**Materials/
Werkstoffe:**

Cover half/
Haubenhälfte: GD-Zn, Ni

Cable strain relief/
Kabel Zugentlastung: Steel, Ni

Cable sleeve/
Kabeltülle: Rubber

Jack screw/
Rändelschraube: Steel, Ni

Lens head screw/
Linsenkopfschraube: Steel, Ni

**Installation specification/
Montagedaten:**

Cable outlet/
Kabelausgang: straight/ gerade

Part no./ Art.-Nr.	
165X17339X	Bulk package/ Massenverpackung
165X17339XE	Single package/ Einzelverpackung

		dim. in mm	Full metal hood 37pos. with straight cable exit Vollmetallhaube 37pol. mit gradem Kabelausgang	
		Date/Datum		
		Name		
		drawn/gez. appd./gepr.		
Index: b Ä7223 16.04.18 L.U.		16.04.2018	Unkrüer	dwg no / Z.-nr.: 16K1A4049
Status: InBearbeitung		17.04.2018	Schmidt	
RoHS compliant/ konform		Scale/Maßstab: 2:1		DIN-A3 1 / 1
		CONEC®		

F I E D C B A